

# LED Site/Roadway/Wall Pack Lamp Series



<b>Stock No.</b>	<b>Product Description</b>
<b>LED-8002-DL</b>	<b>PT-120/277-45W-45LED-DL (Daylight)</b>
<b>LED-8002-NW</b>	<b>PT-120/277-45W-45LED-NW (Neutral White)</b>

**Description:**

Mogul base Hi Power 45W LED Site / Roadway or Wall Pack lamp that can replace up to a 150W MH/HPS light output in an energy saving, 50,000 hr. alternative to Metal Halide, HPS, Fluorescent, or Incandescent lighting. Available in Daylight LD (5700K) or Neutral White NW (3000K).

- 45 Watt
- 100-277 Volt operation
- Daylight DL (5700K) or Neutral White (3000K)
- Lumens: 2900(DL) or 2800(NW)
- 45 on-board LED SMDs
- Up to 50,000 hour lamp life
- Minimal heat output
- Not dimmable
- 5 year warranty
- Active Cooling Delta 70K Hr Fan
- UL Damp Location Listed
- LM79, IES Available

**Applications:**

LED Site/Roadway/Wall Pack Series lamps can impact energy usage and costs in a major way for communities and housing developments with minimal to no maintenance costs thanks to the up to 50,000 hour lamp life.


- Site/Roadway/Post Top
- Wall packs (where applicable)
- Security lighting
- Parks and quads
- Municipal lighting

**Packaging:**

Master pack: 6 each

**Note: Maximum height from ground is 7 meters**

**Note: When retrofitting LED to HID fixture, ballast must be bypassed when present. Eliminating the ballast saves additional costs related to maintenance, energy consumption and performance. Additionally, by-passing ballast will insure no RFI interference.**

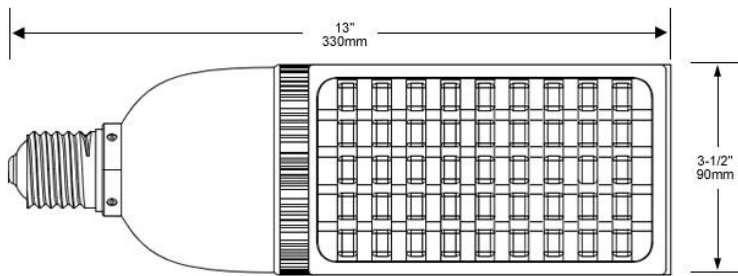

**Technical Specifications:**

<b>Bulb Type:</b>	<b>Site/Roadway/Wall</b>	<b>Mounting:</b>	<b>Mogul E39</b>
<b>Bulb Material:</b>	<b>Alum/Polycarbon</b>	<b>Replaces:</b>	<b>Up to 150W MH/HPS</b>
<b>Power Factor:</b>	<b>99</b>	<b>Life Time:</b>	<b>Up to 50,000 Hrs.</b>
<b>Output Power:</b>	<b>45W</b>	<b>Input Voltage:</b>	<b>AC 100 – 277V</b>
<b>Lumens:</b>	<b>2900(DL), 2800(NW)</b>	<b>Beam Angle:</b>	<b>120 °</b>
<b>Dimensions:</b>	<b>3-1/2" x 13"</b> <b>90mm x 330mm</b>	<b>Kelvin Temp:</b>	<b>(DL) 5700K</b> <b>(NW) 3000K</b>
<b>Lumen per Watt:</b>	<b>62-66</b>	<b>LEDs:</b>	<b>45 Hi Power LEDs</b>
<b>CRI:</b>	<b>85</b>	<b>Dimmable:</b>	<b>No</b>

Note: All specification information falls within a ± 2% range and is subject to change without notice.

NOTE: Light Efficient Design is providing this information to the general public. Please note that all products contained herein are trademarked, copyrighted, and/or have patents pending. Any use of these designs is strictly prohibited without prior written consent. Light Efficient Design protects its proprietary information vigorously in the courts of the United States of America.

106 S. Wynstone Park Drive • N. Barrington, IL 60010  
(847) 380-3540 • FAX: (847) 380-3542  
www.led-llc.com

