

PSH Portable Shop Heater

FEATURES:


- Standard color: Yellow with black accents
- Standard finish epoxy/polyester paint 240V, 1-Phase
- Includes both comfort grip handle & storage handle options
- Handle may be used as a reel for the electric cable
- 6 foot (2m) molded electric cable
- High-limit temperature control with manual reset
- Auto fan delay
- 300 CFM fan
- Stainless steel tubular heating element
- 51° F temperature rise
- Built-in thermostat (60-170°F)
- 4000W may be plugged in to 3-pronged, 20A 250 VAC, 240V outlet
- Mounting bracket for wall or ceiling installation included
- Mounting brackets allow 360° rotation of the unit
- 1-year warranty against defects



The PSH is a high power portable heater designed to provide a back-up heating source at an affordable price. Perfectly suited for the workshop, garage or construction sites, the rotation capability. The convenient 6 foot cord allows greater mobility to areas needing heating, while the handle serves as a reel for the cord when not in use. Easily set the desired temperature with the built-in thermostat. Sure stop high-limit temperature control with manual reset provides overheat protection. With a 300 CFM fan, heat is dispersed efficiently. Standard color: Yellow. 240 Volt Single Phase. One year warranty.

MODEL	UPC# 093319 PART #	DESCRIPTION
PSH2440TB	20637	4000W, 240V, 1-Phase

MOUNTING OPTIONS:

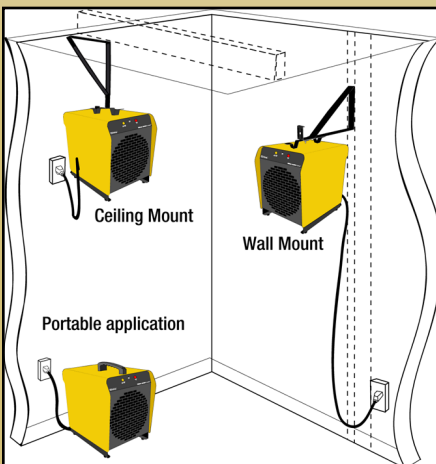

SPECIFICATIONS	
BTU	13,000B
Watts	3,750W
Heating Area (ft2)	450 ft2
Power (Volts)	240V~60Hz
Amps	16A
Heat Settings 1	On/Off
Heat Settings 2	Thermostat

Minimum Clearance From Combustibles

Front	3 ft.
Top	1 ft.
Sides	1 ft.
Rear	1 ft.

