

**DESCRIPTION**

600 Luminous Square Vanity Luminaire. ADA compliant.  
Available in energy efficient LED  
Interior Wall Luminous Vanity Luminaire  
Aluminum or stainless steel end caps and an aluminum body  
Integral electronic HPF, multi-volt 120/277V (347V Canada)  
Standard: Natural Aluminum; Premium: Contact factory for finishes  
Universal mounting back for a standard 3" plaster ring or switch-box  
UL and CUL approved for interior and damp locations; ADA compliant

<b>Catalog #</b>		<b>Type</b>
<b>Project</b>		
<b>Comments</b>		<b>Date</b>
<b>Prepared by</b>		

**SPECIFICATION FEATURES**

**Material**

Painted, plated cold-rolled steel, brass, copper or aluminum end caps and an aluminum body with an extruded matte white acrylic diffuser.

**Finish**

Standard: Natural Aluminum (NA). [Sustainable Design]  
Premium: Aluminum Paint (ALP), Bronze Metallic Paint (BM), Gold Metallic Paint (GM), Matte White (MW), Gun Metal (GNM), Lacquered Satin Aluminum (SAL), Satin Stainless Steel (SSS), Satin Chrome (SC), Polished Chrome (PC), Satin Brass (SB), Polished Brass (PB), Satin Copper (SCP), Polished Copper (PCP), Oxidized Copper (OCP), Satin Nickel (SN), Polished Nickel (PN) or Custom Color (CC).

**Optics**

Refer to www.shaperlighting.com for complete photometrics.

**Ballast**

Integral electronic HPF, multi-volt 120/277V (347V Canada), thermally protected with end-of-life circuitry to accommodate the specified lamp wattage.

**Lamping Options  
Fluorescent Tubes**

24": Two (2) 14W T5 linear fluorescent lamps.

36": Two (2) 21W T5 linear fluorescent lamps. Fluorescent socket injection molded plastic. Lamps furnished by others.

**LED**

24": L1:1300 Nominal lumens at max 12.6W  
36": L3:2000 Nominal lumens at max 18.9W

Long-life LED system coupled with electrical driver to deliver optimal performance. Electronic drivers are available for 120-277 applications. A 0-10V dimming control is available (Standard) on all models.

**Installation**

Supplied with a universal mounting back for a standard 3" plaster ring or switch-box. 36" Luminaire has additional mounting holes to ensure secure attachment. Horizontal or vertical mount. Shaper luminaires are designed for interior installations only.

**Options**

Dimming Ballast - Lutron (DML), Remote Emergency Ballast - Supplied by others (REM), Hand Painted Faux Linen Diffuser (LND), Damp Location (DL): All painted finishes only. Energy Star Rating - Contact factory.

**Labels**

U.L. and C.U.L approved for indoor and damp location. See options for damp location finishing requirements. Shaper's DL option is for interior applications (only) that have more than average moisture (i.e. bathroom, laundry room, etc.) but are not UL listed for pool, sauna, shower, whirlpool and any exterior applications (i.e. covered garage or building entrance) with exposure to weather elements such as rain, wind, etc. ADA compliant.

**Modifications**

Shaper's skilled craftspeople with their depth of experience offer the designer the flexibility to modify standard wall luminaires for project specific solutions. Contact the factory regarding scale options, unique finishes, mounting, additional materials/colors, or decorative detailing.



**600 SERIES**

Interior Wall Luminaire  
Luminous Square Vanity



**ARRA**  
Shaper Lighting certifies that its products satisfy the requirements of Section 1605 of the American Recovery and Reinvestment Act (also known as the ARRA Buy American provision).

**ADA AMERICAN DISABILITIES ACT (ADA)**  
Shaper offers a large selection of ADA interior and exterior wall luminaires. ADA requires all fixtures below 68" to have a maximum projection of 4".

**QUICK SHIP (QS)**  
Shaper's Quick Ship program features over thirty-four fixtures with finish options such as Satin Chrome, Natural Aluminum and Satin Brass and a wide variety of lamp selections. All products ship in five days from receipt of order.

**SUSTAINABLE DESIGN**  
Shaper has a long-standing history of offering environmentally-friendly fixtures. The copper and bronze alloys used in our exterior luminaires feature up to 98% recycled content, contribute less undesirable air emissions compared to painted aluminum and are easy to recycle.


ORDERING INFORMATION

Sample Number: 600-24-W-T5/2/14-277V- ALP-DL


Series	Size	Mounting Type	Lamp	Voltage	Finish	Options
600=Luminous Sconce Vanity	24=24" 36=36"	W=Wall	T5/2/14 <sup>1</sup> T5/2/21 <sup>2</sup>	120V 277V 347V	Standard NA=Natural Aluminum Premium ALP=Aluminum Paint BM=Bronze Metallic Paint CC=Custom Color GM=Gold Metallic Paint GNM=Gun Metal MW=Matte White OCP=Oxidized Copper PC=Polished Chrome PCP=Polished Copper PN=Polished Nickel SAL=Lacquered Satin Aluminum SB=Satin Brass SC=Satin Chrome SCP=Satin Copper SN=Satin Nickel SSS=Satin Stainless Steel	DL=Damp Location DML=Dimming Ballast (Lutron) <sup>1,2</sup> LND=Hand Painted Faux Linen Diffuser REM=Remote Emergency Ballast <sup>3,4</sup>
	LED Size 24=24" 36=36"		LED Lamp L1/827 <sup>3</sup> L3/827 <sup>3</sup> L1/830 <sup>3</sup> L3/830 <sup>3</sup> L1/835 <sup>3</sup> L3/835 <sup>3</sup> L1/840 <sup>3</sup> L3/840 <sup>3</sup>	UNV (120-277V)		

Notes:  
<sup>1</sup> Available in 24".  
<sup>2</sup> Available in 36".  
<sup>3</sup> Interior applications only.  
<sup>4</sup> Supplied by others  
**LED Lamp:**  
 L1-1300 nominal lumens at max 12.6W  
 L3-2000 nominal lumens at max 18.9W

MOUNTING TYPE

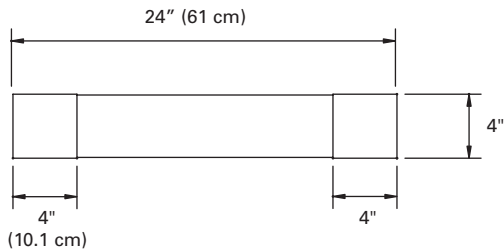

600 - 24" FLUORESCENT or LED

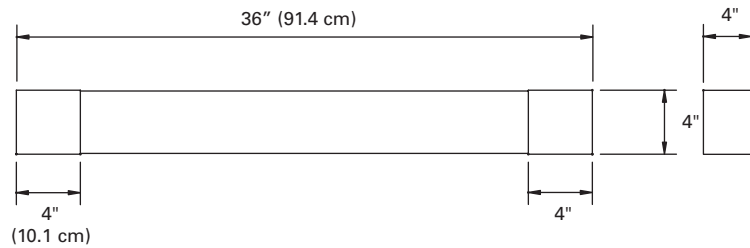

600 - 36" FLUORESCENT or LED