

High CRI T12

FB40T12/6 CW Supreme



Philips T12 High CRI Lamps are energy-efficient lighting solutions and provide excellent color consistency over the life of the lamp.

Product data

• General Characteristics

Base	Medium Bi-Pin [Medium Bi-Pin Fluorescent]
Base Information	Aluminum [Aluminum Base]
Bulb	T12-6U [U-bent T 12/8 inch with 6" spacing]
Rated Avg. Life [3 hr Start]	18000 hr
Energy Saving	Not Applicable

• Light Technical Characteristics

Color Rendering Index	90 Ra8
Color Designation	Cool White Supreme
Color Temperature	4100 K
Initial lumen	2300 Lm
Design Mean Lumens	1955 Lm

• Electrical Characteristics

Watts	40 W
-------	------

• Environmental Characteristics

Mercury (Hg) Content	10.0 mg
----------------------	---------


• Product Dimensions

Nominal Length [inch]	22.44
-----------------------	-------


• Product Data

Product number	423087
Full product name	FB40T12/6 CW Supreme
Short product name	FB40/T12/CW Supreme/6 12PK
Pieces per Sku	1
Skus/Case	12
Bar code on pack	46677423087
Bar code on case	50046677423082
Logistics code(s)	927862003702
eop_net_weight_pp	0.001 kg


Dimensional drawing

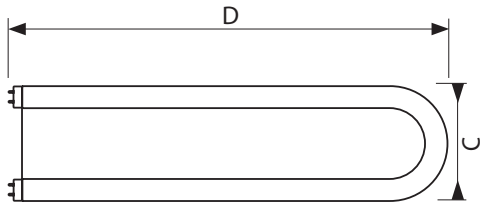

G13, T12-UR

 

G13

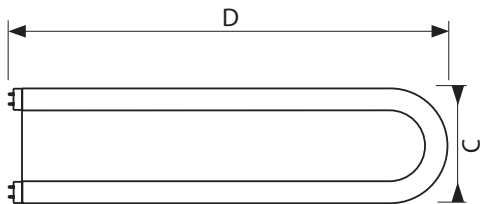

G13, T12-UR



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change