

# Take Stock In America

Buy American

## 48-Hour Quick Ship Program

*(For more expedited shipment, please consult your Customer Service Representative)*



### Recessed Lensed Troffer

Premium grade grid troffer. Acrylic lens. T-8 lamp. Universal Volt Ballast (120/277) - UE


Catalog #	Part #	Description	Stock Level	Ships From
G A 2 32 SD SSO10 UE	53916	2x4, 2 Lamp, 32 W T8 120/277	250	KS
G A 3 32 SD SSO10 UE	53917	2x4, 3 Lamp, 32 W T8 120/277	300	KS
G A 4 32 SD SSO10 UE	53918	2x4, 4 Lamp, 32 W T8 120/277	250	KS
L A 2 U32 SD SSO10 UE	M53919	2x2, 2 Lamp, 32 W T8 U (6") 120/277	250	KS or NY
LA125 3 32 SD SSO10 UE	M50798	2x4, 3 Lamp, 32 W T8 120/277	100	KS or NY
LA125 4 32 SD SSO10 UE	237003	2x4, 4 Lamp, 32 W T8 120/277	100	KS or NY



### Parabolic

Nominal 3" deep louver assembly with parabolic shaped cellular baffles. T-8 lamp. Universal Volt Ballast. (120/277)- UE

Catalog #	Part #	Description	Stock Level	Ships From
N2P G 9 2 U32 FD SSO10 UE	53920	2x2, 2 Lamp, 32 W T8U (6") 9 Cell 120/277	300	KS or NY
PGN 18 3 32 FD SSO10 UE	53921	2x4, 3 Lamp, 32 W T8 18 Cell 120/277	300	KS or NY

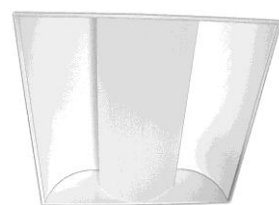

### Fluorescent Recessed Direct / Indirect

Recessed 2 x 2 and 2 x 4 direct / indirect fixtures with perforated center or acrylic center basket (RAD). T-5 Biax and T-8 lamps. Universal Volt Ballast. (120/277)- UE

Catalog #	Part #	Description	Stock Level	Ships From
2PEC G 2 40BX RPW SSBR UE	409016	2X2, 2 Lamp, 40 W Biax 120/277	300	KS or NY
2PEC G 2 17 RPW SSO10 UE	409752	2x2, 2 Lamp, 17 W T8 120/277	150	KS or NY
2PEC G 3 17 RPW SSO10 UE	409757	2x2, 3 Lamp, 17 W T8 120/277	100	KS or NY
2PEC G 2 32 RPW SSO10 UE	409136	2x4, 2 Lamp, 32 W T8 120/277	200	KS or NY
2PEC G 3 32 RPW SSO10 UE	408662	2x4, 3 Lamp, 32 W T8 120/277	300	KS or NY
2PEC G 2 40BX RAD SSBR UE	463600	2x2, 2 Lamp, 40 W Biax 120/277	50	NY
2PEC G 2 17 RAD SSO10 UE	480081	2x2, 2 Lamp, 17 W T8 120/277	50	NY
2PEC G 2 32 RAD SSO10 UE	441462	2x4, 2 Lamp, 32 W T8 120/277	50	NY
2PEC G 3 32 RAD SSO10 UE	436006	2x4, 3 Lamp, 32 W T8 120/277	50	NY



### IMX

Industrial Fluorescent High Bay Fixture featuring Miro 4 internal reflector. Available in 4 lamp T-5 or T-8 and 6 lamp T-5 or T-8 variations. Universal Volt Ballast. (120-277) UE

Catalog #	Part #	Description	Stock Level	Ships From
IMX 4 54 SS5HO UE	214558	4 ft, 4 Lamp, 54 W T5 120/277	500	NY
IMX 6 54 SS5HO2 UE	214557	4 ft, 6 Lamp, 54 W T5 120/277	500	NY
IMX 4 32 SSO10 UE	214561	4 ft, 4 Lamp, 32 W T8 120/277	200	NY
IMX 6 32 SSO102 UE	214559	4 ft, 6 Lamp, 32 W T8 120/277	500	NY



For Additional Information Contact  
Your Local Representative

www.lsi-industries.com

# Take Stock In America

Buy American

## 48-Hour Quick Ship Program

*(For more expedited shipment, please consult your Customer Service Representative)*



### Striplight

Premium housing crimped along sides for extra rigidity and straight alignment. Accepts optional plug-in wiring feature for continuous row installation. T-8 lamps. Universal Volt Ballast (120/277) - UE where applicable.

Catalog #	Part #	Description	Stock Level	Ships From
S 2 25 SSO10 UE	318939	3 ft, 2 Lamp, 25 W T8 120/277	15	KS
S 1 32 SSO10 UE	318949	4 ft, 1 Lamp, 32 W T8 120/277	250	KS or NY <sup>1</sup>
S 2 32 2 SSO10 UE	246900	8 ft, 4 Lamp, 32 W T8 Tandem, 120/277	250	KS or NY <sup>2</sup>
S 2 32 SSO10 UE	234759	4 ft, 2 Lamp, 32 W T8 120/277	250	KS or NY
S 2 59 SSO10 UE	308820	8 ft, 2 Lamp, 59 W T8 120/277	100	KS

NOTE: <sup>1</sup>Part # 434192    <sup>2</sup>Part # 438339



### Industrial

Solid top reflector. T-8 lamps. Quarter turn, captive fasteners release reflector for access to ballast compartment. Furnished with alignment clips and channel coupler. Universal Volt Ballast (120/277) - UE

Catalog #	Part #	Description	Stock Level	Ships From
F22 2 32 2 SSO10 UE W/REFL	297339	8 ft, 4 Lamp, 32 W T8 120/277	100	KS or NY <sup>3</sup>
F22 2 32 SSO10 UE W/REFL	53428Z	4 ft, 2 Lamp, 32 W T8 120/277	100	KS or NY

NOTE: <sup>3</sup>Part # 434558



### Low Profile Wraparound

Surface mounted fluorescent wraparound with impact resistant acrylic lens. T-8 lamps. Low profile appearance with heavy duty steel ends for row mounting without using aligners. Universal Volt Ballast (120/277) - UE

Catalog #	Part #	Description	Stock Level	Ships From
WNA 10 2 32 8T SSO10 UE	360741	8 ft, 4 Lamp, 32 W T8 120/277	50	KS or NY
WNA 10 2 32 SSO10 UE	360712	4 ft, 2 Lamp, 32W T8 120/277	250	KS or NY
WNA 14 3 32 SSO10 UE	360713	4 ft, 3 Lamp, 32W T8 120/277	50	KS or NY
WNA 14 4 32 SSO10 UE	360714	4 ft, 4 Lamp, 32W T8 120/277	200	KS or NY



### Vapor Tight Fixture with Fiber Glass Housing and High Impact Diffuser

High-impact, reinforced polyester, fiberglass housing. T-8 lamps. Standard diffuser formed with 25% high-impact acrylic for strength. National sanitation foundation approved and listed. Universal Volt Ballast (120/277) - UE

Catalog #	Part #	Description	Stock Level	Ships From
EG3 2 32 SSO10 WL UE	246823	4 ft, 2 Lamp, 32 W T8 120/277 Wet label listed	100	KS or NY
EG3 2 32 2 SSO10 WL UE	318874	8 ft, 4 Lamp, 32 W T8 120/277 Tandem, Wet label listed	100	KS or NY



### High Efficiency Expansive Cavity Recessed

For indoor ambient applications, with reduced energy usage. Exclusive linear prismatic lens design offers optimum light delivery by creating controlled, uniform lighting at higher angles to deliver precise, even illumination from the ceiling to the floor thus eliminating shadows.

Catalog #	Part #	Description	Stock Level	Ships From
ASC2 2 17 SSO10 UE	347373	2x2, 2 Lamp, 17 W T8 120/277	200	NY
ASC2 2 28 SS5R UE	384899	2x2, 2 Lamp, 28 W T5 120/277	150	NY
ASC2 2 32 SSO10 UE	348747	2x4, 2 Lamp, 32 W T8 120/277	200	NY



For Additional Information Contact  
Your Local Representative

