

Accessories




Cables and Connectors - Dimensional Drawings and Order Information

M8 3-pin DC Cables

Type	Part no.	Notes
RD3-SM8	7 023 101	Receptacle, DC, 3-pin M8, straight female, field wireable
RD3-RM8	7 023 102	Receptacle, DC, 3-pin M8, right-angle female, field wireable
RD3-SM8M	7 026 124	Receptacle, DC, 3-pin M8, straight male, field wireable
KD3-SUM82	7 022 768	Cable, DC, 3-wire M8, straight female, 2 m, PUR
KD3-SUM85	7 022 769	Cable, DC, 3-wire M8, straight female, 5 m, PUR
KD3-SUM810	7 023 113	Cable, DC, 3-wire M8, straight female, 10 m, PUR
KD3-RUM82	7 023 099	Cable, DC, 3-wire M8, right-angle female, 2 m, PUR
KD3-RUM85	7 023 100	Cable, DC, 3-wire M8, right-angle female, 5 m, PUR
KD3-RUM810	7 023 114	Cable, DC, 3-wire M8, right-angle female, 10 m, PUR

M8 4-pin DC Cables



Type	Part no.	Notes
RD4-SM8	6 009 974	Receptacle, DC, 4-pin M8, straight female, field wireable
RD4-RM8	6 009 975	Receptacle, DC, 4-pin M8, right-angle female, field wireable
RD4-SM8M	7 025 749	Receptacle, DC, 4-pin M8, straight male, field wireable
KD4-SUM82	7 022 754	Cable, DC, 4-wire M8, straight female, 2 m, PUR
KD4-SUM85	7 022 784	Cable, DC, 4-wire M8, straight female, 5 m, PUR
KD4-SUM810	7 023 016	Cable, DC, 4-wire M8, straight female, 10 m, PUR
KD4-RUM82	7 023 775	Cable, DC, 4-wire M8, right-angle female, 2 m, PUR
KD4-RUM85	7 023 776	Cable, DC, 4-wire M8, right-angle female, 5 m, PUR
KD4-RUM810	7 023 020	Cable, DC, 4-wire M8, right-angle female, 10 m, PUR
KD4-SUM85E	7 023 663	Cable, DC, 4-wire M8, straight female, 5 m, PUR, extension cable

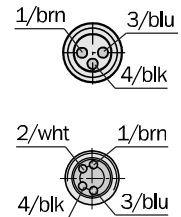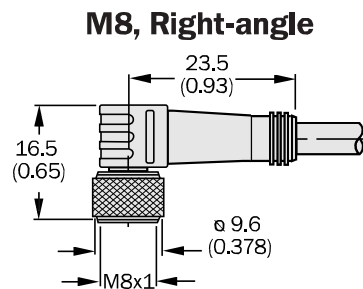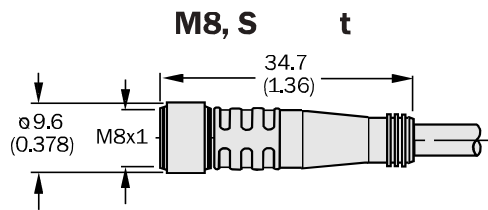

Dimensions in inches (mm)

M12 5-pin AC Cables

Type	Part no.	Notes
KA15-SIM122	7 021 883	Cable, AC, 5-wire M12, straight female, 2 m
KA15-SIM125	7 021 884	Cable, AC, 5-wire M12, straight female, 5 m
KA15-RIM122	7 021 885	Cable, AC, 5-wire M12, right-angle female, 2 m
KA15-RIM125	7 021 886	Cable, AC, 5-wire M12, right-angle female, 5 m

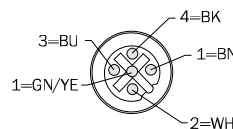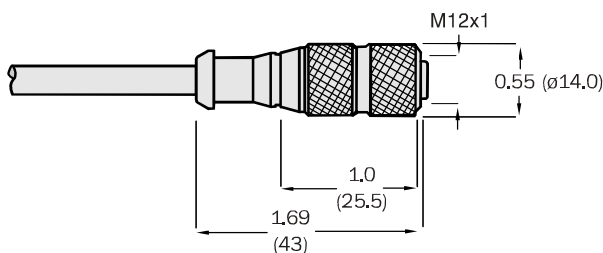

Dimensions in inches (mm)