


Molded Case Circuit Breakers

Panelboard Mounting with INSTA-WIRE

Selection

1-Pole Bolt-On (120V AC)^{①⑤}

Continuous Current Rating @ 40° C	Type BL		Type BLH		Type HBL	
	10,000A IR		22,000A IR		65,000A IR	
	Catalog Number	List Price \$	Catalog Number	List Price \$	Catalog Number	List Price \$
10	B110	33.50	—	—	—	—
15	B115 ^②	33.50	B115H ^②	73.00	B115HH ^②	113.00
20	B120 ^②	33.50	B120H ^②	73.00	B120HH ^②	113.00
25	B125	33.50	B125H	73.00	B125HH■	113.00
30	B130	33.50	B130H	73.00	B130HH	113.00
35	B135	33.50	B135H■	73.00	B135HH■	113.00
40	B140	33.50	B140H	73.00	B140HH	132.00
45	B145■	33.50	B145H■	73.00	B145HH■	132.00
50	B150	33.50	B150H	73.00	B150HH■	132.00
60	B160	33.50	B160H■	73.00	B160HH■	132.00
70	B170	72.00	B170H■	93.00	B170HH■	141.00

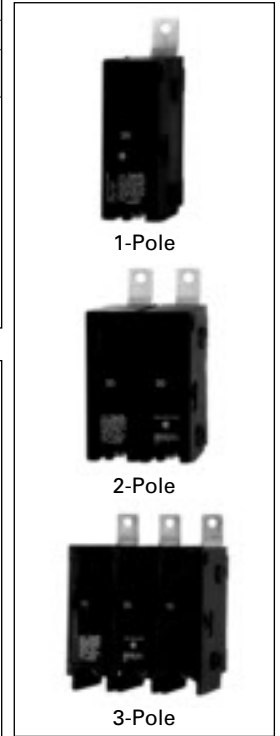


2-Pole Bolt-On (Common-Trip 120/240V AC)^{①⑥}

10	B210	76.00	—	—	—	—
15	B215	76.00	B215H	149.00	B215HH	276.00
20	B220	76.00	B220H	149.00	B220HH	276.00
25	B225	76.00	B225H■	149.00	B225HH■	276.00
30	B230	76.00	B230H	149.00	B230HH	276.00
35	B235	76.00	B235H■	149.00	B235HH■	276.00
40	B240	76.00	B240H	149.00	B240HH	338.00
45	B245	76.00	B245H■	149.00	B245HH■	338.00
50	B250	76.00	B250H	149.00	B250HH	338.00
60	B260	76.00	B260H	149.00	B260HH	338.00
70	B270	149.00	B270H■	229.00	B270HH■	553.00
80	B280	202.00	B280H■	326.00	B280HH■	624.00
90	B290	202.00	B290H■	326.00	B290HH■	624.00
100	B2100	202.00	B2100H	326.00	B2100HH	624.00
110	B2110■	407.00	B2110H■	820.00	B2110HH■	624.00
125	B2125	430.00	B2125H	862.00	B2125HH■	2064.00

2-Pole Bolt-On (Common-Trip 240V AC)^{①③⑥}

15	B215R	202.00	—	—	—	—
20	B220R	202.00	—	—	—	—
30	B230R	202.00	—	—	—	—
40	B240R■	202.00	—	—	—	—
50	B250R	202.00	—	—	—	—
60	B260R	202.00	—	—	—	—
70	B270R■	268.00	—	—	—	—
80	B280R■	306.00	—	—	—	—
90	B290R■	306.00	—	—	—	—
100	B2100R■	306.00	—	—	—	—

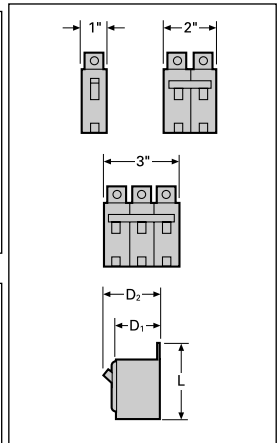

3-Pole Bolt-On (Common-Trip 240V AC)^{①⑦}

10	B310	253.00	—	—	—	—
15	B315	253.00	B315H	381.00	B315HH	479.00
20	B320	253.00	B320H	381.00	B320HH	479.00
25	B325	253.00	B325H	381.00	B325HH■	479.00
30	B330	253.00	B330H	381.00	B330HH	479.00
35	B335	253.00	B335H■	381.00	B335HH■	479.00
40	P340	253.00	B340H	381.00	B340HH	584.00
45	B345	253.00	B345H■	381.00	B345HH■	584.00
50	B350	253.00	B350H	381.00	B350HH	584.00
60	B360	253.00	B360H	381.00	B360HH	584.00
70	B370	311.00	B370H	463.00	B370HH	624.00
80	B380	351.00	B380H■	543.00	B380HH	734.00
90	B390	351.00	B390H■	543.00	B390HH	734.00
100	B3100	351.00	B3100H	543.00	B3100HH	734.00

Breaker Type	Amperes	Dimensions		
		L	D1	D2
BL, BLH	15-50	3 ³ / ₁₆	2 ¹ / ₂	3
BL, BLH	55-125	3 ³ / ₁₆	2 ¹ / ₂	3
HBL	15-125	3 ³ / ₁₆	2 ¹ / ₂	3

MP-T / MP-HT / MP-MT Accessories

Description	Catalog Number	Field/Factory Installed	List Price \$
120V Shunt Trip	add suffix...00S01■	Factory	134.00(adder)
24V Shunt Trip	add suffix...00S07■	Factory	134.00(adder)
120V Auxiliary Switch	add suffix...01■ ^②	Factory	79.00(adder)
1-Pole Padlocking Device	ECPLD1	Field	9.60
2-Pole Padlocking Device	ECPLD2	Field	9.70
3-Pole Padlocking Device	ECQLD3 (bag of 10 pcs.)	Field	93.00
Handle Block	ECHBD1	Field	8.70

Modifications

Description	Catalog Number	List Price \$
400Hz Calibration	add suffix...Y ^⑥	7.50(adder)
415V 50Hz Calibration	add suffix...E ^{⑥⑦}	No adder
Marine 50°C Ambient Calibration	add suffix...M	No adder
Fungus Proofing	add suffix...F	10.00(adder per pole)

■ Built to order. Allow 2-3 weeks for delivery
 ① UL Listed for use with 60/75° wire through 125 amps, HACR rated, 120V AC Fluorescent Lighting.
 ② 1A and 1B contacts.

③ UL Listed for use on 3 phase grounded "B" systems — 10,000 for this application.
 ④ UL Listed for frequent switching applications (SWD).
 ⑤ Shipped 12 per sleeve.
 ⑥ Shipped 6 per sleeve.

⑦ Shipped 4 per sleeve.
 ⑧ UL Listed 5KA IR.
 ⑨ Not UL Listed.
 ⑩ 1 & 2 Poles only.
 ⑪ Contact factory for availability