

Molded Case Circuit Breakers

QJ 225A Frame

Selection/Dimensions

Continuous Current Rating @ 40°C	2-Pole 240V AC Catalog Number	3-Pole 240V AC Catalog Number
----------------------------------	-------------------------------	-------------------------------

Type QJ2^②

Current Rating	2-Pole Catalog Number	3-Pole Catalog Number
60	QJ22B060■	QJ23B060
70	QJ22B070■	QJ23B070
80	QJ22B080■	QJ23B080■
90	QJ22B090■	QJ23B090■
100	QJ22B100	QJ23B100
110	QJ22B110■	QJ23B110
125	QJ22B125	QJ23B125
150	QJ22B150	QJ23B150
175	QJ22B175	QJ23B175
200	QJ22B200	QJ23B200
225	QJ22B225	QJ23B225

Type QJH2^②

Current Rating	2-Pole Catalog Number	3-Pole Catalog Number
60	QJH22B060■	QJH23B060■
70	QJH22B070■	QJH23B070■
80	QJH22B080■	QJH23B080■
90	QJH22B090■	QJH23B090■
100	QJH22B100■	QJH23B100
110	QJH22B110■	QJH23B110
125	QJH22B125	QJH23B125
150	QJH22B150	QJH23B150
175	QJH22B175■	QJH23B175
200	QJH22B200	QJH23B200
225	QJH22B225	QJH23B225

Type QJ2H^②

Current Rating	2-Pole Catalog Number	3-Pole Catalog Number
60	QJ22B060H■	QJ23B060H■
70	QJ22B070H■	QJ23B070H■
80	QJ22B080H■	QJ23B080H■
90	QJ22B090H■	QJ23B090H■
100	QJ22B100H■	QJ23B100H
110	QJ22B110H■	QJ23B110H■
125	QJ22B125H	QJ23B125H
150	QJ22B150H	QJ23B150H
175	QJ22B175H■	QJ23B175H
200	QJ22B200H	QJ23B200H
225	QJ22B225H	QJ23B225H

Type HQJ2^②

Current Rating	2-Pole Catalog Number	3-Pole Catalog Number
100	—	HQJ23B100▲
110	—	HQJ23B110▲
125	—	HQJ23B125▲
150	—	HQJ23B150▲
175	—	HQJ23B175▲
200	—	HQJ23B200▲
225	—	HQJ23B225▲

QJ2

Internal Accessories (Factory installed only) (3-pole only)^③
Add suffix to catalog number.

Control Voltage		Shunt Trip Suffix	Auxiliary Switches		Shunt Trip and 1A and 1B Auxiliary Switch Suffix
AC	DC		1A and 1B Suffix	2A and 2B Suffix	
120/240		00S01■	A01■	A02■	01S01■
	24	00S07■	A01■	A02■	01S07■
	48	00S09■	A01■	A02■	01S09■

■ Built to order. Allow 2–3 weeks for delivery.
▲ Built to order. Allow 6–8 weeks for delivery.
③ See Note: A page 7-81.
Note: QJ breakers are UL Listed for reverse feed applications.

② HACR rated.
③ Internal accessories are not available on 2-pole QJ breakers.

Ordering Information

Load side TA1Q300 lugs are mounted and included when circuit breaker is ordered. For line and load lugs (TA1Q300) installed at no additional charge, add suffix "L" to catalog number.

50°C Calibration - See page 7-91.
400HZ. - See page 7-91.

Shipping Weights

QJ2, QJH2, QJ2H, HQJ2		
Number of Poles	Number per Carton	Shipping Weight (lbs.)
2	10	30
3	10	41

Lugs For 75°C Wire^①


Catalog Number	Lug Body	Lug Wire Range
TA1Q300	Al	(1) #6–300 kcmil Cu (1) #4–300 kcmil Al
TC1Q250	Cu	(1) #6–250 kcmil Cu

Enclosures (Neutral Included)

Type	Catalog Number
1	EB3225(S)(F)
3R (2-pole)	WB2225
3R (3-pole)	WB3225

UL 489 Interrupting Ratings

Breaker Type	RMS Symmetrical Amperes (kA) Volts AC (50/60 Hz)	
	240	208Y/120
QJ2	10	—
QJH2	22	—
QJ2H	42	—
HQJ2	65	100

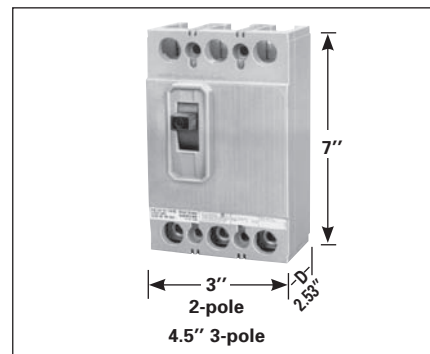

7 MOLDED CASE CIRCUIT BREAKERS

Enclosures Section 6
For external accessories, please refer to pages 7-95 to 7-100