

Circuit Breakers


Lug-In/Lug-Out with INSTA-WIRE

Selection

All BQ/BQH/HBQ circuit breakers are supplied with load side lugs. If line side lugs are required, add suffix "L" to catalog number. Consult Siemens for any additional charge. All standard circuit breakers are calibrated for 40(insert degree symbol)C maximum ambient application.

1-Pole Plug-In (120V AC) ①⑤

Continuous Current Rating @ 40° C	Type BQ		Type BQH		Type HBQ	
	10,000A IR		22,000A IR		65,000A IR	
	Catalog Number	List Price \$	Catalog Number	List Price \$	Catalog Number	List Price \$
10	BQ1B010	33.50	BQ1B010H	—	HB1B010	—
15	BQ1B015 ^②	33.50	BQ1B015H ^②	66.00	HB1B015 ^②	113.00
20	BQ1B020 ^②	33.50	BQ1B020H ^②	66.00	HB1B020 ^②	113.00
25	BQ1B025	33.50	BQ1B025H■	66.00	HB1B025■	113.00
30	BQ1B030	33.50	BQ1B030H	74.00	HB1B030■	113.00
35	BQ1B035■	33.50	BQ1B035H■	74.00	HB1B035■	113.00
40	BQ1B040	33.50	BQ1B040H	74.00	HB1B040■	132.00
45	BQ1B045■	33.50	BQ1B045H■	74.00	HB1B045■	132.00
50	BQ1B050	33.50	BQ1B050H	74.00	HB1B050■	132.00
60	BQ1B060■	33.50	BQ1B060H■	74.00	HB1B060■	132.00
70	BQ1B070■	33.50	BQ1B070H■	92.00	HB1B070■	142.00

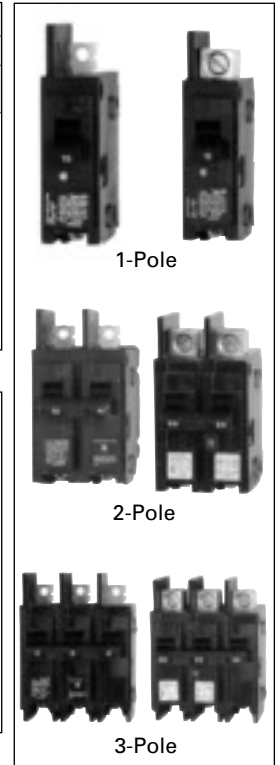

2-Pole Plug-In (Common-Trip 120/240V AC) ①⑥

10	BQ2B010	76.00	—	—	HB2B010■	276.00
15	BQ2B015	76.00	BQ2B015H	149.00	HB2B015■	276.00
20	BQ2B020	76.00	BQ2B020H	149.00	HB2B020■	276.00
25	BQ2B025	76.00	BQ2B025H■	149.00	HB2B025■	276.00
30	BQ2B030	76.00	BQ2B030H	149.00	HB2B030■	276.00
35	BQ2B035	76.00	BQ2B035H■	149.00	HB2B035■	276.00
40	BQ2B040	76.00	BQ2B040H	149.00	HB2B040■	276.00
45	BQ2B045	76.00	BQ2B045H■	149.00	HB2B045■	276.00
50	BQ2B050	76.00	BQ2B050H	149.00	HB2B050■	338.00
60	BQ2B060	76.00	BQ2B060H	149.00	HB2B060■	338.00
70	BQ2B070	149.00	BQ2B070H■	224.00	HB2B070■	552.00
80	BQ2B080	203.00	BQ2B080H■	326.00	HB2B080■	624.00
90	BQ2B090	203.00	BQ2B090H■	326.00	HB2B090■	624.00
100	BQ2B100	203.00	BQ2B100H	326.00	HB2B100■	624.00
110	BQ2B110	407.00	BQ2B110H	864.00	HB2B110■	1794.00
125	BQ2B125	431.00	BQ2B125H	1112.00	HB2B125■	1794.00

2-Pole Plug-In (Common-Trip 240V AC) ①③⑥

15	BQ2H015	203.00	—	—	—	—
20	BQ2H020	203.00	—	—	—	—
30	BQ2H030	203.00	—	—	—	—
40	BQ2H040■	203.00	—	—	—	—
50	BQ2H050	203.00	—	—	—	—
60	BQ2H060	203.00	—	—	—	—
70	BQ2H070■	269.00	—	—	—	—
80	BQ2H080■	306.00	—	—	—	—
90	BQ2H090■	306.00	—	—	—	—
100	BQ2H100■	306.00	—	—	—	—

3-Pole Plug-In (Common-Trip 240V AC) ①⑦

10	BQ3B010	254.00	—	—	HB3B010	480.00
15	BQ3B015	254.00	BQ3B015H	381.00	HB3B015■	480.00
20	BQ3B020	254.00	BQ3B020H	381.00	HB3B020■	480.00
25	BQ3B025■	254.00	BQ3B025H■	381.00	HB3B025■	480.00
30	BQ3B030	254.00	BQ3B030H	381.00	HB3B030■	480.00
35	BQ3B035■	254.00	BQ3B035H	381.00	HB3B035■	480.00
40	BQ3B040	254.00	BQ3B040H	381.00	HB3B040■	584.00
45	BQ3B045■	254.00	BQ3B045H	381.00	HB3B045■	584.00
50	BQ3B050	254.00	BQ3B050H	381.00	HB3B050■	584.00
60	BQ3B060	254.00	BQ3B060H	381.00	HB3B060■	584.00
70	BQ3B070	311.00	BQ3B070H	463.00	HB3B070■	624.00
80	BQ3B080	351.00	BQ3B080H■	543.00	HB3B080■	734.00
90	BQ3B090	351.00	BQ3B090H■	543.00	HB3B090■	734.00
100	BQ3B100	351.00	BQ3B100H	543.00	HB3B100■	734.00

MP-T / MP-HT / MP-MT Accessories

Description	Catalog Number	Field/Factory Installed	List Price \$
120V Shunt Trip	add suffix...00S01■	Factory	141.00(adder)
24V Shunt Trip	add suffix...00S07■	Factory	141.00(adder)
120V Auxiliary Switch	add suffix...01■ ^③	Factory	83.00(adder)
1-Pole Padlocking Device	ECPLD1	Field	10.10
2-Pole Padlocking Device	ECPLD2	Field	10.20
3-Pole Padlocking Device	ECQLD3 (Pkg of 10)	Field	98.00
Handle Block	ECHBD1	Field	9.10

Factory Modifications

Description	Catalog Number	List Price \$
Line Side Lugs	add suffix...L ^{②③}	Consult Siemens
Quick Connect Lug	add suffix...QX	7.50 (adder per pole)
400Hz Calibration	add suffix...Y ^④	8.00 (adder)
415V 50Hz Calibration	add suffix...E ^{②③}	No adder
Marine 50° C Ambient Calibration	add suffix...M	No adder
Fungus Proofing	add suffix...F	10.50 (adder per pole)

① UL Listed for use with 60/75° wire through 125 amps, HACR rated.
 ② 1A and 1B contacts.
 ③ UL Listed for use on 3-phase grounded "B" systems — 10,000 for this application.

④ UL Listed for frequent switching applications (SWD). 120V AC Fluorescent Lighting.
 ⑤ Shipped 12 per sleeve.
 ⑥ Shipped 6 per sleeve.
 ⑦ Shipped 4 per sleeve.

⑧ UL Listed 5KA IR.
 ⑨ Not UL Listed.
 ⑩ 1 & 2 Poles only.

■ Built to order. Allow 2-3 weeks for delivery