


# Enclosed Circuit Breakers

## Enclosures — Type 1

Selection

### Dimensions

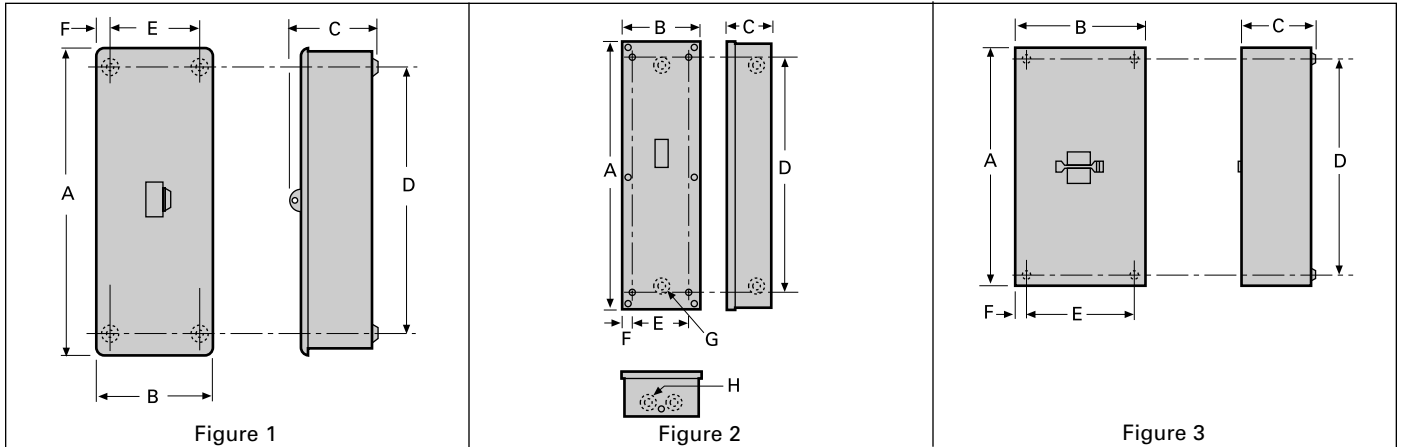

### Type 1

Fig. No.	Breaker Frame	Number of Poles	Maximum Current Rating	Catalog Number	List Price \$ <sup>③</sup>	Weight Lb./Ship. Package	Dimensions (inches)						K.O. Dimensions	
							A	B	C	D	E	F	G	H
1	QP, QPH, HQP	1-2	60	E0204ML1060S <sup>①⑤⑥</sup>	76.00 <sup>②</sup>	16	7 <sup>7</sup> / <sub>8</sub>	5 <sup>5</sup> / <sub>8</sub>	3 <sup>3</sup> / <sub>8</sub>	5 <sup>5</sup> / <sub>8</sub>	3 <sup>3</sup> / <sub>8</sub>	1 <sup>1</sup> / <sub>16</sub>	—	—
1	QP, QPH, HQP	3	100	E0303ML3100S <sup>①⑤⑥</sup>	189.00	8	17 <sup>17</sup> / <sub>8</sub>	7 <sup>7</sup> / <sub>8</sub>	4 <sup>4</sup> / <sub>8</sub>	14 <sup>14</sup> / <sub>8</sub>	4 <sup>4</sup> / <sub>2</sub>	1 <sup>1</sup> / <sub>16</sub>	—	—
1	BQ, BQH, HBQ	3	100	EB3100S <sup>⑤⑥</sup>	189.00 <sup>②</sup>	32	17 <sup>17</sup> / <sub>8</sub>	7 <sup>7</sup> / <sub>8</sub>	4 <sup>4</sup> / <sub>8</sub>	14 <sup>14</sup> / <sub>8</sub>	4 <sup>4</sup> / <sub>2</sub>	1 <sup>1</sup> / <sub>16</sub>	—	—
	NGG	2-3	125	GG0121FN/SN	139.00									
2	ED2, ED4, ED6, HED4	2-3	100	E2N1S <sup>⑤⑥</sup> E2N1F <sup>⑤⑥</sup>	149.00 149.00	8 8	16 <sup>23</sup> / <sub>32</sub> 17 <sup>17</sup> / <sub>2</sub>	7 <sup>7</sup> / <sub>2</sub> 8 <sup>8</sup> / <sub>2</sub>	5 <sup>5</sup> / <sub>16</sub> 5 <sup>5</sup> / <sub>16</sub>	13 <sup>45</sup> / <sub>64</sub> 13 <sup>45</sup> / <sub>64</sub>	5 <sup>5</sup> / <sub>8</sub> 5 <sup>5</sup> / <sub>8</sub>	1 1	7 <sup>7</sup> / <sub>8</sub> , 1 <sup>1</sup> / <sub>8</sub> , 1 <sup>1</sup> / <sub>8</sub>	7 <sup>7</sup> / <sub>8</sub> , 1 <sup>1</sup> / <sub>8</sub> , 1 <sup>1</sup> / <sub>8</sub>
2	ED4, ED6, HED4, CED6	2-3	125	CED6N1S <sup>⑤⑥⑦⑧</sup> CED6N1F <sup>⑤⑥⑦⑧</sup>	271.00 271.00	14 14	21 <sup>15</sup> / <sub>32</sub> 22 <sup>22</sup> / <sub>2</sub>	7 <sup>7</sup> / <sub>32</sub> 8 <sup>8</sup> / <sub>2</sub>	5 <sup>5</sup> / <sub>64</sub> 5 <sup>5</sup> / <sub>64</sub>	18 <sup>18</sup> / <sub>8</sub> 18 <sup>18</sup> / <sub>8</sub>	5 <sup>5</sup> / <sub>8</sub> 5 <sup>5</sup> / <sub>8</sub>	1 1	1 <sup>1</sup> / <sub>2</sub> , 2	1 <sup>1</sup> / <sub>2</sub> , 2
2	FXD6, FD6, FXD6, FD6, HFD6, HFXD6, HHFD6, CFD6	2-3	250	F6N1S <sup>④</sup> F6N1F <sup>④</sup>	184.00 184.00	33	38 <sup>13</sup> / <sub>32</sub>	11 <sup>15</sup> / <sub>32</sub>	5 <sup>5</sup> / <sub>16</sub>	33	8	1 <sup>33</sup> / <sub>64</sub>	1 <sup>1</sup> / <sub>2</sub> , 1 <sup>1</sup> / <sub>2</sub> , 1 <sup>1</sup> / <sub>2</sub> , 2, 2 <sup>1</sup> / <sub>2</sub> , 3	1 <sup>1</sup> / <sub>2</sub> , 1 <sup>1</sup> / <sub>2</sub> , 1 <sup>1</sup> / <sub>2</sub> , 20, 2 <sup>1</sup> / <sub>2</sub> , 3
3	JXD2, JD6, JXD6, HJD6, HJXD6, HHJD6, HHJXD6, SJD6, SHJD6	2-3	400	J6N1 <sup>④</sup>	258.00	120	41 <sup>41</sup> / <sub>16</sub>	22 <sup>27</sup> / <sub>64</sub>	10 <sup>45</sup> / <sub>64</sub>	37	18 <sup>18</sup> / <sub>8</sub>	2 <sup>5</sup> / <sub>16</sub>	—	—
3	LD6, LXD6, HLD6, HLXD6, HHL6, HHLXD6, SLD6, SHLD6, SCJD6, SCLD6, CJD6, CLD6	2-3	600	LD6N1 <sup>④</sup>	449.00	101	46	22 <sup>27</sup> / <sub>64</sub>	10 <sup>45</sup> / <sub>64</sub>	42	18 <sup>18</sup> / <sub>8</sub>	2 <sup>5</sup> / <sub>16</sub>	—	—
3	LMXD6, LMD6, HLMXD6, HLMD6	2-3	800	LMD1 <sup>④</sup>	897.00	202	60	22 <sup>27</sup> / <sub>64</sub>	10	55 <sup>55</sup> / <sub>8</sub>	18 <sup>18</sup> / <sub>8</sub>	2 <sup>5</sup> / <sub>16</sub>	—	—
3	MD6, MXD6, SMD6, HMD6, HMXD6, SHMD6, ND6, NXD6, SND6, HND6, HNXD6, SHND6, CMD6, SCMD6, CND6, SCND6	2-3	1200	MND61 <sup>④</sup>	897.00	202	60	22 <sup>27</sup> / <sub>64</sub>	10	55 <sup>55</sup> / <sub>8</sub>	18 <sup>18</sup> / <sub>8</sub>	2 <sup>5</sup> / <sub>16</sub>	—	—
—	PD6, PXD6, HPD6, HPXD6, CPD6, RD6, SPD6, SHPD6, RXD6, HRD6, HRXD6	3	2000	PRD6N1 <sup>■</sup>	6324.00	350	90	32	28	—	—	—	—	—

For inches / millimeters conversion, see Application Data section.

■ Built to order. Allow 2-3 weeks for delivery.  
CSO - Consult Sales Office for pricing

① Surface mounted, indoor. If flush mounting is required, replace suffix "S" in catalog number with suffix "F".  
Also, if outdoor model required, use prefix "W" instead of "E".

② Discount Schedule B.

③ Does not include circuit breaker. Order circuit breaker separately.

④ Neutral not included. Order as separate item from table on next page.

⑤ Neutral included in enclosure.

⑥ Surface mounted, indoor. If outdoor model is required, use prefix "W" instead of "E". Not available in flush ("F") model.

⑦ Use for 110-125 ampere ED4, ED6, or HED4 circuit breakers.

⑧ Will not accept breaker with shunt trip.

⑨ Will not accept 2-pole GFP or breaker with shunt trip.

⑩ Includes 100% rated breakers.

⑪ Enclosure will accept shunt trip and other internal accessories except GFP.