



Roof Attachment Parts

The parts below are used with the Standard Series 100 Roof Rail for attachment to the roof, structure or building.

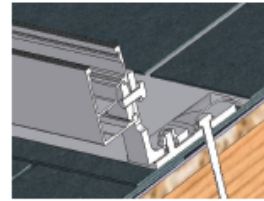

Flashed L-Foot

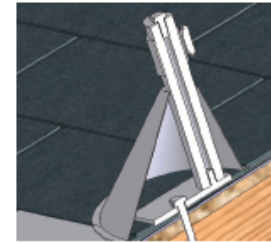

Description	Color	Qty	Application	Item Number
SnapNrack Flashed L-Foot	Clear	1	For Composition shingle roofs	015-11063
SnapNrack Flashed L-Foot	Clear	12	For Composition shingle roofs	015-09975
SnapNrack Flashed L-Foot	Black	1	For Composition shingle roofs	015-09985
SnapNrack Flashed L-Foot	Black	12	For Composition shingle roofs	015-09981
<hr/>				
SnapNrack Standoff kit 1-hole base 5.5"	Black	1	For Tile or built-up type roofs	015-11079
SnapNrack Standoff kit 1-hole base 5.5"	Clear	1	For Tile or built-up type roofs	015-09973
SnapNrack Standoff kit 1-hole base 5.5"	Black	12	For Tile or built-up type roofs	015-09987
SnapNrack Standoff kit 1-hole base 5.5"	Clear	12	For Tile or built-up type roofs	015-09986
SnapNrack Standoff kit 1-hole base 7"	Black	1	For Tile or built-up type roofs	015-09974
SnapNrack Standoff kit 1-hole base 7"	Clear	1	For Tile or built-up type roofs	015-11084
SnapNrack Standoff kit 1-hole base 7"	Black	12	For Tile or built-up type roofs	015-09988
SnapNrack Standoff kit 1-hole base 7"	Clear	12	For Tile or built-up type roofs	015-11083
SnapNrack Standoff kit 4-hole base, 3"	Black	12	For multiple attachment screws	015-11195
SnapNrack Standoff kit 4-hole base, 3"	Clear	12	For multiple attachment screws	015-11196
SnapNrack Standoff kit 4-hole base, 5.5"	Black	12	For multiple attachment screws	015-11197
SnapNrack Standoff kit 4-hole base, 5.5"	Clear	12	For multiple attachment screws	015-11198
SnapNrack Standoff kit 4-hole base, 7"	Black	12	For multiple attachment screws	015-11107
SnapNrack Standoff kit 4-hole base, 7"	Clear	12	For multiple attachment screws	015-11108
SnapNrack Standoff kit HD base 7"	Clear	12	Commercial Grade 2-bolt base	015-09965
SnapNrack Standoff kit HD base 12"	Clear	12	Commercial Grade 2-bolt base	015-09966
SnapNrack Standoff Spacer 1"	Clear	12	For adding 1" height to a standoff	015-09983
SnapNrack Standoff Spacer 1"	Clear	48	For adding 1" height to a standoff	015-11090
<hr/>				
SnapNrack L-foot	Clear	1	92 degree - adjustable	015-09978
SnapNrack L-foot	Clear	12	92 degree - adjustable	015-09977
SnapNrack L-foot with 4-hole base	Clear	12	For multiple attachment screws	015-11115
SnapNrack L-foot	Black	1	92 degree - adjustable	015-09979
SnapNrack L-foot	Black	12	92 degree - adjustable	015-09980
SnapNrack L-foot with 4-hole base	Black	12	For multiple attachment screws	015-11116
<hr/>				
SnapNrack Corrugated Roof Block	Clear	12	Corrugated metal roofs	015-09989
SnapNrack Corrugated Roof Block	Clear	48	Corrugated metal roofs	015-11106




Corrugated Roof Block



92 Deg L-Foot
(Comp Shingle)



Standoff w/4-Hole Base
(Black)

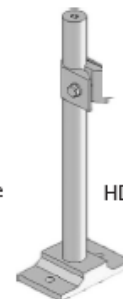

HD Standoff

Key:
Qty - refers to packaged quantity.
Color - refers to the Anodized finish.
Price - is Manufacturer Suggested Retail.