




## RIGID-IMC FITTINGS

### MALLEABLE IRON INSULATED GROUNDING BUSHINGS

Download  
Specification Sheet  
([https://www.sepco-usa.com/wp-content/uploads/2017/03/page\\_055.pdf](https://www.sepco-usa.com/wp-content/uploads/2017/03/page_055.pdf))



Print

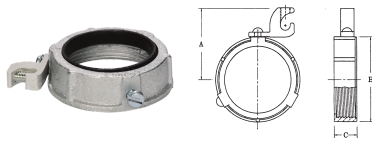

#### 22BI4L

Trade Size	<b>1"</b>
GROUNDING	
LUG CAPACITY	<b>#14 - #4</b>
Dim A	<b>1.63</b>
Dim B	<b>1.76</b>
Dim C	<b>0.72</b>
Unit Pack	<b>25</b>
Master Pack	<b>500</b>
Lbs. / 100 Pcs.	<b>15</b>
UPC	<b>20019</b>
	<b>IB-100L-4,</b>
	<b>383, HGLL3,</b>
	<b>MCBGI-100,</b>
Competitor Part	<b>IBC-100L-</b>
Number	<b>4AC, 1264,</b>
	<b>1261, 1262</b>

**1204, BU-  
803, 3872,  
333M**

**APPLICATION FEATURES**

Used with a locknut to terminate threaded rigid and IMC conduit to a box or enclosure and to provide a smooth pulling surface. Thermoplastic liner prevents damage to wire insulation. Liner rated at 150°C.

The plastic liner won't chip, crack, swell or shrink. It resists corrosion, chemicals, and temperature extremes.

Set-screw provided with each fitting locks bushing in any desired position.

UL Listed for use with Copper or Aluminum Group Conductors.

**STANDARD MATERIALS STANDARD FINISH**

Malleable Iron/Open side tin plated aluminum lug.

Zinc plated  
Optional  
Lug:  
Available with copper  
lug; use suffix  
C instead of

Instead of

L. Example  
20BI4C.

**UL LISTED**

E93683



**OPTIONAL**

**FINISH**

For additional corrosion protection, specify Hot Dipped Galvanized. Add suffix 'G' to Malleable Iron catalog number. Example 20BI4LG. For more information see page 14.