

# Conduit Capped Bushings

For Threaded Rigid Conduit and IMC

**Features:**

- Bushings are supplied with metal cap insert.


**Standard Materials:**

Zinc Die Cast

## Zinc Die Cast - Metal Capped



Type 820Z

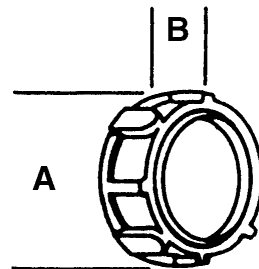


CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100 PCS.	NAED MFG #78-5994 UPC/DCI #
820Z	1/2"	1.15	0.47	100	1000	2	18202
821Z	3/4"	1.41	0.47	100	1000	4	18212
822Z	1"	1.68	0.54	50	500	6	18222
823Z	1-1/4"	1.94	0.60	25	250	9	18232
824Z	1-1/2"	2.20	0.62	25	250	13	18241
825Z	2"	2.80	0.62	-	25	17	18252
838Z	2-1/2"	3.32	0.93	-	25	35	18382
839Z	3"	3.94	0.93	10	100	48	18392
840Z	3-1/2"	4.45	0.94	5	25	57	18402
841Z	4"	5.00	0.97	5	25	81	18412

Also available Zinc Die Cast bushing with paper cap. Please call factory.

## Malleable Iron Bushings - Paper Capped



Type 826

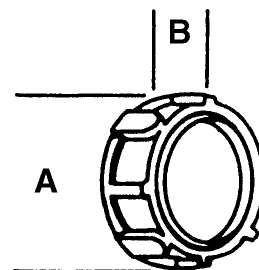

CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100 PCS.	NAED MFG #78-5994 UPC/DCI #
826	1/2"	1.06	0.38	100	1000	3	18261
827	3/4"	1.25	0.44	100	1000	5	18271
828	1"	1.56	0.50	50	500	7	18281
829	1-1/4"	2.00	0.63	25	250	9	18291
830	1-1/2"	2.19	0.63	25	250	13	18301
831	2"	2.63	0.63	-	25	19	18311
832	2-1/2"	3.19	0.75	-	25	35	18321
833	3"	3.81	0.94	-	25	40	18331
834	3-1/2"	4.44	0.94	-	25	50	18341
835	4"	4.94	1.06	-	25	95	18351
836	5"	6.00	1.19	-	10	100	18361
837	6"	7.38	1.31	-	10	110	18371

Also available Malleable Iron bushing with metal cap. Please call factory.

**Standard Materials:**

Malleable Iron

**Standard Finish:**

Zinc Plated