

## ProTac® 1L / ProTac® 2L

### HIGH PERFORMANCE LITHIUM FLASHLIGHT

**MARKET APPLICATIONS:** Law Enforcement, Security, Emergency Medical Services, Sporting Goods, Hardware/Tool, Consumer

**DESCRIPTION:** Compact & powerful, the ProTac® series flashlights offer three different user selectable programs and the latest in power LED technology. The combination of small size and output from the C4® LED result in one of the brightest tactical personal carry lights for its' size. Packaged with a removable pocket clip and holster. (Models also available with AA sized cells.)

**CASE MATERIAL:** 6000 series machined aircraft aluminum with anodized finish. Available in Black.

**DIMENSIONS:**

<b>ProTac® 1L:</b> Length: 3.43 in. (8.71 cm) Head Diameter: 0.90 in. (2.29 cm) Barrel Diameter: 0.77 in. (1.96 cm)	<b>ProTac® 2L:</b> Length: 4.77 in (12.12 cm) Major Diameter: 0.90 in. (2.29 cm) Barrel Diameter: 0.77 in. (1.96 cm)
--	---

**WEIGHT:** **ProTac® 1L:** 2.0 oz (57 grams) with battery\*      **ProTac® 2L:** 2.8 oz (79 grams) with batteries\*

**LENS:** Glass lens, o-ring sealed.

**LIGHT SOURCE:** C4® LED technology, impervious to shock with a 50,000 hour lifetime.

**LIGHT OUTPUT:** See charts for specific model. Optimized electronics provides regulated intensity.

**ON/OFF:** Multi-function, push-button tactical tailswitch. One handed operation of momentary, variable intensity or strobe mode. TEN-TAP™ programmable switch allows user selection of one of three different programs: high/strobe/low (factory default), high only, or low/high.

**RUN TIME:** See charts for specific model. All claims to 10% of initial lumen output.

**BATTERY:** **ProTac® 1L:** One (1) 3 Volt CR123A Lithium battery.    **ProTac® 2L:** Two (2) 3 Volt CR123A Lithium batteries. CR123A batteries have a shelf life of 10 years.

**FEATURES:**












C4® LED technology for extreme brightness.  
 LED Solid State Power Regulation provides maximum light output throughout battery life.  
 IPX7 rated design; waterproof to 1 meter for 30 minutes.  
 2 meter impact resistance tested.  
 TEN-TAP™ programmable switch allows user to select one of three different programs.  
 Anti-roll facecap.  
 Removable pocket clip.  
 Serialized for positive identification.

**WARRANTY:** Streamlight's Limited Lifetime Warranty.

**APPROVALS:** Meets applicable European Community directives. **CE**

**OPTIONAL ACCESSORIES:** Holster.

	ProTac® 1L			ProTac® 2L		
	FL1 STANDARD	HIGH	LOW	FL1 STANDARD	HIGH	LOW
<b>OUTPUT</b>		<b>180</b> LUMENS	<b>12</b> LUMENS		<b>260</b> LUMENS	<b>13</b> LUMENS
<b>RUNTIME</b>		<b>2h</b>	<b>24h</b>		<b>3h</b>	<b>50h</b>
<b>DISTANCE</b>		<b>123m</b>	<b>32m</b>		<b>150m</b>	<b>35m</b>
<b>INTENSITY</b>		<b>3,800cd</b>	<b>250cd</b>		<b>5,600cd</b>	<b>300cd</b>
	<b>1L Strobe Runtime: 4 hours</b>			<b>2L Strobe Runtime: 6 hours</b>		

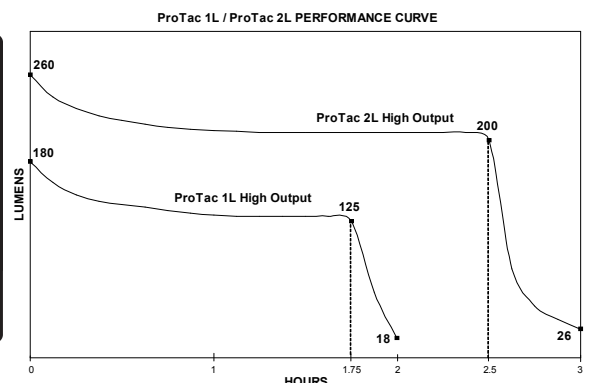

\* Battery(s) included with purchase

All performance claims tested to ANSI/NEMA FL1-2009 Standard

Issued: 12/23/09

Revised: 01/11/13 Rev: 5

Made In China

Document #210