


T6 Circline Compact Fluorescent

- 10,000 Hours average rated lamp life

| Lamp Item # | Description | Lamp Wattage | Incandescent Watts Comparison | Initial Lumens | Diameter (inches) | Length (inches) |
|-------------|----------------|--------------|-------------------------------|----------------|-------------------|-----------------|
| 32018 | T6 Lamp | 18 | 75 | 1200 | 0.75 | 5.75 |
| 32027 | T6 Lamp | 27 | 120 | 2000 | 0.75 | 7.50 |
| 32030T6 | T6 Lamp | 30 | 120 | 2046 | 0.78 | 9.00 |
| 32032 | T6 Lamp | 32 | 130 | 2200 | 0.75 | 9.00 |
| 32033 | T6 Double Lamp | 33 | 125 | 2150 | 1.80 | 5.50 |
| 32040 | T6 Double Lamp | 40 | 150 | 2800 | 0.75 | 7.50 |
| 32058 | T6 Double Lamp | 58 | 200 | 3700 | 0.75 | 9.00 |

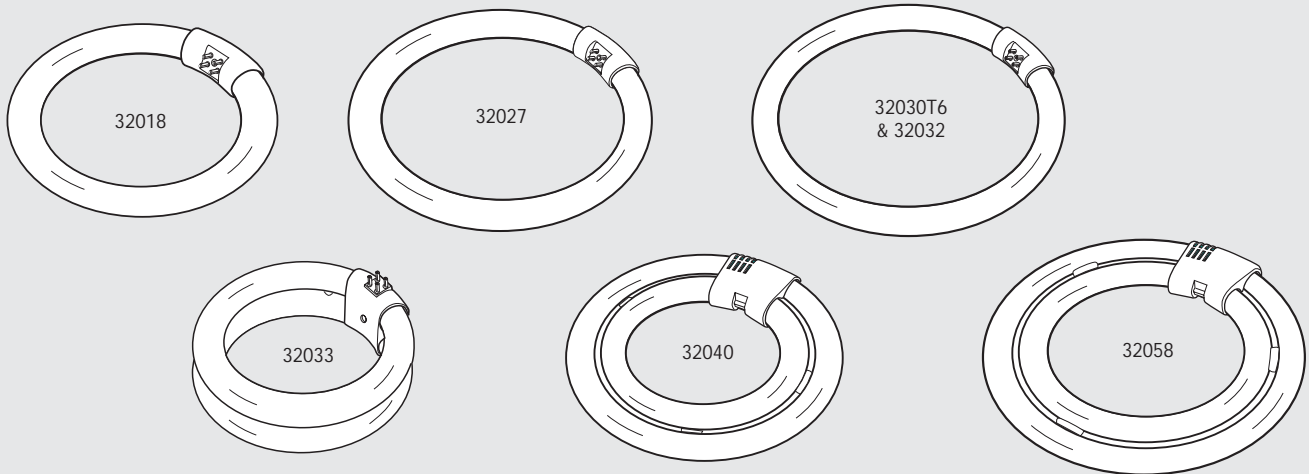

Features and Benefits

- T6 lamps feature smaller diameters with bright light to fit more applications
- Long life, 10,000 hour average rated lamp life
- Lasts 7 years, based on 4 hours use per day
- Lasts 10-13 times longer than similar incandescent
- Replace less often, ideal for hard to reach places
- Lower maintenance and labor costs for lamp replacements
- Saves up to 75% in Energy Costs compared to similar light output incandescent lamps
- 2850°K color temperature closest to incandescent light
- Quick run-up time
- Instant start, flicker free
- World class phosphor insures high lumen output and excellent lumen maintenance

Special Application Options: (Ordering Suffix)

- 3100°K (31K), 3500°K (35K), 4100°K (41K), 5100°K (51K), 6500°K (65K)

Applications:

- Use anywhere a standard incandescent is used.
Perfect for:
Table Lamps, Floor Lamps, Ceiling Fixtures

Specifications (at full brightness)

| | |
|-----------------------------|--------------|
| Input Line Frequency ----- | 50/60HZ |
| Lamp Life (rated) ----- | 10,000 Hours |
| Color Temperature ----- | 2850°K |
| Color Rendering Index ----- | 82 |



ISO 9002
CERTIFIED

12 MONTH
WARRANTY