


NEW! TCP InstaBright G2 covered CFLs

- 8,000 Hours average rated life, 120Volts

Item #	Description	Incandescent Wattage Comparison	Initial Lumens	M.O.L. (inches)	Diameter (inches)	Lamp Life (Hours)
4R2014	14 WATT R20 InstaBright G2	50	410	4.4	2.5	8000
4R3014	★ 14 WATT R30 InstaBright G2	65	650	5.4	3.7	8000
41314	14 WATT A19 InstaBright G2	75	750	4.4	2.4	8000
4G2514	★ 14 WATT G25 InstaBright G2	100	800	4.4	3.1	8000

★ ENERGY STAR®

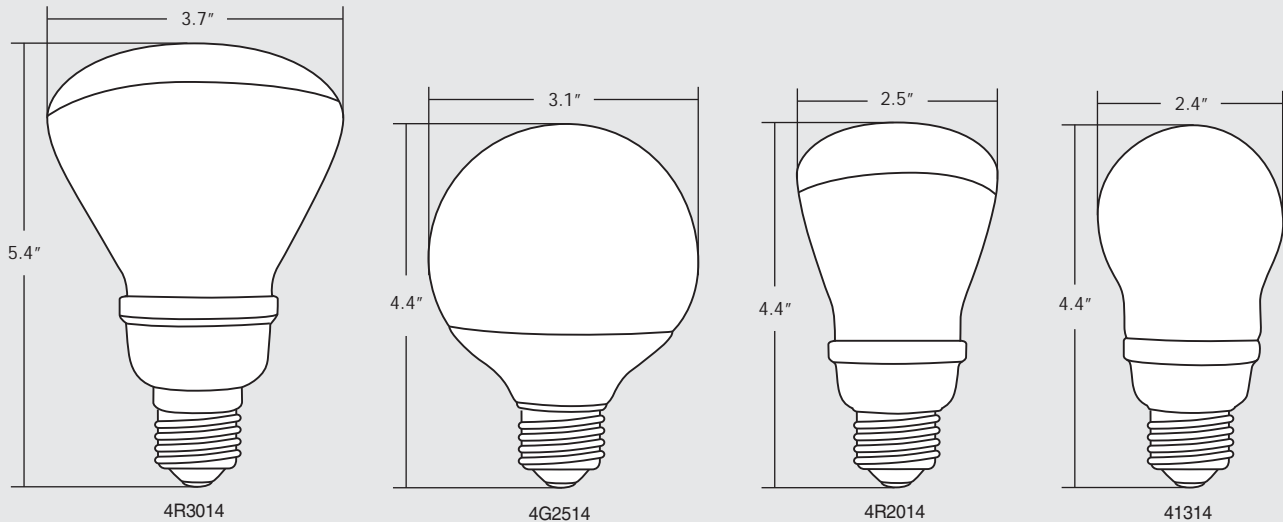

Applications

- Accent and decorative lighting – such as chandeliers, ceiling fans, indoor/outdoor fixtures.
- Ideal for applications with hard to reach areas and small fixtures

Features and Benefits

- Fastest starting covered CFL reaches full brightness in seconds
- Fast run-up time and build-up time, lamps turns on instantly
- Patented technology using amalgam mercury
- RoHS Compliant

Specification

End of Life Protection	Yes
Ballast Type	Electronic
Input Line Voltage:	120VAC
Input Line Frequency	50/60HZ
Lamp Life (Rated)	8,000 hrs
Color Temperature	2700°K
Color Rendering Index	82
Minimum Starting Temp	-20°F
Maximum Operating Temp	160°F
UL/cUL Listed	Yes
Lamp Operating Frequency	45 KHZ
Lamp Current Crest Factor	<1.60
Maximum Open Circuit Voltage	600V
Power Factor	>.50
Total Harmonic Distortion	<150%

12 MONTH
WARRANTY