
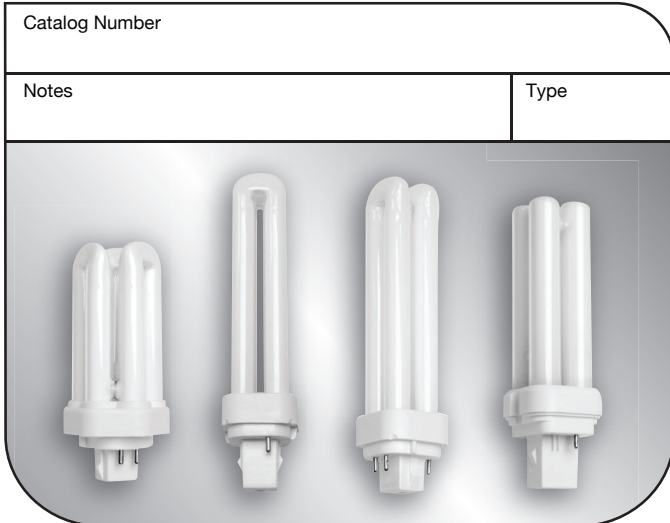
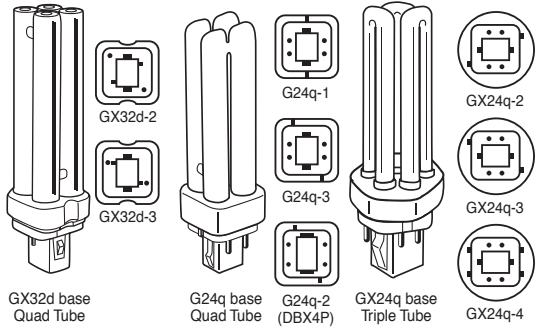


Compact Fluorescent PL Lamp | 10,000 Hours average rated life

Applications:

Perfect for most commercial applications: Use where a standard incandescent is used.

- + Table Lamps
 - + Recessed Downlighting
 - + Outdoor Fixtures
 - + Wall Sconces
 - + Ceiling Fixtures
 - + Ceiling Fans
-
- NOT compatible with dimming applications

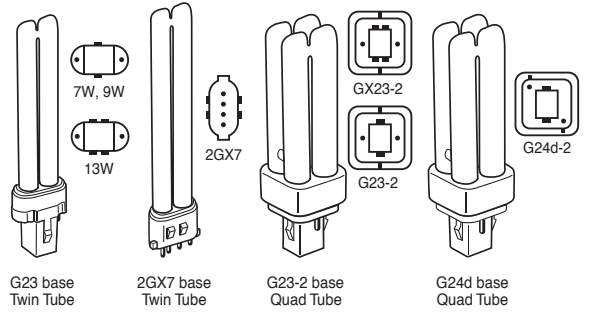

Special Application Options: (Ordering Suffix)

- 2700°K (27K), 3000°K (30K), 3500°K (35K), 4100°K (41K), 5000°K (50K), 6500°K (65K)

Features and Benefits

- Long Life, 10,000 hour average rated life
- Lower maintenance and labor costs for lamp replacements
- Lasts 7 years, based on 3 hours use a day
- Bulb lasts 10-13 times longer than similar incandescent bulbs

Specifications (at full brightness)

Color Temperature 2700° K
 Color Rendering Index 82

Warranties and Certifications:	Item #	Incandescent Wattage Comparison	Description	Base Type	Initial Lumens	M.O.L. (inches)	Diameter (inches)
<p>12 MONTH WARRANTY</p> <p>For the most up-to-date specs, please visit www.tcpi.com</p>	32005	5	Twin Tube, 2-pin	G23	240	3.20	1.20
	32007	7	Twin Tube, 2-pin	G23	380	5.30	1.22
	32009	9	Twin Tube, 2-pin	G23	580	6.50	1.01
	32013	13	Twin Tube, 2-pin	GX23	810	7.00	1.06
	32013IST	13	Twin Tube, 2-pin, Instant Start*	GX23	810	7.00	0.97
	324132GX7	13	Twin Tube, 4-pin	2Gx7	810	6.375	1.26
	32009Q	9	Quad Tube, 2-pin	G23-2	600	4.15	1.34
	32013Q	13	Quad Tube, 2-pin	GX23-2	890	4.66	1.07
	32013ISQ	13	Quad Tube, 2-pin, Instant Start*	GX23-2	890	4.60	1.04
	32018Q	18	Quad Tube, 2-pin	G24d-2	1200	5.96	1.34
	32026Q	26	Quad Tube, 2-pin	G24d-3	1780	6.75	1.34
	32413Q	13	Quad Tube, 4-pin	G24q-1	890	5.08	1.03
	32418Q	18	Quad Tube, 4-pin	G24q-2	1200	5.60	1.02
	32426Q	26	Quad Tube, 4-pin	G24q-3	1780	6.25	1.04
	32020Q	20	Quad Tube, 2-pin	GX32d-2	1250	6.10	1.60
	32027Q	27	Quad Tube, 2-pin	GX32d-3	1600	6.30	1.80
	32413T	13	Triple Tube, 4-pin	GX24q-1	800	4.05	1.85
	32418T	18	Triple Tube, 4-pin	GX24q-2	1200	4.28	1.75
	32426T	26	Triple Tube, 4-pin	GX24q-3	1780	4.87	1.50
	32432T	32	Triple Tube, 4-pin	GX24q-3	2080	5.46	1.47
	32442T	42	Triple Tube, 4-pin	GX24q-4	2730	6.26	1.48

PL Lamp Specifications

Item #	Description	Initial Lumens	CCT	M.O.L. (inches)	Diameter (inches)	Item #	Description	Initial Lumens	CCT	M.O.L. (inches)	Diameter (inches)
32005	5W TWIN TUBE PL LAMP 2 PIN 27K	240	2700	3.20	1.20	324132GX7	13W 4 PIN PL 2GX7 BASE	810	2700	6.375	1.26
3200535K	5W TWIN TUBE PL LAMP 2 PIN-35K	240	3500	3.20	1.20	324132GX730K	13W 4 PIN PL 2GX7 BASE 30K	810	3000	6.375	1.26
3200541K	5W TWIN TUBE PL LAMP 2 PIN-41K	240	4100	3.20	1.20	324132GX735K	13W 4 PIN PL 2GX7 BASE 35K	810	3500	6.375	1.26
3200550K	5W TWIN TUBE PL LAMP 2 PIN-50K	230	5000	3.20	1.20	324132GX741K	13W 4 PIN PL 2GX7 BASE 41K	810	4100	6.375	1.26
						324132GX750K	13W 4 PIN PL 2GX7 BASE 50K	760	5000	6.375	1.26
32007	7W TWIN TUBE PL LAMP 2PIN 27K	380	2700	5.30	1.22	32413Q	13W QUAD LAMP PL 4-PIN	890	2700	5.08	1.03
3200730K	7W TWIN TUBE PL LAMP 2PIN 30K	380	3000	5.30	1.22	32413Q30K	13W QUAD LAMP PL 4-PIN 30K	890	3000	5.08	1.03
3200735K	7W TWIN TUBE PL LAMP 2PIN 35K	380	3500	5.30	1.22	32413Q35K	13W QUAD LAMP PL 4-PIN 35K	890	3500	5.08	1.03
3200741K	7W TWIN TUBE PL LAMP 2PIN 41K	380	4100	5.30	1.22	32413Q41K	13W QUAD LAMP PL 4-PIN 41K	890	4100	5.08	1.03
3200750K	7W TWIN TUBE PL LAMP 2PIN 50K	350	5000	5.30	1.22	32413Q50K	13W QUAD LAMP PL 4-PIN 50K	840	5000	5.08	1.03
32009	9W TWIN TUBE PL LAMP 27K	580	2700	6.50	1.01	32413T	13W TRIPLE LAMP PL 4-PIN 27K	800	2700	4.05	1.85
3200935K	9W TWIN TUBE PL LAMP 35K	580	3500	6.50	1.01	32413T35K	13W TRIPLE LAMP PL 4-PIN 35K	800	3500	4.05	1.85
3200941K	9W TWIN TUBE PL LAMP 41K	580	4100	6.50	1.01	32413T41K	13W TRIPLE LAMP PL 4-PIN 41K	800	4100	4.05	1.85
3200950K	9W TWIN TUBE PL LAMP 50K	540	5000	6.50	1.01						
32009Q	9W QUAD PL LAMP 2-PIN 9DTT 27K	600	2700	4.15	1.34	32418Q	18W QUAD LAMP PL 4-PIN	1200	2700	5.60	1.02
32009Q41K	9W QUAD PL LAMP 2-PIN 41K	600	4100	4.15	1.34	32418Q30K	18W QUAD LAMP PL 4-PIN 30K	1200	3000	5.60	1.02
32013	13W TWIN TUBE PL LMP 2-PIN 27K	810	2700	7.00	1.06	32418Q35K	18W QUAD LAMP PL 4-PIN 35K	1200	3500	5.60	1.02
3201330K	13W TWIN TUBE PL LMP 2-PIN 30K	810	3000	7.00	1.06	32418Q41K	18W QUAD LAMP PL 4-PIN 41K	1200	4100	5.60	1.02
3201335K	13W TWIN TUBE PL LMP 2-PIN-35K	810	3500	7.00	1.06	32418Q50K	18W QUAD LAMP PL 4-PIN 50K	1140	5000	5.60	1.02
3201341K	13W TWIN TUBE 41K	810	4100	7.00	1.06						
3201350K	13W TWIN TUBE PL LMP 2-PIN 50K	760	5000	7.00	1.06	32418T	18W TRIPLE LAMP PL 4-PIN 27K	1200	2700	4.28	1.75
3201365K	13W TWIN TUBE PL LMP 2-PIN 65K	760	6500	7.00	1.06	32418T30K	18W TRIPLE LAMP PL 4-PIN 30K	1200	3000	4.28	1.75
32013ISQ	13W INSTANT START QUAD LAMP	890	2700	4.60	1.04	32418T35K	18W TRIPLE LAMP PL 4-PIN 35K	1200	3500	4.28	1.75
32013ISQ35K	13W INSTANT START QUAD LMP 35K	890	3500	4.60	1.04	32418T41K	18W TRIPLE LAMP PL 4-PIN 41K	1200	4100	4.28	1.75
32013ISQ41K	13W INSTANT START QUAD LMP 41K	890	4100	4.60	1.04						
32013IST	13W TWIN TUBE INSTNT START 27K	810	2700	7.00	0.97	32426Q	26W QUAD LAMP PL 4-PIN	1780	2700	6.25	1.04
32013IST35K	13W TWIN TUBE INSTNT START 35K	810	3500	7.00	0.97	32426Q30K	26W QUAD LAMP PL 4-PIN 30K	1780	3000	6.25	1.04
32013IST41K	13W TWIN TUBE INSTNT START 41K	810	4100	7.00	0.97	32426Q35K	26W QUAD LAMP PL 4-PIN 35K	1780	3500	6.25	1.04
						32426Q41K	26W QUAD LAMP PL 4-PIN 41K	1780	4100	6.25	1.04
						32426Q50K	26W QUAD LAMP PL 4-PIN 50K	1680	5000	6.25	1.04
32013Q	13W QUAD PL LAMP 2-PIN 13DTT	890	2700	4.66	1.07	32426T	26W TRIPLE LAMP PL 4-PIN 27K	1780	2700	4.87	1.50
32013Q30K	13WQUAD PL LMP 2-PIN 13DTT-30K	890	3000	4.66	1.07	32426T30K	26W TRIPLE LAMP PL 4-PIN 30K	1780	3000	4.87	1.50
32013Q35K	13WQUAD PL LMP 2-PIN 13DTT-35K	890	3500	4.66	1.07	32426T35K	26W TRIPLE LAMP PL 4-PIN 35K	1780	3500	4.87	1.50
32013Q41K	13WQUAD PL LMP 2-PIN 41K	890	4100	4.66	1.07	32426T41K	26W TRIPLE LAMP PL 4-PIN 41K	1780	4100	4.87	1.50
32013Q50K	13WQUAD PL LMP 2-PIN 50K	840	5000	4.66	1.07	32426T50K	26W TRIPLE LAMP PL 4-PIN 50K	1680	5000	4.87	1.50
32018Q	18W QUAD PL LMP-2700K	1200	2700	5.96	1.34	32432T	32W TRIPLE LAMP PL 4-PIN 27K	2080	2700	5.46	1.47
32018Q30K	18W QUAD PL LMP 30K	1200	3000	5.96	1.34	32432T30K	32W TRIPLE LAMP PL 4-PIN 30K	2080	3000	5.46	1.47
32018Q35K	18W QUAD PL LMP-35K	1200	3500	5.96	1.34	32432T35K	32W TRIPLE LAMP PL 4-PIN 35K	2080	3500	5.46	1.47
32018Q41K	18W QUAD PL LMP-41K	1200	4100	5.96	1.34	32432T41K	32W TRIPLE LAMP PL 4-PIN 41K	2080	4100	5.46	1.47
32018Q50K	18W QUAD PL LMP-50K	1120	5000	5.96	1.34	32432T50K	32W TRIPLE LAMP PL 4-PIN 50K	1930	5000	5.46	1.47
						32432T65K	32W TRIPLE LAMP PL 4-PIN 65K	1930	6500	5.46	1.47
32020Q	20W QUAD PL LMP	1250	2700	6.10	1.60	32442T	42W TRIPLE LAMP PL 4-PIN 27K	2730	2700	6.26	1.48
32020Q50K	20W QUAD PL LMP-50K	1150	5000	6.10	1.60	32442T30K	42W TRIPLE LAMP PL 4-PIN 30K	2730	3000	6.26	1.48
32026Q	26W QUAD PL LMP-27K	1780	2700	6.75	1.34	32442T35K	42W TRIPLE LAMP PL 4-PIN 35K	2730	3500	6.26	1.48
32026Q30K	26W QUAD PL LMP-30K	1780	3000	6.75	1.34	32442T41K	42W TRIPLE LAMP PL 4-PIN 41K	2730	4100	6.26	1.48
32026Q35K	26W QUAD PL LMP-35K	1780	3500	6.75	1.34	32442T50K	42W TRIPLE LAMP PL 4-PIN 50K	2540	5000	6.26	1.48
32026Q41K	26W QUAD PL LMP-41K	1780	4100	6.75	1.34	32442T65K	42W 4PIN TRIPLE TUBE PL 65K	2540	6500	6.26	1.48
32026Q50K	26W QUAD PL LMP-50K	1680	5000	6.75	1.34						
32027Q	20W 2PIN QUAD PL GX32D-3	1600	2700	6.30	1.80						
32027Q41K	20W 2PIN QUAD PL GX32D-3 41K	1600	4100	6.30	1.80						
32027Q50K	20W 2PIN QUAD PL GX32D-3 50K	1600	5000	6.30	1.80						

For the most up-to-date specs, please visit www.tcp.com

TCP, Inc.
325 Campus Dr. | Aurora, Ohio 44202 | P: 1-800-324-1496 | F: 330-995-6188 | tcp.com

©TCP, Inc. JULY 2013/50577

12 MONTH WARRANTY

