



PRO

LED Dimmable BR40, BR30 and R20 Lamps

LED

25,000 Hours average rated life, 120 Volts

Applications:


Ideal for dimmable BR40, BR30, AND R20 flood and spot light applications.

- + Recessed Downlights
- + Track Lights
- + Display Lights
- + Outdoor Fixtures That Protect From Elements




Features and Benefits

- 65W & 85W BR30/BR40 & 50W R20 replacement.
- Exceeds all industry standards – submitted for ENERGY STAR testing .
- Smooth, uniform dimming from 100% - 0.5%.
- Highly efficient LEDs and Driver.
- Long Life: 25,000 hours.
- Consistent color within 3 MacAdam ellipse tolerance.
- UL approved for damp locations.

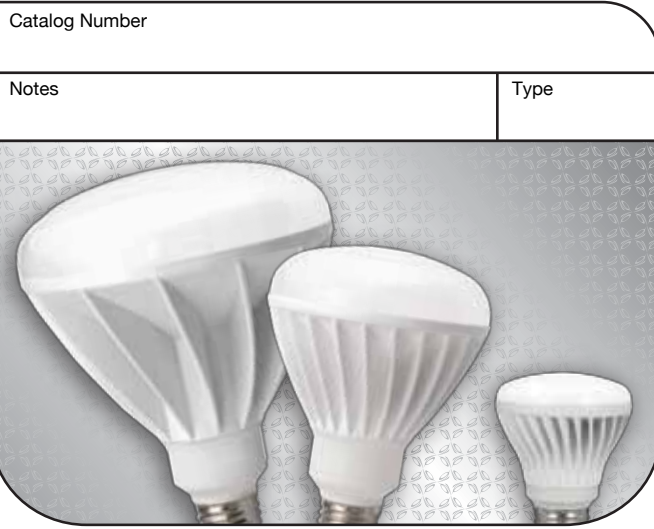

Specifications

Input Line Voltage:	120 VAC
Input Power	See Chart
Input Line Frequency	50/60HZ
Lamp Life (Rated)	25,000 hrs
Minimum Starting Temp	-20°C
Maximum Operating Temp	40°C
CRI	85

Warranties and Certifications:	Item #	Description	Voltage	Wattage	Lumens	LPW	M.O.L. (inches)	Diameter (inches)	CCT	CRI	Case Quantity	STK/MTO
 5 YEAR WARRANTY*	BR40											
	LED11E26BR4027K	LED 11W BR40 Flood	120	11	650	59.1	6.6	5.0	2700	85	12	STK
	LED14E26BR4027K	LED 14W BR40 Flood	120	14	850	60.7	6.6	5.0	2700	85	12	STK
	BR30											
	LED11E26BR3027K	LED 11W BR30 Flood	120	11	650	59.1	5.4	3.8	2700	85	12	STK
	LED14E26BR3027K	LED 14W BR30 Flood	120	14	850	60.7	5.4	3.8	2700	85	12	STK
	BR20											
	LED9E26R2027K	LED 9W BR20 Flood	120	9	450	50.0	3.5	2.5	2700	85	12	STK

*Based on 12 hours use per day





PRO

LED Dimmable BR40, BR30 and R20 Lamps

MTO = Made to Order -- 1 to 2 week delivery. Case quantities only.

Color Temperatures	Item #	Description	Voltage	Wattage	Lumens	LPW	M.O.L. (inches)	Diameter (inches)	CCT	CRI	Case Quantity	STK/MTO
2700K Warm ← 2700K → Cool	BR40											
	LED11E26BR4027K	LED 11W BR40 Flood	120	11	650	59.1	6.6	5.0	2700	85	12	STK
	LED14E26BR4027K	LED 14W BR40 Flood	120	14	850	60.7	6.6	5.0	2700	85	12	STK
	BR30											
	LED11E26BR3027K	LED 11W BR30 Flood	120	11	650	59.1	5.4	3.8	2700	85	12	STK
	LED14E26BR3027K	LED 14W BR30 Flood	120	14	850	60.7	5.4	3.8	2700	85	12	STK
	BR20											
	LED9E26R2027K	LED 9W BR20 Flood	120	9	450	50.0	3.5	2.5	2700	85	12	STK
	4100K Warm ← 4100K → Cool	BR40										
LED11E26BR4041K		LED 11W BR40 Flood	120	11	685	62.3	6.6	5.0	4100	85	12	STK
LED14E26BR4041K		LED 14W BR40 Flood	120	14	900	64.3	6.6	5.0	4100	85	12	STK
BR30												
LED11E26BR3041K		LED 11W BR30 Flood	120	11	685	62.3	5.4	3.8	4100	85	12	STK
LED14E26BR3041K		LED 14W BR30 Flood	120	14	900	64.3	5.4	3.8	4100	85	12	STK
BR20												
LED9E26R2041K		LED 9W BR20 Flood	120	9	475	52.8	3.5	2.5	4100	85	12	STK

COMING SOON!

Color Lenses



Pink Lens												
LED14E26BR40PNK	LED 11W BR40 Flood	120	14	TBD	TBD	6.6	5.0	Pink	TBD	12	MTO	
LED14E26BR30PNK	LED 14W BR30 Flood	120	14	900	64.3	5.4	3.8	Pink	85	12	MTO	
Blue Lens												
LED14E26BR40BL	LED 11W BR40 Flood	120	14	TBD	TBD	6.6	5.0	Blue	TBD	12	MTO	
LED14E26BR30BL	LED 14W BR30 Flood	120	14	TBD	TBD	5.4	3.8	Blue	TBD	12	MTO	
Green Lens												
LED14E26BR40GR	LED 11W BR40 Flood	120	14	TBD	TBD	6.6	5.0	Green	TBD	12	MTO	
LED14E26BR30GR	LED 14W BR30 Flood	120	14	TBD	TBD	5.4	3.8	Green	TBD	12	MTO	
Red Lens												
LED14E26BR40RD	LED 11W BR40 Flood	120	14	TBD	TBD	6.6	5.0	Red	TBD	12	MTO	
LED14E26BR30RD	LED 14W BR30 Flood	120	14	TBD	TBD	5.4	3.8	Red	TBD	12	MTO	

