


# LOADING DOCK LIGHTS - FULLY ASSEMBLED

Incandescent • Quartz Halogen • High Pressure Sodium • Metal Halide



24" Arm

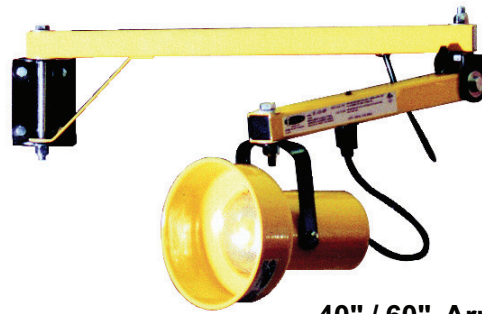

40" / 60" Arm (VA) with Vertical Adjustment Joint

Arms constructed of yellow powder coated, 14 gauge steel tubing.

Cordset consists of 5' of 18/3 SJTW cord and NEMA 5-15 plug.

3" x 5"x 3/16" steel mounting plate accepts 3/8" hardware.

On "VA" arm units, outer arm swings 300° in horizontal plane & 210° in vertical plane.

## INCANDESCENT



UPC CODE	MODEL	ARM LENGTH	WATTS	VOLTS	MAX LUMENS	AVE BULB LIFE (HRS)	ON / OFF SWITCH	BULB INCLUDED	GUARD INCLUDED	SHIPPING WT. (LBS.)
686334	DKL-24-A	24"	300	120	3,700	2,000	YES	NO	NO	10
446648	DKL-40VA-A	40"								14
446662	DKL-60VA-A	60"								17

## QUARTZ HALOGEN



UPC CODE	MODEL	ARM LENGTH	WATTS	VOLTS	MAX LUMENS	AVE BULB LIFE (HRS)	ON / OFF SWITCH	BULB INCLUDED	GUARD INCLUDED	SHIPPING WT. (LBS.)
446709	DKL-24-QH-A	24"	500	120	11,000	2,000	NO	YES	YES	16
446716	DKL-40VA-QH-A	40"								21
446723	DKL-60VA-QH-A	60"								24

## HIGH PRESSURE SODIUM



UPC CODE	MODEL	ARM LENGTH	WATTS	VOLTS	MAX LUMENS	AVE BULB LIFE (HRS)	ON / OFF SWITCH	BULB INCLUDED	GUARD INCLUDED	SHIPPING WT. (LBS.)
446679	DKL-24-HPS-A	24"	50	120	4,000	24,000	YES	YES	NO	12
446686	DKL-40VA-HPS-A	40"								16
446693	DKL-60VA-HPS-A	60"								20

## METAL HALIDE



UPC CODE	MODEL	ARM LENGTH	WATTS	VOLTS	MAX LUMENS	AVE BULB LIFE (HRS)	ON / OFF SWITCH	BULB INCLUDED	GUARD INCLUDED	SHIPPING WT. (LBS.)
385190	DKL-24-MH	24"	100	120	9,000	15,000	NO	YES	YES	21
385206	DKL-40VA-MH	40"								26
385213	DKL-60VA-MH	60"								31