

RETROFIT/REFIT KITS

Retrofit Reflector kit for Parabolics & Troffers




Increased light output with greater energy efficiency for Parabolics or Troffers. Kit includes socket bracket, reflector, tek screws and lamp holders. Consult factory to add lamps and ballasts to the kit.

ITEM NO.	SIZE (L x W x H)	LAMPING
24P32M20BL10	2 x 4 Parabolic Retrofit Kit	2-F32T8
24P32W10BL10	2 x 4 Parabolic Retrofit Kit	2-F32T8
24C2M20BL10	2 x 4 Troffer Retrofit Kit	2-F32T8
24C2W10BL10	2 x 4 Troffer Retrofit Kit	2-F32T8
22C2M20BL10	2 x 2 Troffer Retrofit Kit	2-F17T8
22C2W10BL10	2 x 2 Troffer Retrofit Kit	2F17T8

L10 is for Short, shunted, snap fit lamp holders (For IS ballasts)
Change to L11 for short, unshunted, snap fit (for RS and ProStart ballasts).
M20 is mirrored reflector and W10 is enhanced white aluminum reflector.

Universal Strip Retrofit Kit w/Reflector

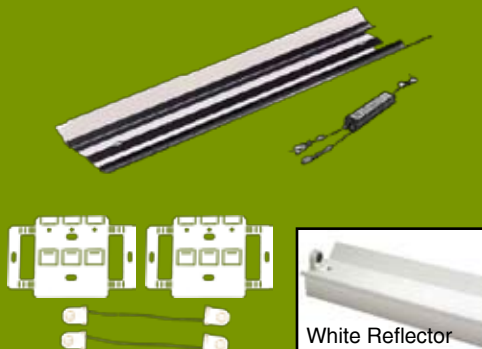


The SRK Universal Retrofit Kit is designed for 4' or 8' fluorescent industrial and strip fixtures and installs with simple hand tools. The universal socket bracket is designed for simple fit up to most standard fluorescent channels from 4 1/4" to 5 1/4" in width. The reflector mounts to final wired socket brackets with 2 quarter-turn fasteners for easy maintenance after retrofit is complete. The SRK strip retrofit kit serves as the ballast cover. Mount and connect new ballast to the sockets. Choice of precision formed, high performance, premium mirrored specular reflector (M20) or enhance white reflector (W10). Choice of ballasts.

ITEM NO.	SIZE (L x W x H)	LAMPING
SKR4232M20MV	48" x 9.25" x 2.4"	2-F32T8
SKR4232W10MV	48" x 9.25" x 2.4"	2-F32T8
SKR82328M20MV	96" x 9.25" x 2.4"	4-F32T8
SKR82328WHOMV	96" x 9.25" x 2.4"	4-F32T8

Change lamp count and lamp type as needed. Change ballast as required - see page 44, for all ballast options.

Ballast Cover Refit Kit

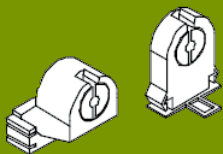

T5 style lamp holder converts 48in body to correct length for T5 lamp

T8 style lamp holder shown on right.

Convert an existing strip to utilize more energy efficient T8 or T5 lamps. Kit includes ballast cover with lampholder cut outs, ballast mounting plate, lampholders as specified and eight or twelve #8x3/8" TEK mounting screws. Ballasts sold separately.

ITEM NO.	SIZE (L x W x H)	LAMPING
48" SERIES		
4RB421T8L10	48" x 4.25"	1-F32T8
4RB501T8L10	48" x 5.0"	1-F32T8
4RB421T5L10	48" x 4.25"	1-F54T5HO
4RB501T5L10	48" x 5.0"	1-F54T5HO
4RB422T8L10	48" x 4.25"	2-F32T8
4RB502T8L10	48" x 5.0"	2-F32T8
4RB422T5L10	48" x 4.25"	2-F54T5HO
4RB502T5L10	48" x 5.0"	2-F54T5HO
96" SERIES (Tandem kits**)		
8RB421X2T8L10	96" x 4.25"	2-F32T8
8RB501X2T8L10	96" x 5.0"	2-F32T8
8RB421X2T5L10	96" x 4.25"	2-F54T5HO
8RB501X2T5L10	96" x 5.0"	2-F54T5HO
8RB422X2T8L10	96" x 4.25"	4-F32T8
8RB502X2T8L10	96" x 5.0"	4-F32T8
8RB422X2T5L10	96" x 4.25"	4-F54T5HO
8RB502X2T5L10	96" x 5.0"	4-F54T5HO

L10 is shunted Lampholders suitable for Instant Start ballasts. Change to L11 for un-shunted lampholders for Rapid or Pro Start ballasts. Note: Most T5 and T5HO ballasts are Rapid or Pro Start.

** One lamp in cross section is (1x2) is 2 lamps total. Two lamps in cross section (2x2) are 4 lamps total.

Retrofit Doorframe Kit



Sturdy Steel frame is installed onto a standard inverted tee system to replace missing, damaged or mismatched luminaire door frames.

ITEM NO.	SIZE (L x W x H)
FL-RGA-2X2-RETRO	23 3/4" X 23 3/4" Doors and Lens
FL-RGA-2X4-RETRO	23 3/4" X 47 3/4" Doors and Lens

Standard with A12 .10 Acrylic Lens "A". For other lens options see page 48.