



SEARCH Sut

[Supplier Center](#) [Distributor Center](#)

BROWSE PRODUCTS

Category: | Brand:


PRODUCTS

- [Bending](#)
- [Bolt Cutters](#)
- [Cable Termination](#)
- [CATV/Broadband Instruments](#)
- [Connectors](#)
- [Electric Test Instruments](#)
- [Fasteners](#)
- [Fiber Connections](#)
- [Fiber Optic Instruments](#)
- [Fishing](#)
- [Hydraulic Tools](#)
- [Knockouts](#)
- [Material Handling](#)
- [Power Tool Accessories](#)
- [Power Tools](#)
- [Professional Hand Tools](#)
- [Pulling](#)
- [Storage](#)
- [Telco Instruments](#)
- [VDV Instruments](#)
- [VDV Termination](#)
- [VDV Tools](#)
- [Wire Termination](#)

[Fishing](#) > [Fish Tapes](#) > [Steel Fish Tapes](#) > FISHTAPE,STEEL-125'

FISHTAPE,STEEL-125'

[Images](#)

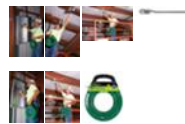

[SAVE PRODUCT TO PDF](#)

Related Products

 Image Unavailable



User Reviews
[\(No Reviews Yet.\)](#)

Cat No: **FTS438-125** UPC No: **783310127093**

[Where to Buy ▶](#)

- [Description](#)
- [Specifications](#)
- [Reviews](#)

- Accessory : R438B Swivel Ball Head for use on 1/8 IN Steel Fish Tapes, R438-BM Ball Tip Male Half, 439-1 12 IN (305 MM) Flexible Fish Tape Leader, 439-2 12 IN (305 MM) SPEED FLEX Leader (solder joints)
- Application : For Excellent Fishing Performance
- Length : 125.000 FT (38.100 M)
- Material : Steel
- Replacement Part : RS438-125 Replacement Steel Tape - 125 FT (NO CASE), 10051 8-1/2 IN Case/Handle Replacement Kit, 10052 12 IN Case/Handle Replacement Kit
- Sub Brand : MagnumPRO
- Tensile Strength : 400.000 LB (1.700 KN) MaximumDesign Strength
- Weight : 5.500 LB (2.500 KG)
- Width : 1/8 IN (3.200 MM)



GREENLEE.

Copyright © 2013 Greenlee Textron Inc., a subsidiary of Textron Inc. All rights reserved. | Powered by the Precis E-business Platform™