

Weatherproof Lampholders

Lampholders, Die-Cast Zinc Zamak 3



CAT. NO.	COLOR	LAMP MAX.	DESCRIPTION
Standard			
L-80	Silver	150W • PAR 38 or R40	Inside Gasket and Ground Screw
WHUP-1	Natural	150W • PAR 38 or R40	Inside Gasket and Ground Screw
D-PAK®			
DL-80	Silver	—	—
DL-80-BR	Bronze	—	—
DL-80-WH	White	—	—
Gasketed			
L-80-D	Silver	150W • PAR 38 or R40	Heavy-Duty Slip-On Gasket and Ground Screw
Deep-Shielded			
L-800	—	150W • PAR 38 or R40	Inside Gasket and Ground Screw
Wireguard			
LG-80	—	—	Mounts to L-80 Series Lampholder

Decorative Floodlight



CAT. NO.	COLOR	LAMP MAX.	DESCRIPTION
2L80D2	White	150W • PAR 38	Two Lampholders Round Cover, or R40 Inside Ground Screws
D-PAK®			
D2L80S3	Silver	—	—

Spike Lights

Portable Mount


For use with 150-Watt Lamp

- Lampholders are heavy-duty die-cast construction
- Lampholders have powder-coat green finish
- Current-carrying components are copper or copper alloy and sockets are porcelain
- Factory wired

CAT. NO.	DESCRIPTION	STD. CTN.
B660GR	Spike Light with 6' Cord	16

UL Listed E-42680.

Portable Spotlights

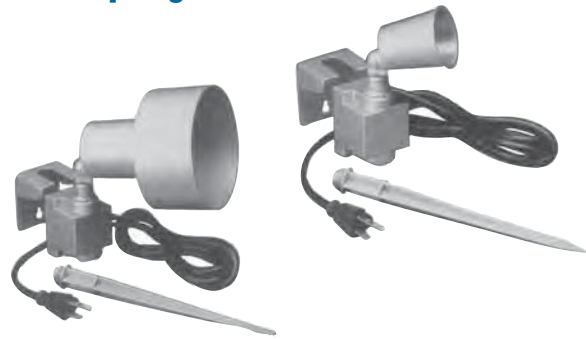

CAT. NO.	COLOR	LAMP MAX.	DESCRIPTION
K702	Silver	150W • PAR 38 or R40	Standard Lampholder, Ground Spike, Wall Bracket, Gasket and Screws
K780	Silver	150W • PAR 38 or R40	Deep-Shielded Lampholder, Ground Spike, Wall Bracket, Gasket and Screws
K780BR	Bronze	150W • PAR 38 or R40	Standard Lampholder, Ground Spike, Wall Bracket, Gasket and Screws

redodot® and Carlon® Weatherproof Boxes, Covers and Conduit Bodies