


Ground Rod Clamps and Accessories

Type GUV — U-Bolt Clamps

Grounding

- Listed for direct burial
- For connecting copper or copper clad steel grounding conductor to ground rod or pipe
- Excellent for connecting multiple electrodes with a single cable as in substation grounding
- All components are cast or forged from copper alloy
- Specially designed spacer provides proper alignment between cable and electrode and affords more positive contact area

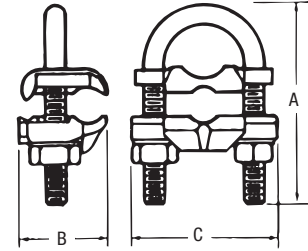

Cat. No.	Conductor Range (CU)		Nominal Rod Size (in.)		IPS Pipe Size (in.)		Dimensions (in.)		
	max.	min.	max.	min.	max.	min.	A	B	C
GUV584	4	8	3/4	5/8	3/8	—	2-13/16	1-9/16	2-1/4
GUV5821	2/0	4	3/4	5/8	3/8	—	2-13/16	1-9/16	2-1/4
GUV5825	250	2/0	3/4	5/8	3/8	—	2-13/16	1-9/16	2-1/4
GUV784	4	8	1	7/8	3/4	1/2	2-3/4	1-9/16	2-5/8
GUV7821	2/0	4	1	7/8	3/4	1/2	2-3/4	1-9/16	2-5/8
GUV7825	250	2/0	1	7/8	3/4	1/2	2-3/4	1-9/16	2-5/8
GUV1184	4	8	1-1/4	1-1/8	1	—	3-5/16	1-9/16	2-3/4
GUV11821	2/0	4	1-1/4	1-1/8	1	—	3-5/16	1-9/16	2-3/4
GUV1384	4	8	1-1/2	1-3/8	1-1/4	—	3-7/16	1-9/16	2-15/16
GUV13821	2/0	4	1-1/2	1-3/8	1-1/4	—	3-7/16	1-9/16	2-15/16
GUV13825	250	2/0	1-1/2	1-3/8	1-1/4	—	3-7/16	1-9/16	2-15/16
GUV1584	4	8	1-7/8	1-5/8	1-1/2	—	3-15/16	1-9/16	3-3/16
GUV15821	2/0	4	1-7/8	1-5/8	1-1/2	—	3-15/16	1-9/16	3-3/16
GUV15825	250	2/0	1-7/8	1-5/8	1-1/2	—	3-15/16	1-9/16	3-3/16
GUV204	4	8	2-3/8	2	2	—	4-7/16	1-9/16	3-11/16
GUV2021	2/0	4	2-3/8	2	2	—	4-7/16	1-9/16	3-11/16
GUV2025	250	2/0	2-3/8	2	2	—	4-7/16	1-9/16	3-11/16
GUV21221	2/0	4	2-7/8	2-1/2	2-1/2	—	4-15/16	1-9/16	4-3/16
GUV21225	250	2/0	2-7/8	2-1/2	2-1/2	—	4-15/16	1-9/16	4-3/16
GUV3021	2/0	4	3-1/2	3	3	—	5-9/16	1-9/16	4-13/16
GUV3025	250	2/0	3-1/2	3	3	—	5-9/16	1-9/16	4-13/16
GUV31221	2/0	4	4	3-1/2	3-1/2	—	6-1/16	1-9/16	5-1/2
GUV4021	2/0	4	4-1/2	4	4	—	6-5/16	1-9/16	5-11/16
GUV4025	250	2/0	4-1/2	4	4	—	6-5/16	1-9/16	5-11/16

For tin plating, add suffix TP to Catalogue number.