


# Steel City® Hangers & Clamps

## Conduit Hangers

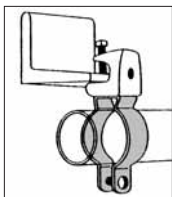

### Features

- Accommodates 1/2" through 4" EMT or rigid conduit.
- Can be used for either vertical or horizontal installation.
- 6HTB Series with thread impression so there are less parts to handle or drop.
- Installs easily with a screwdriver.



Fig. 1



Fig. 2



Fig. 3

## 6H Series Conduit and Pipe Hangers

With Bolt		Without Bolt		EMT	Rigid Conduit or Pipe	Qty. per Box
Cat. No.	Fig. No.	Cat. No.	Fig. No.			
6H0-B	2	6H0	1	1/2	3/8-1/2	100
6H0-TB	3	6H0	1	1/2	3/8-1/2	100
6H1-B	2	6H1	1	3/4	3/4	100
6H1-TB	3	6H1	1	3/4	3/4	100
6H2-B	2	6H2	1	1	1	100
6H2-TB	3	—	—	1	1	100
6H2 1/2-B	2	6H2 1/2	1	1-1/4	—	100
6H2 1/2-TB	3	—	—	1-1/4	—	100
6H3-B	2	6H3-SC	1	1-1/2	1-1/4	100
6H3-TB	3	—	—	1-1/2	1-1/4	100
6H4-B	2	6H4	1	—	1-1/2	100
6H4-TB	3	—	—	—	1-1/2	100
6H5-B	2	6H5	1	2	2	100
6H5-TB	3	—	—	2	2	100
6H6-B	2	6H6	1	2-1/2	2-1/2	100
6H7-B	2	6H7	1	3	3	100
6H8-B	2	6H8	1	3-1/2	3-1/2	100
6H9-B	2	6H9*	1	4	4	100

\* CSA not applicable

Add **SS** suffix to part number for stainless steel.

Load rating is 500 lbs. with a safety factor of 3. Available with or without closure bolt.

Standard finishes: electrogalvanized and Type 302 Stainless Steel.

Top hole diameter : 6H0 to 6H3 = 9/32"  
6H4 to 6H9 = 11/32"

