

# Carlon®

## Liquidtight Flexible Non-Metallic Conduit & Fittings

T&B Catalog Number:



LT43C-CAR  
03448113193  
Active

**UPC Number:**  
**Status:**  
**Description:**

3/8 inch liquidtight non-metallic fitting.

### Features

- Non-conductive and non-corrosive.
- Resistant to oil, acid, ozone and alkaline.
- Easy to install.
- Approved for indoor and outdoor locations
- UL listed for wet locations
- Nitrile rubber 'O' ring for a liquidtight termination.
- Temperatures up to 225 degree F (107 degree C)
- Meets UL standard 514B.

### Application

For use with Carflex conduit and Carflex X-Flex conduit.

### General

Trade Size (inches) 3/8  
Material Non-Metallic

### Dimension Information

Size (inches) 3/8  
Degree of Bend Straight  
A (inches) 0.55  
B (inches) 0.75  
C (inches) 1.6  
D (inches) 1.3  
E (inches) 1.4

### Packaging

T&B Order Multiple 15  
Package in Units 15  
T&B Sold in UOM Each  
T&B Weight Per UOM 0.09 lbs. Each

### Application Support

T&B Sales Drawings wsd-ac04398  
Product Overview-Carflex Liquidtight Flex-Available on Website  
ible Tubing


### Certifications

RoHS Compliance No

### Certifications



File Nbr:  
E 32447

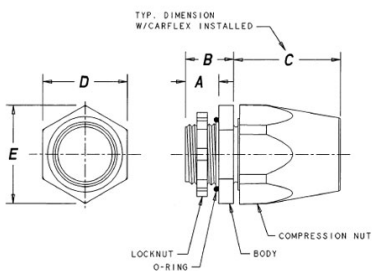

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)