


# Catamount®

## Cable Ties

### CAT STRAP

- All Plastic Two Piece Strapping and Buckles for Diverse Applications
- 120# and 250# Minimum Tensiles per MIL-STD-23190
- UV Nylon for Outdoor Use
- 50 Foot Lengths Allow for Large Bundle Diameters; Cut To Size for Your Application
- Resistant To Fuels, Lubricants and Most Chemicals; UL Flammability 94 V-2; Oxygen Index: 30

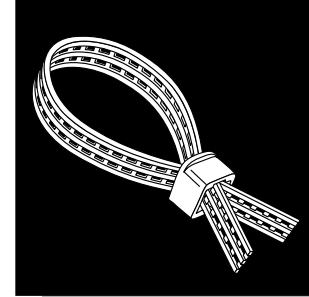

### STRAPPING

Item Number	Trade Size	Width (Inch)	Thickness (Inch)	Minimum Tensile (LB)	Feet/Roll
STR-375-0-L	3/8	.355	.080	120	50
STR-500-0-L	1/2	.495	.103	250	
Tolerance ±		.010			

### CLIPS

Item Number	Trade Size	Width (Inch)	Thickness (Inch)	Minimum Tensile (LB)	Quantity
CLIP-375-0-Q	3/8	.600 x .550	.375	120	25
CLIP-500-0-Q	1/2	.810 x .727	.495	250	
Tolerance ±		.010			



### STRIPED TIES

Per Bag	Item Number	Tie Color	Stripe Color	Bundle Diameter		Length		Width		Minimum Loop Tensile LB (kg)
				Inch	(mm)	Inch	(mm)	Inch	(mm)	
50	L-4-18-1/10-L	Brown	White	1/16 - 7/8 (2 - 16)	4.0	(102)	.100	(3)	18	(8.2)
	L-4-18-1/2-L		Red							
	L-4-18-1/0-L		Black							
	L-4-18-1/4-L		Yellow							
	L-4-18-1/7-L		Purple							
	L-4-18-3/10-L	Orange	White							
	L-4-18-3/2-L		Red							
	L-4-18-3/0-L		Black							
	L-4-18-3/4-L		Yellow							
	L-4-18-3/7-L		Purple							
	L-4-18-5/10-L	Green	White							
	L-4-18-5/2-L		Red							
	L-4-18-5/0-L		Black							
	L-4-18-5/4-L		Yellow							
	L-4-18-5/7-L		Purple							
	L-4-18-6/10-L	Blue	White							
	L-4-18-6/2-L		Red							
	L-4-18-6/0-L		Black							
	L-4-18-6/4-L		Yellow							
	L-4-18-6/7-L		Purple							
L-4-18-8/10-L	Gray	White								
L-4-18-8/2-L		Red								
L-4-18-8/0-L		Black								
L-4-18-8/4-L		Yellow								
L-4-18-8/7-L		Purple								

- Also available in bulk packages of 1000
- Use QC-100, L-200, L-400, L-400C, or ERG-299 Installation Tool

**Thomas & Betts**

# Catamount®

## Cable Ties

### CATAMOUNT® CABLE TIES INDUSTRIAL JAR



90457-I and 90650-IUV

#### Features:

- Ties available in natural nylon or black weather-resistant nylon
- Reusable jar
- Easily merchandised
- Great value
- UL Recognized and Mil-Spec Approved

## CAT-PAK® CABLE TIE ASSORTMENTS

- Four Styles in Convenient Resealable Bags
- Natural or UV Black Nylon
- Point-of-Purchase Display

**UL** RECOGNIZED

Item Number	Contents	Material	Bags/Case
CAT-711	100 L-7-50-9 50 L-11-60-9	Natural Nylon	25
CAT-4811	100 L-4-18-9 100 L-8-40-9 50 L-11-50-9		35
CAT-5811	200 L-5-30-9 200 L-8-40-9 50 L-11-50-9		30
CAT-14120	50 L-14-120-9		15

• For UV Black Assortments, add "-B" to Item Number

Catalog Number	Material	Jar Qty.	Length (inches)	Width	Max. Bundle (inches)	Tensile Strength	Pallet Qty.	
							Mini	Full
CAT90457-I	Natural Nylon	200	4	.100	5/8 (6.25)	18#	240	400
		100	5.6	.130	1 1/4 (1.25)	30#		
		200	7.5	.187	1 3/4 (1.75)	50#		
CAT90457-IUV	Black Weather-Resistant Nylon	200	4	.100	5/8 (6.25)	18#		
		100	5.6	.130	1 1/4 (1.25)	30#		
		200	7.5	.187	1 3/4 (1.75)	50#		
90650-I	Natural Nylon	300	4	.100	5/8 (.625)	18#	160	320
		300	7.5	.187	1 3/4 (1.75)	50#		
		50	11.1	.187	3	50#		
90650-IUV	Black Weather-Resistant Nylon	300	4	.100	5/8 (.625)	18#		
		300	7.5	.187	1 3/4 (1.75)	50#		
		50	11.1	.187	3	50#		

**Thomas&Betts**