

Angler® Pipe and Conduit Clamp

For EMT, IMC, Rigid and Standard Pipe.



Universal Series

CAT. NO.	SIZE (IN.)	STRAP THICKNESS	DESIGN LOAD (LBS.)	INSTALL TORQUE (IN. LBS.)	STD. CTN.
Galv-Krom® Finish					
C 109 1/2	½	14 ga.	400	40	100
C 109 3/4	¾	14 ga.	500	40	100
C 109 1	1	14 ga.	500	40	100
C 109 1 1/4	1¼	14 ga.	500	40	100
C 109 1 1/2	1½	12 ga.	800	60	50
C 109 2	2	12 ga.	800	60	50
C 109 2 1/2	2½	12 ga.	800	60	50
C 109 3	3	12 ga.	800	60	50
C 109 3 1/2	3½	11 ga.	1,200	60	25
C 109 4	4	11 ga.	1,200	60	25

SilverGalv® Finish

C 109 1/2 EG	½	14 ga.	400	40	100
C 109 3/4 EG	¾	14 ga.	500	40	100
C 109 1 EG	1	14 ga.	500	40	100
C 109 1 1/4 EG	1¼	14 ga.	500	40	100
C 109 1 1/2 EG	1½	12 ga.	800	60	50
C 109 2 EG	2	12 ga.	800	60	50
C 109 2 1/2 EG	2½	12 ga.	800	60	50
C 109 3 EG	3	12 ga.	800	60	50
C 109 3 1/2 EG	3½	11 ga.	1,200	60	25
C 109 4 EG	4	11 ga.	1,200	60	25

Available in SilverGalv® Finish by adding "EG" suffix to catalog number.



Rigid Series

CAT. NO.	SIZE (IN.)	STRAP THICKNESS	DESIGN LOAD (LBS.)	INSTALL TORQUE (IN. LBS.)	STD. CTN.
Galv-Krom® Finish					
C 109R 1/2	½	14 ga.	600	40	100
C 109R 3/4	¾	14 ga.	600	40	100
C 109R 1	1	14 ga.	600	40	100
C 109R 1 1/4	1¼	14 ga.	600	40	100
C 109R 1 1/2	1½	12 ga.	800	60	50
C 109R 2	2	12 ga.	800	60	50
C 109R 2 1/2	2½	12 ga.	800	60	50
C 109R 3	3	12 ga.	800	60	50
C 109R 3 1/2	3½	11 ga.	1,200	60	25
C 109R 4	4	11 ga.	1,200	60	25

SilverGalv® Finish

C 109R 1/2 EG	½	14 ga.	600	40	100
C 109R 3/4 EG	¾	14 ga.	600	40	100
C 109R 1 EG	1	14 ga.	600	40	100
C 109R 1 1/4 EG	1¼	14 ga.	600	40	100
C 109R 1 1/2 EG	1½	12 ga.	800	60	50
C 109R 2 EG	2	12 ga.	800	60	50
C 109R 2 1/2 EG	2½	12 ga.	800	60	50
C 109R 3 EG	3	12 ga.	800	60	50
C 109R 3 1/2 EG	3½	11 ga.	1,200	60	25
C 109R 4 EG	4	11 ga.	1,200	60	25


Hex head size ¾" for ½" to 1¼" sizes, ½" for 1½" to 4" sizes.

Material: Stamped Steel.

Pipe sizes 2½" to 4" utilize the same clamps for the Rigid Series and the Universal Series.

Available in SilverGalv® Finish by adding "EG" suffix to catalog number.

C-200 Universal Pipe Straps

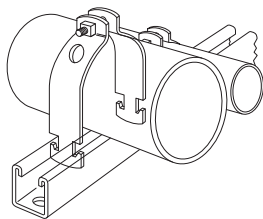

CAT. NO.	EMT, IMC, RIGID PIPE SIZE (IN.)	PIPE O.D. RANGE (IN.)	STRAP THICKNESS	WT. LBS./C
C-200-1/2	½	.706-.804	14 ga.	12
C-200-3/4	¾	.922-1.060	14 ga.	13
C-200-1	1	1.163-1.315	14 ga.	14
C-200-1-1/4	1¼	1.508-1.660	14 ga.	16
C-200-1-1/2	1½	1.738-1.900	12 ga.	27
C-200-2	2	2.196-2.375	12 ga.	31

Design load equal to C-105 straps.