



Conduit Fittings-PVC Coated

T&B Catalog Number:

STG5-G

UPC Number:

70450840894

Status:

Active

Description:

PVC Coated Zinc Grounded Hub with Thermoplastic Insulated Throat, Pipe Size 1-1/2 Inch/41 Metric, Overall Diameter 2.75 Inch/69.85 Millimeters, Maximum Panel Thickness 0.25 Inch/6.35 Millimeters, Throat Diameter 1.53 Inch/38.86 Millimeters, Nitrile Rubber (Buna-N) Sealing Ring, Dark Gray

Features

Coated with a nominal .002 in. (2 mil) blue urethane on the interior, before PVC Coating is applied.


A minimum .040 in. (40 mil) PVC Coating is bonded to the exterior.

Innovative sealing ring and groove.

Hexagonal body and locknut design.

Insulated throat and sharper and deeper teeth.

Pressure sealing sleeves to protect the connection.

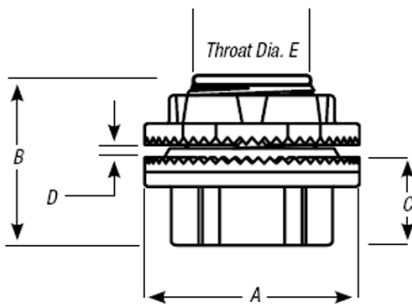

General

Custom_Finish	stg_112
Trade Size (inches)	1 1/2
Material	Zinc
Finish	PVC Coated
Color	Dark Gray

Dimension Information

Dimension A (inches)	2 3/4
Dimension B (inches)	1 7/8
Dimension C (inches)	1 1/16
Dimension D (inches)	1/4
Dimension E (inches)	1 17/32

Technical Information

Chemical Resistance Chart	Available on Website
---------------------------	----------------------

Specifications

Ocal Specification Guide-1995 Master Format-PDF	Available on Website
Ocal Specification Guide-1995 Master Format-DOC	Available on Website
Ocal Specification Guide-2004 Master Format-PDF	Available on Website
Ocal Specification Guide-2004 Master Format-DOC	Available on Website

Packaging

Package in Units	25
T&B Sold in UOM	Each
T&B Weight Per UOM	0.85 lbs. Each

Application Support

Ocal Specifications	Available on Website
Recommended Installation Procedures	Available on Website
Product Overview-Conduit Outlet Bodies	Available on Website

NEMA Standards-RN 1	Available on Website
NEC 310-16 - Conductors for General Wiring	Available on Website
NEC Table 8	Available on Website

Notes

Dimensional values are of uncoated fittings.
 Standard color is dark gray. Also available in white and light blue. Custom colors are also available upon request. Please contact Technical Services, 888-862-3289.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
 8155 T&B Blvd.
 Memphis, TN 38125
 www.tnb.com

T&B Technical Support
 MS 3B-50
 8155 T&B Blvd.
 Memphis, TN 38125

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321
 Email:techsupport@tnb.com