


## Bushings, Nipples, Locknuts and Plugs

Meets and surpasses NEC® requirements!

### Insulated Throat Fittings

- Steel or malleable iron (steel through 1½")
- Exceeds NEC 373-6C requirements for protection of ungrounded connectors at entrance to raceways, pull boxes and junctions
- Recognizable by distinctive trademarked blue insulating liner in throat
- Reduces wire pulling effort by as much as 50%
- Temperature rating of 105° C
- Look for the unique T&B blue color, ensuring the highest quality fitting

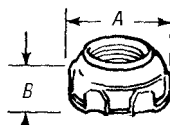

Nylon insulated metallic bushings

CAT. NO.		DIMENSIONS (IN.)		
STL. OR M.I.	ALUM.	SIZE	A	B
1222	1222AL	½"	1½/₃₂	²³/₆₄
1223	1223AL	¾"	1½/₃₂	³¹/₆₄
1224	1224AL	1"	1¹⁹/₃₂	¹¹/₃₂
1225	1225AL	1¼"	1¹⁵/₁₆	²¹/₃₂
1226	1226AL	1½"	2²/₁₆	²³/₃₂
1227	1227AL	2"	2¹¹/₁₆	¼
1228	1228AL	2½"	3³/₁₆	½/₃₂
1229	1229AL	3"	3²/₃₂	⁵/₁₆
1230	1230AL	3½"	4¼	1¹/₁₆
1231	1231AL	4"	4¾	1³/₃₂
1232†	1232AL†	4½"	—	—
586	586AL	5"	5²¹/₃₂	1³/₃₂
587	587AL	6"	6¹/₁₆	1¹¹/₃₂


† Not CSA Certified

Catalog series 1222 thru 1232, 586 and 587 are available in aluminum. Add suffix AL to Cat. No. The aluminum series fittings are not CSA certified.

Locknut-type base improves bonding and resists loosening under vibration.

### Metallic Bushings

- Aluminum, steel or malleable iron (steel through 1½")
- Smoothly rounded shoulder covers end of conduit
- Broad flange covers knockout hole
- High ribs for easy tightening with fingers or with wrench
- ½" to 1½" sizes, formed in steel, feature extra-smooth shoulders

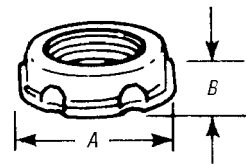

CAT. NO.		DIMENSIONS (IN.)		
STL. OR M.I.	ALUM.	SIZE	A	B
122	122AL	½"	1½/₃₂	¹³/₃₂
123	123AL*	¾"	1¼	¼/₁₆
124	124AL**	1"	1³/₁₆	½
125-TB	125AL	1¼"	1³/₃₂	⁹/₁₆
126	126AL	1½"	2³/₃₂	¹⁹/₃₂
127	127AL	2"	2²/₃₂	⁵/₈
128	128AL	2½"	3³/₁₆	¾
129	129AL	3"	3²/₃₂	1³/₁₆
130-TB	130AL	3½"	4¾	1⁵/₁₆
131-TB	131AL	4"	4¹¹/₁₆	1
132-TB	—	4½"	5¹/₁₆	1³/₆₄
133-TB	133AL	5"	6	1³/₁₆
134-TB	134AL	6"	7¼	1¼

\* Not UL Listed or CSA Certified

UL File No. E-23018


\*\* Not CSA Certified

CSA File No. 2884

Available with DURA-PLATE® Finish.

Perfect threads for easy thread-on!

### Plastic Insulating Bushings

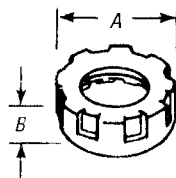

All Plastic Insulating Bushings

- Impact-resistant plastic insulation
- Ribbed for easy, secure gripping
- UL Listed 105° C



CAT. NO.	SIZE	DIMENSIONS (IN.)	
		A	B
222-TB	½"	1¹/₁₆	¾
223-TB	¾"	1³/₃₂	1³/₃₂
224	1"	1³/₁₆	⁹/₁₆
225-TB	1¼"	1²³/₃₂	⁹/₁₆
226	1½"	2¹/₃₂	⁹/₁₆
227	2"	2²⁵/₃₂	⁵/₈
228-TB	2½"	3¾	¾
229-TB	3"	4¹/₁₆	¾
230-TB	3½"	4¾	7/₈
231	4"	5¹/₈	1
232	4½"	5¹¹/₁₆	1
233	5"	6³/₁₆	1
234	6"	7¹/₁₆	1

UL Rated flame retardant 94V-1