

Long Barrel Copper Lug T&B Catalog Number:

256-30695-1222P

UPC Number:


78621091051

Status:

Active

Description:

Copper Two-Hole Lug, Long Barrel, Peep Hole, Max 35kV, Wire Size 750 kcmil, 3/8 Inch Bolt Size, 1 Inch Hole Spacing, Tin Plated, Die Color Code Black, Die Code 106

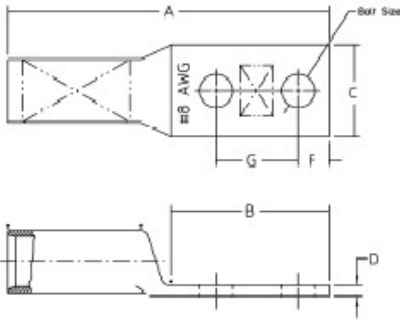

General

Material	Copper
Finish	Tin Plated
Wire Size	750 kcmil
Number of Studs	2
Stud Size	3/8
Bolt Hole Spacing	1
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Black
Die Code	106

Dimension Information

A (inches)	6.25
B (inches)	3
C (inches)	1.938
D (inches)	.25
E (inches)	1.333
F (inches)	.5
G (inches)	1

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	6
T&B Inner Pack	6
Package in Units	30
T&B Sold in UOM	Each
T&B Weight Per UOM	1 lbs. Each

Application Support

Product Overview	Available on Website
------------------	----------------------

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com