



Long Barrel Copper Lug
T&B Catalog Number:

256-30695-1246

UPC Number:

78621017009

Status:


Active

Description:

Copper Two-Hole Lug, Long Barrel, Blind End, Peep Hole, Max 35kV, Wire Size #4 AWG, 1/4 Inch Bolt Size, 3/4 Inch Hole Spacing, Tin Plated, Die Color Code Gray, Die Code 29

General

Material	Copper
Finish	Tin Plated
Wire Size	#4 AWG
Number of Studs	2
Stud Size	1/4
Bolt Hole Spacing	3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Grey
Die Code	29

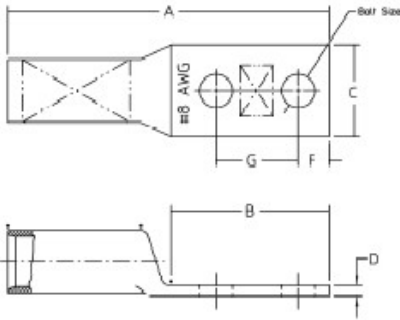

Dimension Information

A (inches)	2.313
B (inches)	1.313
C (inches)	.563
D (inches)	.094
E (inches)	.359
F (inches)	.25
G (inches)	0.75

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	10
T&B Inner Pack	10
Package in Units	50
T&B Sold in UOM	Each
T&B Weight Per UOM	4.38 lbs. per 100

Application Support

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com