


MC and AC Cable Fittings

The easiest and best connector to install when making sharp bends at the enclosure or equipment!

TITE-BITE® Connectors — 90° Angle Nylon Insulated



- Steel or malleable iron construction
- Offers all of the advantages of the straight connector with only one screw to tighten, except in the larger sizes, which have two
- Peep hole on top provides for easy inspection of ABC bushing
- Narrow design makes it easy to install connectors in adjacent knockouts

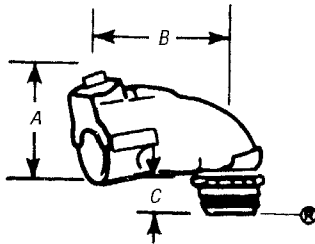

CAT. NO.	CABLE OPENING (IN.)		TRADE SIZE	K.O. SIZE	DIMENSIONS (IN.)		
	MAX.	MIN.			A*	B	C
3130-TB#•	.660	.470	3/8"	1/2"	1 11/32	1 1/32	1 5/16
3132#•	.920	.670	1/2"	1/2"	1 1/8	2 1/16	1 5/16
3135#	1.093	.906	3/4"	3/4"	2 1/8	2 1/8	3/4
3137#	1.468	1.250	1"	1"	2 21/32	2 1/8	1/2
3138***	1.750	1.562	1 1/4"	1 1/4"	3 3/16	3 3/32	3/4
3139***	2.031	1.812	1 1/2"	1 1/2"	4	4 1/8	1 1/16
3140***	2.500	2.312	2"	2"	4 15/16	5 1/16	1 1/16
3141***	3.062	2.812	2 1/2"	2 1/2"	6 3/32	6	3/4
3142***	3.562	3.312	3"	3"	7 11/32	7 1/8	3/4
3143****†	4.060	3.620	3 1/2"	3 1/2"	—	—	—
3144-TB****†	4.560	4.120	4"	4"	—	—	—

UL File No. E 23018

CSA File No. 2684

#UL Listed for Metal Clad Cable (MC).

•UL Listed for new Interlocked Armor Ground Type Metal Clad Cable (MCI-A).

***UL Listed for flexible metal conduit only.

*Approximate dimension with screw at minimum height.


†CSA not applicable.

Angle clip provides secure mechanical grip that tightens under tension or vibration!



TITE-BITE® Connectors — 90° Angle

- Throat is long enough to install in cast housing knockouts
- 3/8" and 1/2" sizes of steel construction
- 3/4" and larger sizes made of malleable iron

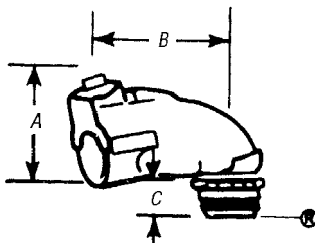

CAT. NO.	CABLE OPENING (IN.)		TRADE SIZE	K.O. SIZE	DIMENSIONS (IN.)		
	MAX.	MIN.			A*	B	C
321#•	.660	.470	3/8"	1/2"	1 11/32	1 1/2	3/8
323#•	.920	.670	1/2"	1/2"	1 1/8	2 3/8	1 1/32
325#	1.093	.906	1/2"	3/4"	2 1/8	2 1/8	1/2
326-TB#	1.468	1.250	1"	1"	2 21/32	2 1/8	1
327-TB***	1.750	1.562	1 1/4"	1 1/4"	3 3/8	3 3/8	—
328***	2.031	1.812	1 1/2"	1 1/2"	4 1/8	4 1/8	—
329***	2.500	2.312	2"	2"	4 3/8	4 3/32	—
330-TB***	3.062	2.812	2 1/2"	2 1/2"	6 1/2	6	—
331***	3.562	3.312	3"	3"	5 25/32	7	—
332††	4.060	3.620	3 1/2"	3 1/2"	—	—	—
333††	4.560	4.120	4"	4"	—	—	—
3144-TB****†	4.560	4.120	4"	4"	—	—	—

UL File No. E 23018

CSA File No. 2684

#UL Listed for Metal Clad Cable (MC).

•UL Listed for new Interlocked Armor Ground Type Metal Clad Cable (MCI-A).

***UL Listed for flexible metal conduit only.

*Approximate dimension with screw at minimum height.

††CSA not applicable.