


## Hook and Loop Fasteners

### FO, FOL, FOS and FOR Series


#### New version available — UL94V-2 rated material

- High-quality Hook & Loop Fasteners designed specifically for Thomas & Betts
- Enables quick and convenient bundling of data and fiber optic cables
- Sizes available to accommodate varying bundle diameters
- Screw and adhesive mounting bases provide multiple mounting options

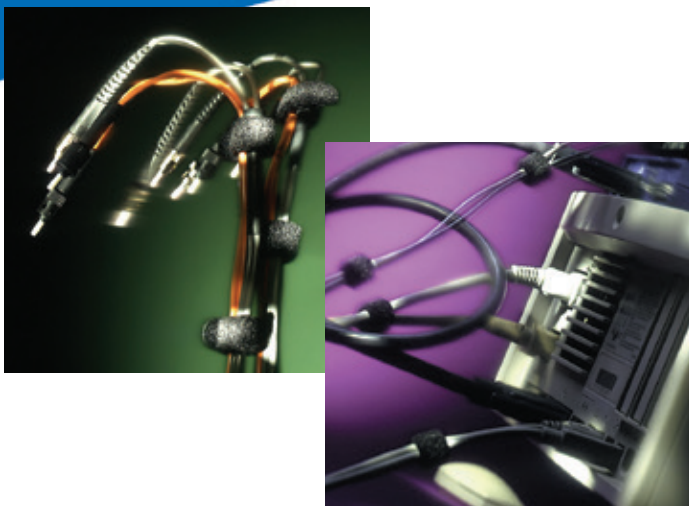

**FO Series Loop Ties**

Wrap pre-determined bundle diameters using the convenient slotted head!

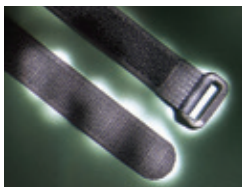


**FOL Series Buckle Ties**

Polymer buckles provide added strength and stability.



**FOS Series Strip Ties**

Pre-cut lengths make bundling a cinch!

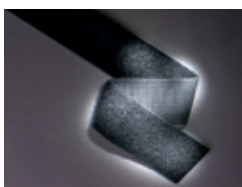

**FOR Series Rolled Hook and Loop**

Rolled hook and loop material enables custom cut lengths, avoiding waste.

**Fasteners available in these colours:** Black, Brown, Red, Orange, Yellow, Green, Blue, Grey, and White.  
Please consult Regional Sales Office for delivery and availability.

Cat. No.	Min. Tensile Strength (lb./N)	Max. Bundle Dia. (in./mm)	Length (in./mm)	Width (in./mm)	Std. Pkg.
<b>*FO Series Loop Ties</b>					
<b>FO200-40-0</b>	40/177.9	2.0/50.80	9/228.6	0.50/12.7	10
<b>FO200-50-0</b>	50/222.4			0.75/19.05	
<b>FO350-40-0</b>		3.5/88.90	13/330.2	0.50/12.7	
<b>FO350-50-0</b>	0.75/19.05				
<b>FOL Series Buckle Ties</b>					
<b>FOL300-50-0</b>	50/222.4	3.0/76.20	12/304.8	0.75/19.05	10
<b>FOL500-50-0</b>		5.0/127.00	18/457.2		
<b>FOS Series Strip Ties</b>					
<b>FOS150-50-0</b>	50/222.4	1.5/38.10	6/152.4	-	10
<b>FOS320-50-0</b>		3.2/81.28	12/304.8		
<b>FOS500-50-0</b>		5.0/127.00	18/457.2		
<b>FOR Series Rolled Hook and Loop</b>					
<b>FOR180-50-0</b>	50/222.4	Various	180/4572	-	1

Black is standard colour.

Multiple colours available for identifying specific bundles

\*Add — "FR" for UL94V-2 rated material, after colour choice.

Contact your Regional Sales Office for availability and delivery.

### Two mounting bases designed for use with hook and loop fasteners



Cat. No.	Description	Screw Size	Max. Tie Width Accom.	Std. Pkg.
<b>Nylon 6/6 Mounting Bases</b>				
<b>TC368</b>	2 in. x 2 in. Screw Mounted	#8	0.75/19.05	500
<b>TC368A</b>	2 in. x 2 in. Adhesive Mounted			

-40°F/-40°C to 176°F/80°C  
Natural nylon colour.