


## Conduit Bodies

### Conduit Bodies, Covers and Gaskets — A Series (continued)

#### LB Style

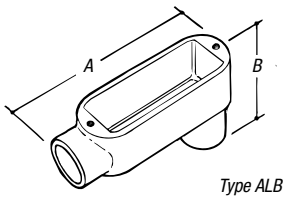


CAT. NO.	TRADE SIZE (IN.)	A (IN.)	B (IN.)	STD. CTN.
ALB-1	1/2	3 3/8	2 1/16	50
ALB-2	3/4	4 5/8	2 1/16	50
ALB-3	1	5 3/8	2 3/4	25
ALB-4	1 1/4	7 1/4	3 3/16	10
ALB-5	1 1/2	7 1/4	3 13/16	10
ALB-6	2	9 1/2	4 1/2	5
ALB-7*	2 1/2	12 1/4	5 1/4	1
ALB-8*	3	12 1/4	5 5/8	1
ALB-9*	3 1/2	15	6 15/16	1
ALB-10*	4	15	6 15/16	1

CAT. NO.	HUB SIZE (IN.)	STD. CTN.
<b>D-PAK® *</b>		
DALB-1-CG	1/2	25
DALB-2-CG	3/4	16
DALB-3-CG	1	6
DALB-4-CG	1 1/4	5
DALB-5-C	1 1/2	5
DALB-6-CG	2	2
DALB-7-CG	2 1/2	2
DALB-8-CG	3	2
DALB-9-CG	3 1/2	2
DALB-10-CG	4	2

\* Shipped with cover. Price includes cost of cover and body.  
UL File No. E-28688.

#### LL Style

- Die-cast copper-free aluminum construction
- Provide access for pulling, splicing and maintenance
- For rigid conduit/IMC applications
- UL Listed

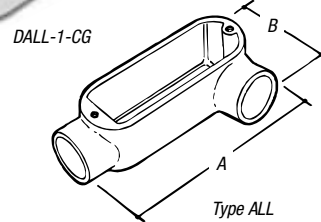

CAT. NO.	TRADE SIZE (IN.)	A (IN.)	B (IN.)	STD. CTN.
ALL-1	1/2	3 3/8	2	50
ALL-2	3/4	4 5/8	2 15/16	50
ALL-3	1	5 3/8	2 1/2	25
ALL-4	1 1/4	7 1/4	3 3/8	10
ALL-5	1 1/2	7 1/4	3 3/8	10
ALL-6	2	9 1/2	3 15/16	5
ALL-7*	2 1/2	12 1/4	5 1/2	1
ALL-8*	3	12 1/4	5 1/2	1
ALL-9*	3 1/2	15	6 1/2	1
ALL-10*	4	15	6 1/2	1

CAT. NO.	HUB SIZE (IN.)	STD. CTN.
<b>D-PAK® *</b>		
DALL-1-CG	1/2	12
DALL-2-CG	3/4	15
DALL-3-CG	1	5
DALL-4-CG	1 1/4	4
DALL-5-CG	1 1/2	5
DALL-6-CG	2	2
DALL-7-CG	2 1/2	2
DALL-8-CG	3	2
DALL-9-CG	3 1/2	2
DALL-10-CG	4	2

\* Shipped with cover. Price includes cost of cover and body.  
UL File No. E-28688