


Cable Ties

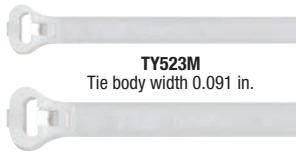

TY523M
Tie body width 0.091 in.



TY524
Tie body width 0.140 in.



TY525M
Tie body width 0.184 in.



TY5272M
Actual size body width 0.270 in.



Std. Cat. No.	Bulk Cat. No.	Type DSG	Plenum Rating	Usage	ANSI UL94 Flame Rating	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Military Standard Part No.	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
Ty-Rap® Standard Nylon 6/6 Cable Ties												
TY523M	TY23M	2/21	AH-2	Indoor Only	V-2	0.09/2.29	3.62/91.95	0.87/22.00	MS3367-4	18/80.00	100	1,000
TY52315M	TYB2315M						7.00/177.80	1.25/32.00	–			
TY5232M	TY232M						8.00/203.20	2.00/51.00	–			
TY5234M	TY234M						14.00/355.60	4.00/102.00	–			
TY524M	TY24M					0.14/3.56	5.50/139.70	1.38/35.00	MS3367-5	40/180.00		
TY5242M	TY242M						8.19/208.03	2.00/51.00	–			
TY526M	TY26M						11.10/281.94	3.00/76.00	–			
TY5244M	TY244M						14.50/368.30	4.00/102.00	–			
TY525M	TY25M	2S/21S	AH-2	Indoor Only	V-2	0.19/4.83	7.31/185.67	1.89/48.00	MS3367-1	50/222.00		
TY5253M	TY253M						11.60/294.64	3.00/78.00	MS3367-7			
TY528M	TY28M						14.20/360.68	4.00/102.00	MS3367-2			
TY5272M	TY272M					0.27/6.86	8.75/222.25	2.00/51.00	–	120/540.00		
TY527M	TY27M	13.40/340.36	4.00/102.00	MS3367-3								
TY5275M	TY275M	18.00/457.20	5.00/127.00	–								
TY5277M	TY277M	24.30/617.22	7.00/177.00	–								
TY529M	TY29M					30.00/762.00	9.00/229.00	MS3367-6		50		
TY53510M**	–	N/A	N/A		N/A	0.32/8.13	35.00/889.00	10.00/254.00	–	175/778.40		–
TY54513M**	–	N/A	N/A		N/A	0.32/8.13	45.00/330.20	13.00/330.20	–			–

Cable ties made from natural nylon 6/6 are excellent performers in most applications. Nylon 6/6 is recommended for use in temperatures ranging from -60°C to 85°C (-76°F to 185°F). CSA Certified file 002884. Natural 6/6 Nylon Cable Ties are suitable for use in air handling plenum spaces in accordance with rules 12-010 (3), (4) and (5), and 12-020 of the CEC.

** RUL
Halogen free, Silicone free
UL recognized models.

Cable Ties



TY523MX
Tie body width 0.091 in.



TY524MX
Tie body width 0.140 in.



TY525MX
Tie body width 0.184 in.



TY5272MX
Actual size body width 0.270 in.

The MX Series cable ties are recommended for outdoor use.



Std. Cat. No.	Bulk Cat. No.	Type DSG	Plenum Rating	Usage	ANSI UL94 Flame Rating	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Military Standard Part No.	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
Ty-Rap® Nylon 6/6 – Weather-Resistant												
TY523MX	TY23MX	2/21	AH-2	Indoor/ Outdoor	V-2	0.09/2.29	3.62/91.95	0.87/22.00	MS3367-4	18/80.00	100	1,000
TY52315MX	TYB2315MX						7.00/177.80	1.25/32.00	–			
TY5232MX	TY232MX						8.00/203.20	2.00/51.00	–			
TY5234MX	TY234MX						14.00/355.60	4.00/102.00	–			
TY524MX	TY24MX					0.14/3.56	5.50/139.70	1.38/35.00	MS3367-5	40/180.00		
TY5242MX	TY242MX						8.19/208.03	2.00/51.00	–	30/130.00		
TY526MX	TY26MX						11.10/281.94	3.00/76.00	–			
TY5244MX	TY244MX					14.50/368.30	4.00/102.00	–				
TY525MX	TY25MX					0.19/4.83	7.31/185.67	1.89/48.00	MS3367-1	50/220.00		
TY5253MX	TY253MX						11.60/294.64	3.00/78.00	MS3367-7			
TY528MX	TY28MX	14.20/360.68	4.00/102.00	MS3367-2								
TY5272MX	TY272MX	2S/21S	N/A	Indoor/ Outdoor	HB	0.27/6.86	8.75/222.25	2.00/51.00	–	120/540.00	50	500
TY527MX	TY27MX						13.40/340.36	4.00/102.00	MS3367-3			
TY5275MX	TY275MX						18.00/457.20	5.00/127.00	–			
TY5277MX	TY277MX						24.30/617.22	7.00/177.00	–			
TY529MX	TY29MX*						30.00/762.00	9.00/229.00	MS3367-6			
TY53510MX**	–	N/A	N/A	Indoor/ Outdoor	N/A	0.32/8.13	35.00/889.00	10.00/254.00	–	175/778.40	–	
TY54513MX**	–	N/A					45.00/330.20	13.00/330.20	–			

* For military compliance of weather-resistant black 120 lb. ties, replace suffix X with O (i.e. TY27M-O).

**

Halogen free, Silicone free

CSA Certified file 002884. Natural 6/6 Nylon Cable Ties are suitable for use in air handling plenum spaces in accordance with rules 12-010 (3), (4) and (5), and 12-020 of the CEC.

Nylon 6/6 is recommended for use in temperatures ranging from -60°C to 85°C (-76°F to 185°F).

Cable Ties



Std. Pkg. Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Tensile Strength (lb./N)	Std. Pkg.
Ty-Rap® Nylon 6/6 Cable Tie – Colour Assortment					
TY525M-CLRS	0.19/4.83	7.31/185.67	1.75/44.45	50/222.00	100

Cable ties are same size as TY525M shown above. 10 ties in each colour (black, brown, red, orange, yellow, green, blue, purple, grey & white) are packaged. 100 total cable ties per package.



The colours you need in convenient packs!

Ty-Rap® Nylon 6/6 Cable Ties – Colour Assortment

- Construction – nylon 6/6, 316 stainless steel locking device

Std. Cat. No.	Bulk Cat. No.	Description	Type DSG	Plenum Rating	Usage	ANSI UL94 Flame Rating	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Tensile Strength (lb./N)	Std. Pkg.
–	TY525M-CLRS	Multi-Coloured Natural Nylon (10 each of standard ten colours)	2S/21S	AH2	Indoor Only	V2	0.19/4.83	7.31/185.67	1.89/48.00	50/222.00	100
–	TY25M-0	Black, Natural Nylon									1000
–	TY25M-1	Brown, Natural Nylon									
–	TY25M-2	Red, Natural Nylon									
–	TY25M-3	Orange, Natural Nylon									
–	TY25M-4	Yellow, Natural Nylon									
–	TY25M-5	Green, Natural Nylon									
–	TY25M-6	Blue, Natural Nylon									
–	TY25M-7	Purple, Natural Nylon									
–	TY25M-8	Grey, Natural Nylon									
–	TY25M-9	White, Natural Nylon									


For use in temperatures ranging from -60°C to 85°C (-76°F to 185°F)

- UL Listed Natural Nylon 6/6 Cable Ties are suitable for use in air handling spaces (plenums) in accordance with rules 12-010 (3), (4) and (5), and 12-020 of the CEC part I
- CSA Certified file 002884
- 100 standard ties in black, brown, red, orange, yellow, green, blue, purple, grey and white (10 each)
- Recommended tooling – ERG-50, WT1-TB

Natural nylon is standard. For coloured Ty-Rap® ties, add the following suffix numbers to catalogue numbers. **Example:** TY25M-2 would be red TY25M. (Consult Regional Sales Office for ordering information.)

Colour	Suffix No.	Colour	Suffix No.	Colour	Suffix No.	Colour	Suffix No.
Black	X	Red	2	Green	5	Grey	8
(outdoor)		Orange	3	Blue	6	White	9
Brown	1	Yellow	4	Purple	7		


How to Order Coloured Ty-Rap® Cable Ties and Accessories

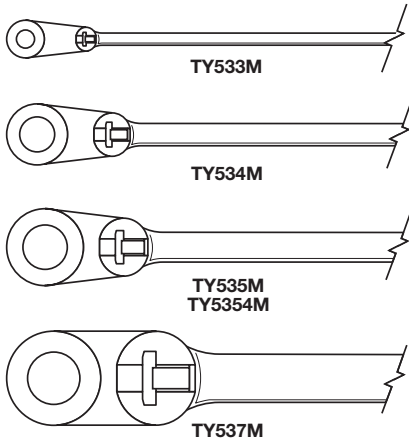

Great for use with screws, nuts and bolts for secure fastening to surfaces.

Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Mounting Hole	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
Ty-Rap® Mounting Head Cable Ties								
TY533M	TY33M	0.09/2.29	4.00/101.60	0.63/16.00	#4	18/80.07	100	1,000
TY534M	TY34M	0.14/3.56	6.00/152.40	1.13/28.70	#8	40/177.90		
TY535M	TY35M	0.18/4.57	7.80/198.12	1.75/44.45	#10	50/222.40		
TY5354M	TY354M		14.60/370.84	4.00/101.60	#10			
TY1435M	-	0.19/4.83	7.80/198.12	1.77/44.96	0.248		-	
TY635M	-				0.138			
TYF535M	TYF35M		7.24/183.90	0.138	100			
TY537M	TY37M	0.30/7.62	13.90/353.06	3.50/88.90	1/4	120/533.80	50	500

Cable ties made from natural nylon 6/6 are excellent performers in most applications. Nylon 6/6 is recommended for use in temperatures ranging from -40°C to 85°C (-40°F to 185°F).

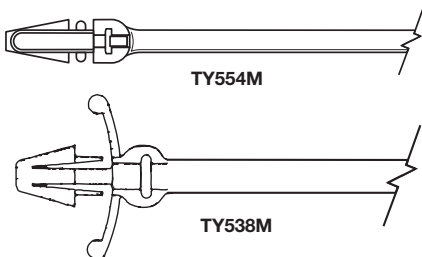


For use in 3/16 in. and 1/4 in. pre-drilled holes. Thickness panel 0.094 max. (TY554M) Range 0.04 - 0.156 (TY538M)

Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Mounting Hole	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
Ty-Rap® Push Mount Cable Ties								
TY554M	TY54M	0.14/3.56	5.96/151.38	1.13/28.70	3/16	40/177.90	100	1,000
TY538M	TY38M*	0.18/4.57	7.80/198.12	1.75/44.45	1/4	50/222.40		

Cable ties made from natural nylon 6/6 are excellent performers in most applications. Nylon 6/6 is recommended for use in temperatures ranging from -40°C to 85°C (-40°F to 185°F).

* Nylon 6/6 UV weather-resistant version available (TY38MX).

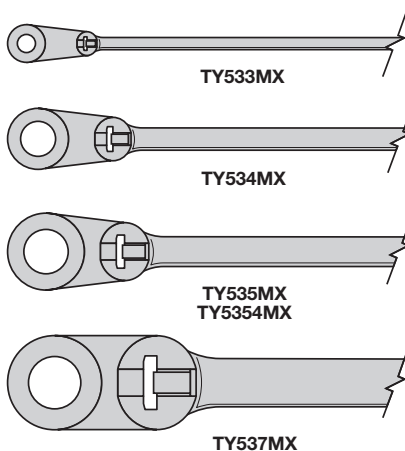

The MX series cable ties are recommended for outdoor use.

Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Mounting Hole	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
Ty-Rap® Nylon 6/6 Weather-Resistant								
TY533MX	TY33MX	0.09/2.29	4.00/101.60	0.63/16.00	#4	18/80.07	100	1,000
TY534MX	TY34MX	0.14/3.56	6.00/152.40	1.13/28.70	#8	40/177.90		
TY535MX	TY35MX	0.18/4.57	7.80/198.12	1.75/44.45	#10	50/222.40		
TY5354MX	TY354MX		14.60/370.84	4.00/101.60	#10			
TY537MX	TY37MX	0.30/7.62	13.90/353.06	3.50/88.90	1/4		120/533.80	50

Colour - Black

For use in temperatures ranging from -40°C to 85°C (-40°F to 185°F).