

# Carlon<sup>®</sup> PVC New Work Boxes



Carlon<sup>®</sup> Blue PVC Boxes

## Two-Gang Adjustable

- Patented design allows for adjustment from 0" to 1<sup>3</sup>/<sub>4</sub>" after installation
- Ideal for new work or retrofit upgrade applications
- Backless low voltage bracket and floor box designs available
- Ideal for various drywall thicknesses and wall finishes

**CARLON  
EXCLUSIVE**



B234ADJ



B234ADJC



## Two-Gang Adjustable 34.0 Cu. In

CAT. NO.	SIZE CU. IN.	MOUNTING MEANS	DESCRIPTION	DIMENSIONS (IN.)	STD. CTN. QTY.
B234ADJ	34.0	Adjustable bracket	Adjusts 0" - 1 <sup>3</sup> / <sub>4</sub> "	5 <sup>5</sup> / <sub>8</sub> W x 3 <sup>5</sup> / <sub>8</sub> H x 3 D	16
B234ADJC	34.0	Adjustable bracket	Large knockout	5 <sup>5</sup> / <sub>8</sub> W x 3 <sup>5</sup> / <sub>8</sub> H x 3 D	16

## Two-Gang Nail-On



B232A-UPC



N2-1614-MNC



N2-1614-RNC



SN-236




SN-236-FS



SN-236-V



SN-241

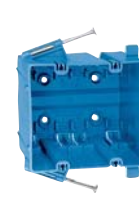

SN-241-FS




## Two-Gang Nail-On 32.0 - 41.0 Cu. In.

CAT. NO.	SIZE CU. IN.	MOUNTING MEANS	DESCRIPTION	DIMENSIONS (IN.)	STD. CTN. QTY.
B232A-UPC	32.0	Captive nails	—	3 <sup>3</sup> / <sub>4</sub> L x 4 W x 3 D	50
N2-1614-MNC	32.0	Angled side nails	7 <sup>1</sup> / <sub>32</sub> " offset wallboard tabs Cable-Lok™ clamps bulk packed	4 <sup>1</sup> / <sub>16</sub> L x 3 <sup>5</sup> / <sub>8</sub> W x 2 <sup>3</sup> / <sub>4</sub> D	50
N2-1614-RNC	32.0	Angled side nails	No wallboard tabs Cable-Lok™ clamps bulk packed	4 <sup>1</sup> / <sub>16</sub> L x 3 <sup>5</sup> / <sub>8</sub> W x 2 <sup>3</sup> / <sub>4</sub> D	50
SN-236	36.0	Compound angled nails	3 <sup>1</sup> / <sub>8</sub> " offset wallboard tabs molded fast clamp	4 L x 3 <sup>5</sup> / <sub>8</sub> W x 3 <sup>1</sup> / <sub>8</sub> D	50
SN-236-FS	36.0	Compound angled nails	3 <sup>1</sup> / <sub>8</sub> " offset wallboard tabs molded fast clamp/fast set	4 L x 3 <sup>5</sup> / <sub>8</sub> W x 3 <sup>1</sup> / <sub>8</sub> D	50
SN-236-V	36.0	Compound angled nails	3 <sup>1</sup> / <sub>8</sub> " offset wallboard tabs molded V-clamp	4 L x 3 <sup>5</sup> / <sub>8</sub> W x 3 <sup>1</sup> / <sub>8</sub> D	50
SN-241	41.0	Compound angled nails	3 <sup>1</sup> / <sub>8</sub> " offset wallboard tabs molded fast clamp	4 L x 3 <sup>5</sup> / <sub>8</sub> W x 3 <sup>5</sup> / <sub>8</sub> D	50
SN-241-FS	41.0	Compound angled nails	3 <sup>1</sup> / <sub>8</sub> " offset wallboard tabs molded fast clamp/fast set	4 L x 3 <sup>5</sup> / <sub>8</sub> W x 3 <sup>5</sup> / <sub>8</sub> D	50

## Two-Gang Bracket



B232B-UPC

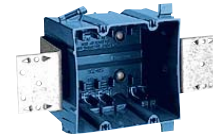

SB2-236-FS



## Two-Gang Bracket 32.0 - 36.0 Cu. In.

CAT. NO.	SIZE CU. IN.	MOUNTING MEANS	DESCRIPTION	DIMENSIONS (IN.)	STD. CTN. QTY.
B232B-UPC	32.0	Bracket for 3 <sup>1</sup> / <sub>8</sub> " to 5 <sup>1</sup> / <sub>8</sub> " wallboard – steel or wood stud mounting	—	3 <sup>3</sup> / <sub>4</sub> L x 4 W x 3 D	50
SB2-236-FS	36.0	Two 3 <sup>1</sup> / <sub>8</sub> " offset brackets for wood/steel studs	3 <sup>1</sup> / <sub>8</sub> " offset	3 <sup>9</sup> / <sub>16</sub> L x 4 W x 3 <sup>9</sup> / <sub>16</sub> D	20



United States  
Tel: 901.252.8000  
Fax: 901.252.1354

Technical Services  
Tel: 888.862.3289

**Thomas & Betts**

[www.tnb.com](http://www.tnb.com)