


Couplings and Accessories

One-piece fitting couples armored cable or flexible conduit to threaded rigid conduit!

TITE-BITE® Combination Couplings — Armored Cable for Threaded Rigid

- Tite-Bite® wedge holds conduit securely with a double grip
- When used with a Chase® nipple, this fitting will connect flexible conduit to outlet boxes, enabling more wiring space in the box than the usual connector
- UL® Listed as a grounding means under NEC® 350-5
- Malleable iron construction

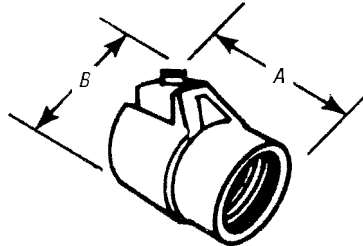


| CAT. NO. | SIZE | DIMENSIONS (IN.) | |
|----------|------|------------------|---------|
| | | A | B |
| 440 | 1/2" | 1 1/8 | 1 7/32 |
| 441 | 3/4" | 1 1/4 | 2 1/8 |
| 442 | 1" | 2 | 2 17/32 |

UL File No. E-23018
CSA File No. 2884

Mount flat against wall, eliminating the need to offset conduit!

Entrance Ells

- Designed for a straight pull in either direction
- Smooth surface
- Make it easy to pull heavy wires without damage to insulation
- Made of copper-free aluminum

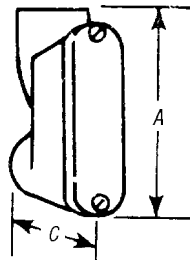

| CAT. NO. | CONDUIT SIZE | DIMENSIONS (IN.) | |
|----------|--------------|------------------|---------|
| | | A | C |
| 1490 | 1/2" | 3 | 1 19/32 |
| 1491 | 3/4" | 3 3/8 | 1 1/8 |
| 1492 | 1" | 4 1/4 | 2 23/64 |
| 1493 | 1 1/4" | 5 1/64 | 2 19/16 |
| 1494 | 1 1/2" | 6 1/4 | 2 1/8 |
| 1495 | 2" | 6 3/4 | 3 1/16 |

UL File No. E-23018. CSA File Nos. 2884 and 589

Adjustable design fits a wide range of flange sizes!

Adjustable Beam Clamps

- Includes bolts
- Steel construction



| CAT. NO. | DESCRIPTION |
|----------|---------------------------|
| 700TB | Fits Flange 2 3/4"–7 3/8" |
| 701 | Fits Flange 7"–12" |
| 703 | Special Bolt and (3) Nuts |

CSA File No. 2884.

Fits any flange, tapered or straight, up to 5/8" thick!

Conduit Supports

- For use with standard rigid conduit, EMT or IMC
- Broad hook holds conduit at any desired angle
- Malleable iron construction



| CAT. NO. | SIZE |
|----------|--------|
| 690TB | 1/2" |
| 691TB | 3/4" |
| 692TB | 1" |
| 693TB | 1 1/4" |

CSA File No. 2884