

CAT#	A	B
0/0B	.550	.595
1/1B	.66	.67
2/2B	.845	.610
3/3B	.94	.680
4/4B	1.16	.775

CAT#	Fits Cable
0/0B	14/2, 14/3, 12/2, 12/3
1/1B	14/4, 6/1, 4/1
2/2B	12/4, 10/2, 10/3, 2/1
3/3B	10/4, 8/2, 8/3, 1/1
4/4B	8/4, 6/2, 6/3, 6/4, 4/2, 4/3

ANTI-SHORT BUSHINGS

PLASTIC

TOPAZ CAT #	UPC#	SIZE	FLEX SIZE	PER BAG	SHIP CASE	WT/ CASE
0	10000	0	5/16"	35	500 BAGS	15
1	10010	1	3/8"	35	400 BAGS	12
2	10020	2	7/16"	35	300 BAGS	18
3	10030	3	1/2"	20	200 BAGS	16
4	10040	4	3/4"	16	100 BAGS	9

BULK

0B	10041	0	5/16"	-	5000	3
1B	10042	1	3/8"	-	5000	3
2B	10043	2	7/16"	-	2000	4
3B	10044	3	1/2"	-	2000	4
4B	10045	4	3/4"	-	1000	3

DOWNLOAD SPEC SHEET




FLEXIBLE STEEL CONDUIT

- SMOOTH INTERIOR FOR EASY WIRE PULL THROUGH
- COIL

STEEL

TOPAZ CAT #	UPC#	SIZE	FEET COIL	UNIT CTN	SHIP CASE	WT/ CASE
5200	80341	3/8"	100'	-	100	15
5250	85482	3/8"	250'	-	250	37
5201	80342	1/2"	100'	-	100	21
5202	80343	3/4"	100'	-	100	25
5203	80345	1"	100'	-	100	45
5203C50	85524	1"	50'	-	50	24
5204	82011	1-1/4"	50'	-	50	24
5205	80346	1-1/2"	50'	-	50	30
5205C25	85526	1-1/2"	25'	-	25	16
5206	80347	2"	25'	-	25	19
5207	80348	2-1/2"	25'	-	25	26
5208	80349	3"	25'	-	25	31
5209	80350	3-1/2"	25'	-	25	34
5210	80351	4"	25'	-	25	34

DOWNLOAD SPEC SHEET

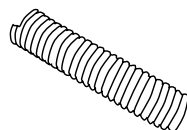

CAT#	Diameter	
	INNER	OUTER
5200/5250	.376	.571
5201	.634	.866
5202	.846	1.063
5203/C50	1.059	1.299
5204	1.343	1.535
5205/C25	1.520	1.850
5206	2.075	2.362
5207	2.559	2.953
5208	3.110	3.504
5209	3.551	3.957
5210	4.154	4.508


FLEXIBLE STEEL CONDUIT

- SMOOTH INTERIOR FOR EASY WIRE PULL THROUGH
- REEL

STEEL

TOPAZ CAT #	UPC#	SIZE	FEET REEL	UNIT CTN	SHIP CASE	WT/ CASE
5200R	85240	3/8"	1000'	-	1000	159
5201R	85241	1/2"	500'	-	500	80
5201RL	85508	1/2"	1000'	-	1000	160
5202R	85242	3/4"	300'	-	300	48
5202R500	85523	3/4"	500'	-	500	80
5203R	85243	1"	200'	-	200	99
5203R300	85525	1"	300'	-	300	150
5204R	85244	1-1/4"	200'	-	200	104
5204R400	85589	1-1/4"	400'	-	400	52
5205R	85245	1-1/2"	100'	-	100	63
5206R	85246	2"	100'	-	100	81

DOWNLOAD SPEC SHEET

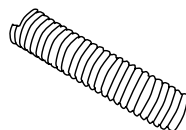

CAT#	Diameter	
	INNER	OUTER
5200R	.376	.571
5201R/RL	.634	.866
5202R/R500	.846	1.063
5203R/R300	1.059	1.299
5204R/R400	1.343	1.535
5205R	1.520	1.850
5206R	2.075	2.362