


| CAT# | A | B | C |
|------|-------|------|------|
| 481 | 2.06 | 1.00 | .50 |
| 482 | 2.38 | 1.06 | .50 |
| 483 | 2.94 | 1.25 | .56 |
| 484 | 3.50 | 1.88 | .75 |
| 485 | 3.81 | 1.44 | .81 |
| 486 | 4.75 | 1.94 | 1.00 |
| 487 | 5.75 | 2.44 | .75 |
| 488 | 6.69 | 2.63 | .88 |
| 489 | 7.13 | 2.88 | 1.06 |
| 489A | 8.88 | 3.06 | 1.06 |
| 489B | 10.13 | 3.75 | .60 |
| 489C | 12.19 | 4.00 | .75 |

EMT/RIGID CLAMP BACKS

MALLEABLE IRON

| TOPAZ CAT # | UPC# | SIZE | UNIT CTN | SHIP CASE | WT/ CASE |
|-------------|-------|--------|----------|-----------|----------|
| 481 | 14510 | 1/2" | 25 | 250 | 16 |
| 482 | 14520 | 3/4" | 25 | 250 | 22 |
| 483 | 14530 | 1" | 25 | 250 | 35 |
| 484 | 14540 | 1 1/4" | 10 | 100 | 21 |
| 485 | 14550 | 1 1/2" | 10 | 100 | 27 |
| 486 | 14560 | 2" | 5 | 50 | 22 |
| 487 | 14570 | 2 1/2" | — | 25 | 14 |
| 488 | 14580 | 3" | — | 10 | 9 |
| 489 | 14590 | 3 1/2" | — | 10 | 14 |
| 489A | 14600 | 4" | — | 10 | 18 |
| 489B | 14601 | 5" | — | 10 | 25 |
| 489C | 14602 | 6" | — | 10 | 30 |

DOWNLOAD SPEC SHEET

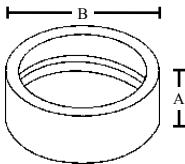

| CAT# | A | B |
|------|------|------|
| 1661 | .522 | .570 |
| 1662 | .538 | .764 |
| 1663 | .614 | .954 |
| 1664 | .620 | 1.26 |
| 1665 | .620 | 1.44 |
| 1666 | .619 | 1.86 |
| 1667 | 1.12 | 2.34 |
| 1668 | 1.19 | 2.78 |
| 1669 | 1.22 | 3.27 |
| 1670 | 1.22 | 3.71 |

EMT INSULATING BUSHING

6/6 NYLON

| TOPAZ CAT # | UPC# | SIZE | UNIT CTN | SHIP CASE | WT/ CASE |
|-------------|-------|--------|----------|-----------|----------|
| 1661 | 18451 | 1/2" | 100 | 1000 | 5 |
| 1662 | 18452 | 3/4" | 100 | 1000 | 6 |
| 1663 | 18453 | 1" | 50 | 500 | 5 |
| 1664 | 18454 | 1 1/4" | 25 | 250 | 4 |
| 1665 | 18455 | 1 1/2" | 25 | 250 | 5 |
| 1666 | 18456 | 2" | 20 | 200 | 5 |
| 1667* | 18457 | 2 1/2" | — | 25 | 1 |
| 1668* | 18458 | 3" | — | 25 | 2 |
| 1669* | 18459 | 3 1/2" | — | 25 | 2 |
| 1670* | 18460 | 4" | — | 25 | 2 |

DOWNLOAD SPEC SHEET



*EMT & RIGID