



CAT#	A	B	C
LL1	4.295	1.370	2.030
LL2	5.090	1.625	2.330
LL3	5.915	1.900	2.650
LL4	7.894	2.770	3.385
LL5	7.894	2.770	3.385
LL6	10.134	3.335	3.810
LL7	13.000	4.063	5.709
LL8	12.750	4.682	5.506
LL9	15.500	5.452	6.171
LL10	15.500	5.452	6.171

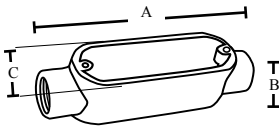

CAT#	A	B	C
C1	4.720	1.370	1.330
C2	5.570	1.625	1.540
C3	6.460	1.900	1.740
C4	8.528	2.770	2.490
C5	8.528	2.770	2.490
C6	10.831	3.335	3.100
C7	13.500	4.060	4.450
C8	13.000	4.685	4.450
C9	15.937	5.450	5.500
C10	15.937	5.450	5.500

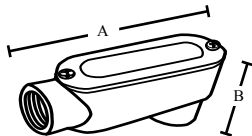

CAT#	A	B
MLBCG4	10.19	4.06
MLBCG5	15.54	4.88
MLBCG6	15.54	4.88
MLBCG7	17.88	8.00
MLBCG8	21.06	10.00
MLBCG9	24.31	10.25
MLBCG10	27.50	12.50

CONDUIT BODIES RIGID THREADED TYPE

COPPER FREE ALUMINUM

TOPAZ CAT #	UPC#	SIZE	MAX # CONDUCTORS	UNIT CTN	SHIP CASE	WT/ CASE
RIGID LL TYPE						
LL1	21040	1/2"	1#6AWG	10	100	28
LL2	21050	3/4"	2#6AWG	10	50	23
LL3	21060	1"	3#6AWG	5	25	18
LL4	21070	1 1/4"	3#2AWG	2	10	14
LL5	21080	1 1/2"	3#2AWG	2	10	16
LL6	21090	2"	3#2/OAWG	1	5	14
LL7	21100	2 1/2"	3#4/OAWG	—	1	6
LL8	21110	3"	3#250MCM	—	1	6
LL9	21120	3 1/2"	3#350MCM	—	1	8
LL10	21130	4"	4#350MCM	—	1	8

DOWNLOAD SPEC SHEET



E170258

RIGID C TYPE

TOPAZ CAT #	UPC#	SIZE	MAX # CONDUCTORS	UNIT CTN	SHIP CASE	WT/ CASE
C1	19900	1/2"	1#6AWG	10	100	24
C2	19910	3/4"	2#6AWG	10	50	21
C3	19920	1"	3#6AWG	5	25	15
C4	19930	1 1/4"	3#2AWG	2	10	15
C5	19940	1 1/2"	3#2AWG	2	10	17
C6	19950	2"	3#2/OAWG	1	5	13
C7	19960	2 1/2"	3#4/OAWG	—	1	6
C8	19970	3"	3#250MCM	—	1	6
C9	19980	3 1/2"	3#350MCM	—	1	8
C10	19990	4"	4#350MCM	—	1	8

DOWNLOAD SPEC SHEET




E170258

MOGUL CONDUIT BODIES WITH COVERS & GASKETS

RIGID LB TYPE

MALLEABLE IRON

TOPAZ CAT #	UPC#	SIZE	UNIT CTN	SHIP CASE	WT/ CASE
MLBCG4	32110	1 1/4"	—	5	8
MLBCG5	32120	1 1/2"	—	2	10
MLBCG6	32130	2"	—	2	9
MLBCG7	32131	2 1/2"	—	1	26
MLBCG8	32132	3"	—	1	34
MLBCG9	32133	3 1/2"	—	1	74
MLBCG10	32134	4"	—	1	74

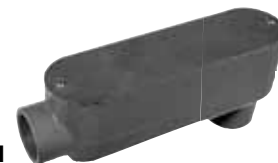

E170258

DOWNLOAD SPEC SHEET

DOWNLOAD SPEC SHEET