



SWITCHES

Switches

SWITCHES

ROCKER, ROTARY & MISCELLANEOUS SWITCHES

CAT. NO.	UPC CODE	CIRCUIT FUNC.	POLES & THROWS	RATINGS			VOLTAGE	LAMP COLOR	ACTR. CONTACT	CONN. TYPE	CTN. QTY.
				AMPS 125 VAC	AMPS 250 VAC	H.P. 125-250 VAC					
 77010RQ	77010	on off	DPST	20	10	1 1/2 @ 125, 2 @ 250	non-lighted	black	maintained	.250 quikconnect	5
77040RQ	77040	on on	DPDT	20	10	1 1/2 @ 125, 2 @ 250	non-lighted	black	maintained	.250 quikconnect	5
77060RQ	77060	on off on	DPDT	20	10	1 1/2 @ 125, 2 @ 250	non-lighted	black	maintained	.250 quikconnect	5
77090RQ	77090	(on) off	DPST	15	10	3/4	non-lighted	black	momentary	.250 quikconnect	5
77100RQ	77100	(off) on	DPST	15	10	3/4	non-lighted	black	momentary	.250 quikconnect	5
77110RQ	77110	(on) on	DPDT	15	10	3/4	non-lighted	black	momentary	.250 quikconnect	5
77120RQ	77120	(on) off on	DPDT	15	10	3/4	non-lighted	black	momentary	.250 quikconnect	5
77130RQ	77130	(on) off (on)	DPDT	15	10	3/4	non-lighted	black	momentary	.250 quikconnect	5
DIMENSIONS IN INCHES A: 1.348 B: .750 C: .762 D: .422											
 77140RQ	77140	on off	SPST	15	10	—	non-lighted	black	maintained	.250 quikconnect	5
DIMENSIONS IN INCHES A: 1.250 B: .625 C: .828 D: .406											
 77150RQ	77150	on off	SPST	15	7.5	—	—	red	maintained	.250 quikconnect	5
DIMENSIONS IN INCHES A: 1.250 B: .625 C: .828 D: .406											
 77030RQ	77030	on off	DPST	15	10	3/4 @ 250	125V incand.	1st lens red 2nd lens —	maintained	.250 quikconnect	5
77020RQ	77020	on off	DPST	15	10	3/4 @ 250	125V neon	amber —	maintained	.250 quikconnect	5
77050RQ	77050	on on	DPDT	15	10	3/4 @ 250	125V incand.	red amber	maintained	.250 quikconnect	5
77070RQ	77070	on off on	DPDT	15	10	3/4 @ 250	125V neon	amber amber	maintained	.250 quikconnect	5
77080RQ	77080	on off on	DPDT	15	10	3/4 @ 250	125V neon	red red	maintained	.250 quikconnect	5
DIMENSIONS IN INCHES A: .426 B: 1.088 C: .709 D: .345 E: 1.302											
 77300RW	77300	on off	SPST	3	1	non-lighted	rotary canopy		maintained	wire leads	5
DIMENSIONS IN INCHES A: .718 B: .600 C: .265											
 77340RW	77340	on off	SPST	6	3	non-lighted	rotary canopy		maintained	wire leads	5
77320RW	77320	off on on on	SPST	3	1	non-lighted	rotary canopy		maintained	wire leads	5
DIMENSIONS IN INCHES A: 1.000 B: .844											
 79100MS	79100	on off	SPST	6	3	—			feed through switch	screws	5
DIMENSIONS IN INCHES A: .844 B: .594 C: 1.375											
 79200MS	79200	N.C. & N.O.	SPDT	5	—	—			magnetic feed switch	screws	5
DIMENSIONS IN INCHES A: 2.500 B: .531											

() indicates momentary position All rocker switches are black phenolic bases with a black snap-in bezel and nylon actuator.

PUSHBUTTONS & PULL CHAINS

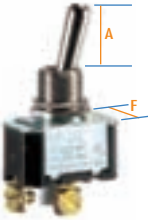
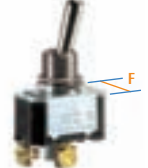
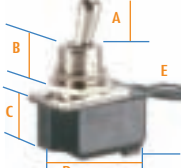
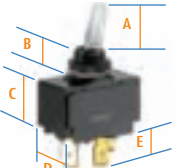
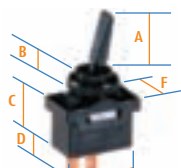
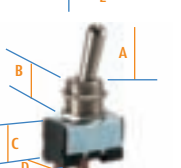
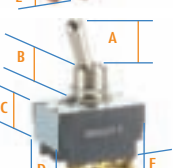
	CAT. NO.	UPC CODE	CIRCUIT FUNCTIONS	POLES & THROWS	RATINGS			ACTUATOR STYLE	ACTUATOR MATERIAL	CONTACT	CONN. TYPE	CTN. QTY.
					AMPS 125 VAC	AMPS 250 VAC	H.P. 125-250 VAC					
	76050PS	76050	push on, push off	SPST	6*	3*	—	pushbutton	brass/nickel	maintained	screws	5
	76040PW	76040	push on, push off	SPST	6	3	1/3 @125	pushbutton	brass/nickel	maintained	wire leads	5
DIMENSIONS IN INCHES			A: .437	B: .562	C: .542	D: 1.183						
	7610PW	7610	push on, push off	SPST	10	5	1/4 @125	pushbutton	nylon	maintained	wire leads	5
	DIMENSIONS IN INCHES			A: 1.003	B: .612	C: .550	D: .993					
	76060PS	76060	push on, push off	SPST	15	10	—	pushbutton	brass/nickel	maintained	screws	5
	DIMENSIONS IN INCHES			A: .283	B: .562	C: .982	D: 1.125					
	76090PW	76090	on off	SPST	6	3	—	push canopy	brass	maintained	wire leads	5
	76100PW	76100	on off	SPST	6	3	—	push canopy	nickel	maintained	wire leads	5
DIMENSIONS IN INCHES			A: .968	B: .313	C:	D: .858						
	76020PS	76020	off (on)	SPST N.O.	3/4	1/4	—	pushbutton	nylon	momentary	screws	5
	76030PS	76030	on (off)	SPST N.C.	3/4	1/4	—	pushbutton	nylon	momentary	screws	5
DIMENSIONS IN INCHES			A: .460	B: 1.070	C: .650	D: 1.950						
	76065PS	76065	off (on)	SPST N.O.	3	—	—	pushbutton	plastic	momentary	screws	5
	DIMENSIONS IN INCHES			A: .689	B: 1.406	C: .563	D: .875					
	76070PS	76070	off (on)	SPST N.O.	15	10	—	pushbutton	brass/nickel	momentary	screws	5
	76080PS	76080	on (off)	SPST N.C.	15	10	—	pushbutton	brass/nickel	momentary	screws	5
DIMENSIONS IN INCHES			A: .576	B: .562	C: 1.382							
	75101CW	75101	on off	SPST	6	3	—	chain w/cord	brass	—	wire leads	5
	75102CW	75102	on off	SPST	6	3	—	chain w/cord	nickel	—	wire leads	5
DIMENSIONS IN INCHES			A: 1.250	B: .781	C: .594							
	75110CW	751103	way/2 circuit	SP3T	6	3	—	chain w/cord	brass	—	wire leads	5
	75111CQ	751110	ff on on on	SP3T	6	3	—	chain w/cord	brass	—	push in	5
DIMENSIONS IN INCHES			A: 1.250	B: 1.125	C: .742							

*Amperage and voltage are also valid for D.C. Rating () indicates momentary position

Switches

SWITCHES

TOGGLE SWITCHES - MAINTAINED CONTACT & SINGLE POLE

CAT. NO.	UPC CODE	CIRCUIT FUNCTIONS	POLES & THROWS	RATINGS			ACTUATOR STYLE	ACTUATOR MATERIAL	CONN. TYPE	CTN. QTY.	
				AMPS 125 VAC	AMPS 250 VAC	H.P 125-250 VAC					
	78110TS	78110	on off	SPST	6	3	—	bat	brass/nickel	screws	5
	78210TS	78210	on off	SPST	20	10	3/4	bat	brass/nickel	screws	5
	78120TQ	78120	on off	SPST	20	10	3/4	bat	brass/nickel	.250 quikconnect	5
	78200TS	78200	on on	SPDT	20	10	3/4	bat	brass/nickel	screws	5
	78160TS	78160	on off on	SPDT	20	10	3/4	bat	brass/nickel	screws	5
	78060TQ	78060	on on	SPDT	20	10	3/4	bat	brass/nickel	.250 quikconnect	5
	78070TQ	78070	on off on	SPDT	20	10	3/4	bat	brass/nickel	.250 quikconnect	5
DIMENSIONS IN INCHES		A: .687	B: .465	C: .670	D: .348	E: 1.134	F: .634	THREAD: 15/32-32UNS-2A		KEYWAY: .072 X .038 DP	
	78140TS	78140	on off	SPST	6*	3*	—	bat	brass/nickel	screws	5
DIMENSIONS IN INCHES		A: .687	B: .465	C: .560	D: .348	E: .890	F: .524	THREAD: 15/32-32UNS-2A		KEYWAY: .072 X .038 DP	
	78150TW	78150	on off	SPST	10*	4*	—	bat	brass/nickel	wire leads	5
DIMENSIONS IN INCHES		A: .500	B: .469	C: .685	D: 1.093	E: 1.856	THREAD: 15/32-32		STANDARD 6" WIRE LEADS		
	78020TQ	78020	on off	SPST	15*	10*	3/4	flat	poly. (amber)**	.250 quikconnect	5
	78030TQ	78030	on off	SPST	15*	10*	3/4	flat	poly. (green)**	.250 quikconnect	5
	78040TQ	78040	on off	SPST	15*	10*	3/4	flat	poly. (red)**	.250 quikconnect	5
DIMENSIONS IN INCHES		A: .715	B: .379	C: .865	D: .750	E: .422	THREAD: 15/32-32UNS-2A		KEYWAY: .072 X .038 DP		
	78280TS	78280	on off	SPST	16*	8*	1	bat	brass/nickel	screws	5
	78010TQ	78010	on off	SPST	20	10	1 1/2	flat	nylon	.250 quikconnect	5
	78015TS	78015	on off	SPST	20	10	—	flat	nylon	screws	5
DIMENSIONS IN INCHES		A: .687	B: .280	C: .687	D: .375	E: 1.000	F: .588	KEYWAY: .072 X .038			
	78050TQ	78050	on off	SPST	20	10	3/4	bat	brass/nickel	.250 quik connect	5
DIMENSIONS IN INCHES		A: .687	B: .465	C: .585	D: .522	E: .312	THREAD: 15/32-32UNS-2A		KEYWAY: .072 X .038		
	78350TS	78350	circuits 1&2 on off circuits 1 on	2 circuits	15	10	3/4 @ 250	bat	brass/nickel	screws	5
DIMENSIONS IN INCHES		A: .687	B: .465	C: .778	D: .750	E: 1.308	F: .422	KEYWAY: .072 X .038			

*Amperage and voltage are also valid for D.C. Rating

**Lighted toggle

Poly. = Polycarbonate

TOGGLE SWITCHES - MAINTAINED & MOMENTARY CONTACT - MULTIPLE POLE

	CAT. NO.	UPC CODE	CIRCUIT FUNCTIONS	POLES & THROWS	RATINGS			ACTUATOR STYLE	ACTUATOR MATERIAL	CONN. TYPE	CTN. QTY.
					AMPS 125 VAC	AMPS 250 VAC	H.P 125-250 VAC				
	78080TQ	78080	on off	DPST	15	10	—	bat	brass/nickel	.250 quikconnect	5
	78220TS	78220	on off	DPST	20	10	3/4	bat	brass/nickel	screws	5
	78130TQ	78130	on off	DPST	20	10	3/4	bat	brass/nickel	.250 quikconnect	5
	78090TQ	78090	on on	DPDT	15	10	—	bat	brass/nickel	.250 quikconnect	5
	78100TQ	78100	on off on	DPDT	15	10	1 1/2	bat	brass/nickel	.250 quikconnect	5
	78270TS	78270	on on	DPDT	20	10	1 1/2@125.2@250	bat	brass/nickel	screws	5
	78240TS	78240	off (on)	DPST	15	10	3/4	bat	brass/nickel	screws	5
	78250TS	78250	on off (on)	DPDT	15	10	3/4	bat	brass/nickel	screws	5
	78260TS	78260	(on) off (on)	DPDT	15	10	3/4	bat	brass/nickel	screws	5
	DIMENSIONS IN INCHES			A: .687	B: .465	C: .778	D: .750	E: 1.308	F: .422	THREAD: 15/32-323UNS-2A	KEYWAY: .072 X .038
	78290TS	78290	on off	DPST	16*	8*	1	bat	brass/nickel	screws	5
	DIMENSIONS IN INCHES			A: .687	B: .465	C: .765	D: .836	E: 1.750	F: 1.764	THREAD: 15/32-323UNS-2A	KEYWAY: .072 X .038
	78300TS	78300	on off	DPST	20*	10*	1 1/2	bat	brass/nickel	screws	5
	DIMENSIONS IN INCHES			A: .687	B: .465	C: .895	D: 1.000	E: 2.093			
	78325TS	78325	on off	DPST	16	8	1	bat	nylon**	screws	5
	DIMENSIONS IN INCHES			A: .674	B: .468	C: .780	D: .810	E: 1.870			
	78310TS	78310	on off	3PST	15	10	3/4 @ 250	bat	brass/nickel	screws	5
	78315TS	78315	on off on	3PDT	15	10	3/4 @ 250	bat	brass/nickel	screws	5
DIMENSIONS IN INCHES			A: .688	B: .469	C: .965	D: .300	THREAD: 15/32				
	78330TS	78330	on off	4PST	15	10	3/4 @ 250	bat	brass/nickel	screws	5
	78320TS	78320	on on	4PDT	15	10	3/4 @ 250	bat	brass/nickel	screws	5
	78340TS	78340	on off on	4PDT	15	10	3/4 @ 250	bat	brass/nickel	screws	5
	DIMENSIONS IN INCHES			A: .687	B: .465	C: 1.436	D: .803	E: .422	F: 1.308	THREAD: 15/32-323UNS-2A	KEYWAY: .072 X .038
	78170TS	78170	off (on)	SPST	15	10	3/4	bat	brass/nickel	screws	5
	78180TS	78180	on off (on)	SPST	15	10	3/4	bat	brass/nickel	screws	5
	78190TS	78190	(on) off (on)	SPST	15	10	3/4	bat	brass/nickel	screws	5
DIMENSIONS IN INCHES			A: .687	B: .465	C: .670	D: .803	E: .348				
	79300MS	79300	rubber cover for toggles								
	DIMENSIONS IN INCHES			A: .950	B: .812						

*Amperage and voltage are also valid for D.C. Rating () Indicates momentary position

**Double-insulated for shock proof requirements