

PDQ-I LED

24V DC Strip Lighting

Ultra-Compact Indoor


PDQ-H-I High Output

PDQ-S-I Standard Output

LEDs

- **High-output**
Warm White: 2,800°K ±100°K, CRI 70, 225 lm per foot
Natural White: 4,100°K ±100°K, CRI 65, 235 lm per foot
- **Standard-output**
Warm White: 2,800°K ±100°K, CRI 70, 125 lm per foot
Natural White: 4,100°K ±100°K, CRI 65, 135 lm per foot


System

- 24VDC system, onboard constant-current driver:
High-output – 3.65W per foot
Standard-output – 2.30W per foot
- Dimmable with magnetic low-voltage (MLV) dimmer
- 40' max. run length
- Ultra-compact strip
- Available in 5' and 20' lengths
- Field-cutable with convenient markings every 4 inches
- Easy installation – 3M™ peel-n-stick adhesive pre-attached to strip
- UL/C-UL Listed for dry location 



24VDC, High-output LEDs

<input type="checkbox"/>	PDQ24-H-I-20-WW	Warm White High-output LED (2,800°K ±100K), CRI 70	20'
<input type="checkbox"/>	PDQ24-H-I-20-NW	Natural White High-output LED (4,100°K ±100K), CRI 65	20'
<input type="checkbox"/>	PDQ24-H-I-5-WW	Warm White High-output LED (2,800°K ±100K), CRI 70	5'
<input type="checkbox"/>	PDQ24-H-I-5-NW	Natural White High-output LED (4,100°K ±100K), CRI 65	5'

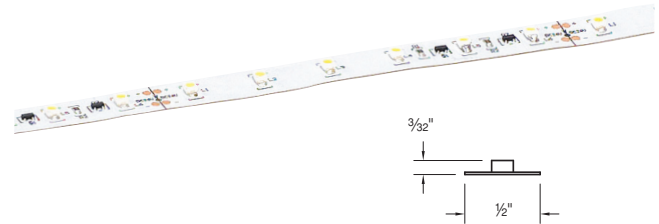

24VDC, Standard-output LEDs

<input type="checkbox"/>	PDQ24-S-I-20-WW	Warm White Standard-output LED (2,800°K ±100K), CRI 70	20'
<input type="checkbox"/>	PDQ24-S-I-20-NW	Natural White Standard-output LED (4,100°K ±100K), CRI 65	20'
<input type="checkbox"/>	PDQ24-S-I-5-WW	Warm White Standard-output LED (2,800°K ±100K), CRI 70	5'
<input type="checkbox"/>	PDQ24-S-I-5-NW	Natural White Standard-output LED (4,100°K ±100K), CRI 65	5'

Project _____

Fixture Type _____

Location _____

Contact _____

Phone _____




A Division of Troy-CSL Lighting, Inc.

14508 Nelson Avenue City of Industry CA 91744 Tel: 626.336.4511 Fax: 626.330.4266 www.csllighting.com

PDQ-I LED Accessories

System

- 24VDC system, onboard constant-current driver:
High-output – 3.65W per foot
Standard-output – 2.30W per foot
- Dimmable with magnetic low-voltage (MLV) dimmer
- 40' max. run length
- Ultra-compact strip
- Available in 5' and 20' lengths
- Field-cuttable with convenient markings every 4 inches
- Easy installation – 3M™ peel-n-stick adhesive pre-attached to strip
- UL/C-UL Listed for dry location 

PDQ LED Indoor Dimmable LED Drivers

24VDC

<input type="checkbox"/>	D-133	20W Mag	24V	E.I. magnetic	5" x 2¼" x 2"	4 lbs
<input type="checkbox"/>	D-134	40W Mag	24V	E.I. magnetic	5" x 2¼" x 2"	4 lbs
<input type="checkbox"/>	D-135	60W Mag	24V	E.I. magnetic	6" x 2⅝" x 2¼"	4 lbs
<input type="checkbox"/>	D-136	100W Mag	24V	E.I. magnetic	6" x 2⅝" x 2¼"	5 lbs
<input type="checkbox"/>	D-137	150W Mag	24V	E.I. magnetic	7½" x 3" x 3"	7 lbs

Connectors and Power Feeds

For Standard- and High-output Indoor LEDs only

<input type="checkbox"/>	PDQ24-I-CON-1	1"	24VDC Connector
<input type="checkbox"/>	PDQ24-I-CON-6	6"	24VDC Connector
<input type="checkbox"/>	PDQ24-I-CON-12	12"	24VDC Connector
<input type="checkbox"/>	PDQ24-I-CON-24	24"	24VDC Connector
<input type="checkbox"/>	PDQ24-I-PWR-10	10'	24VDC Power Feed



Indoor Power Feed



A Division of Troy-CSL Lighting, Inc.

14508 Nelson Avenue City of Industry CA 91744 Tel: 626.336.4511 Fax: 626.330.4266 www.csllighting.com