


Type 1 Lay-in Wireway Flat Lid

No Knock-outs Gray Powder Coated

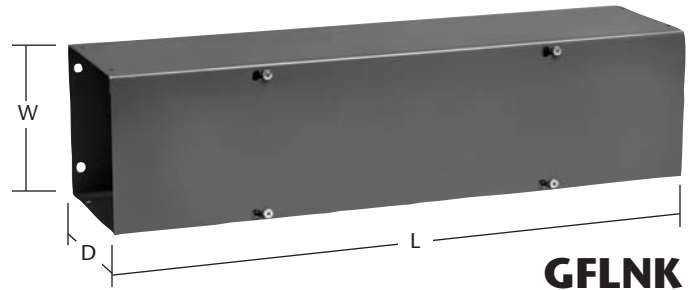

No Knock-outs

Catalog #	UPC 761515	Size D"xW"xL"	STD CTN	WGT	List Price, \$
4412GFLNK	16116	4x4x12	1	3	23.33
4424GFLNK	16118	4x4x24	1	6	40.00
4436GFLNK	16120	4x4x36	2	9	53.33
4448GFLNK	16122	4x4x48	2	12	68.89
4460GFLNK	16124	4x4x60	2	15	80.00
4472GFLNK	16126	4x4x72	2	18	102.22
4496GFLNK	16128	4x4x96	2	24	164.44
44120GFLNK	16130	4x4x120	2	30	168.89
6612GFLNK	16132	6x6x12	1	5	45.56
6624GFLNK	16134	6x6x24	1	10	60.00
6636GFLNK	16136	6x6x36	2	15	80.00
6648GFLNK	16138	6x6x48	2	20	106.67
6660GFLNK	16140	6x6x60	2	25	120.00
6672GFLNK	16142	6x6x72	2	30	164.44
6696GFLNK	16144	6x6x96	2	40	244.44
66120GFLNK	16146	6x6x120	2	50	275.56
8812GFLNK	16150	8x8x12	1	6	75.56
8824GFLNK	16152	8x8x24	1	13	111.11
8836GFLNK	16154	8x8x36	1	19	168.89
8848GFLNK	16156	8x8x48	1	26	204.44
8860GFLNK	16158	8x8x60	1	33	235.56
8872GFLNK	16160	8x8x72	1	39	306.67
8896GFLNK	16162	8x8x96	1	52	444.44
88120GFLNK	16164	8x8x120	1	65	511.11
101012GFLNK	16165	10x10x12	1	9	102.22
101024GFLNK	16166	10x10x24	1	17	168.89
101036GFLNK	16168	10x10x36	1	25	244.44
101048GFLNK	16170	10x10x48	1	34	311.11
101060GFLNK	16172	10x10x60	1	42	355.56
101072GFLNK	16174	10x10x72	1	51	444.44
101096GFLNK	16176	10x10x96	1	68	577.78
1010120GFLNK	16178	10x10x120	1	85	711.11
121212GFLNK	16179	12x12x12	1	10	120.00
121224GFLNK	16180	12x12x24	1	20	217.78
121236GFLNK	16182	12x12x36	1	30	311.11
121248GFLNK	16184	12x12x48	1	40	377.78
121260GFLNK	16186	12x12x60	1	50	435.56
121272GFLNK	16188	12x12x72	1	60	546.67
121296GFLNK	16190	12x12x96	1	80	666.67
1212120GFLNK	16192	12x12x120	1	100	888.89

Prices subject to change without notice
Replaces all previous prices