


# 400 Watt High Pressure Sodium

# 23022 DATA SHEET



**HIGH  
PRESSURE  
SODIUM**

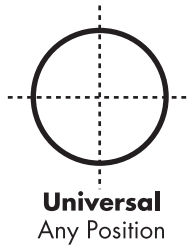

**ED18**



Dia. = 2.2" (57mm)  
MOL = 9.6" (244mm)  
LCL = 5.8" (146mm)  
Base = Mogul (E39)

## LU400 GENERAL Characteristics

Lamp Type	HPS Single Ended
ANSI Code	S51
Bulb Shape	ED18
Base Type	Mogul (E39)
Bulb Finish	Clear
Rated Life	24000 hours
Operating Position	Universal

## PHOTOMETRIC

Initial Lumens	51000
Lumens Per Watt	128
Lamp Lumen Depreciation (LLD)	.90 (90%) @ 12000 hours
Correlated Color Temperature	2100K
Chromaticity Coordinates (CIE-x,y)	.522 .423
Color Rendering Index (CRI)	22

## PHYSICAL

Bulb Diameter	2.2" (57mm)
Max. Overall Length (MOL)	9.6" (244mm)
Light Center Length (LCL)	5.8" (146mm)
Effective Arc Length	N/A
Max. Base Temperature (°C)	210
Max. Bulb Temperature (°C)	400
Socket Pulse Rating (KV)	4
Luminaire Type	Enclosed Rated

## ELECTRICAL

Lamp Watts	400
Lamp Oper. Voltage (Nom.)	100

## SUSTAINABILITY

Recycling Program	Smartpac® 800-451-2606
-------------------	------------------------

## NOTES

**(800) 451-2606**  
**or (440) 248-3510**

Fax: (800) 451-2605  
7905 Cochran Road  
Glenwillow, Ohio 44139 USA  
E-mail: [venture@adlt.com](mailto:venture@adlt.com)  
**VentureLighting.com**

This Product is Recyclable Through  Smartpac  
THE RECYCLING RESOURCE