


**PRODUCT SPECIFICATIONS**
 Part Number: HT185-02548  
 18 AWG/5 Conductor Thermostat Cable Solid

COMPLIANCE		
RoHS		YES
UL Listed		YES
NEC		YES
CERTIFICATIONS		
UL 13, Power Limited Circuit Cable		UL 1685 Vertical Tray
UL Listed Type CL2R		NEC Article 725
PHYSICAL SPECIFICATIONS		
Conductor Material		Solid Bare Copper
Conductor Size		18 AWG
Number of Conductors		5
Conductor Diameter (in.)		.041
Insulating Material Type		Polypropylene
Insulation Diameter (in.)		0.057
Insulation Nominal Thickness (in.)		0.008
Number of Insulations		5
Insulation Color Code		Red, White, Green, Blue, Yellow
Jacket Material Type		PVC
Jacket Color		White
Jacket Diameter (in.)		0.172
Jacket Nominal Thickness (in.)		0.016
Jacket Flame Rate		CL2R
Cable Weight (lb/250 ft)		9
Ripcord		Nylon
Sunlight Resistant		YES
PROPERTIES	PART NUMBER	LENGTH
TEMPERATURE RATING	HT185-02548	250 ft Plastic Spool
OPERATING VOLTAGE		
CAPACITANCE		
CHARACTERISTIC IMPEDANCE		
DC RESISTANCE		
FLAME RATING		

Cross Section:

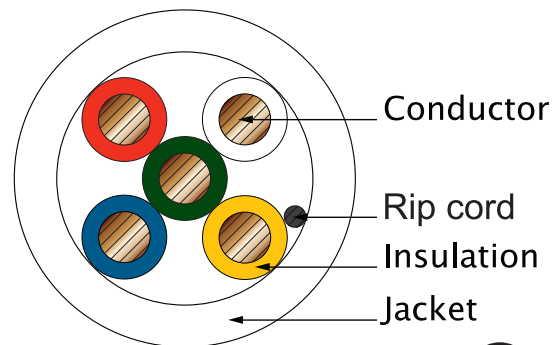

NOTE: TECHNICAL SHEETS ARE SUBJECT TO CHANGE WITHOUT NOTICE.



© 2013 VERICOM Global Solutions