

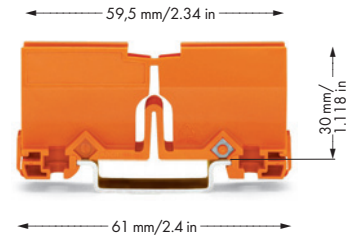
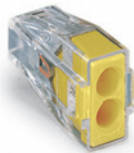


PUSH WIRE® Connectors for Junction Boxes Series 773

2 x 0.75 – 2.5 mm ² "s" 2 x 1.5 – 2.5 mm ² "st" 400 V/4 kV/2* I _N 24 A	2 x AWG 18 – 12 "sol." 2 x AWG 16 – 12 "str." 600 V, 20 A	4 x 0.75 – 2.5 mm ² "s" 4 x 1.5 – 2.5 mm ² "st" 400 V/4 kV/2* I _N 24 A	4 x AWG 18 – 12 "sol." 4 x AWG 16 – 12 "str." 600 V, 20 A	Mounting carrier for 773 Series PUSH WIRE® Connectors for Junction Boxes Carrier width 18 mm / 0.71 in
1 Approvals		1 Approvals		1 Approvals

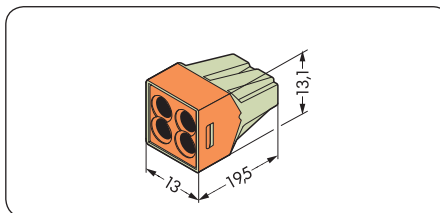




Color	Item No.	Item No.	Item No.	Color	Item No.	Item No.	PU	Color	Item No.	PU
PUSH WIRE® connector for junction boxes ②,				PUSH WIRE® connector for junction boxes ②,				Mounting carrier,		
2-conductor connector, color of housing transparent,				4-conductor connector, color of housing transparent,				orange	773-332	50 (5 x 10)
color of cover yellow	773-102		500 (10 x 50)	color of cover orange	773-104		500 (10 x 50)	Marker strips,		
								plain	243-110	1 card

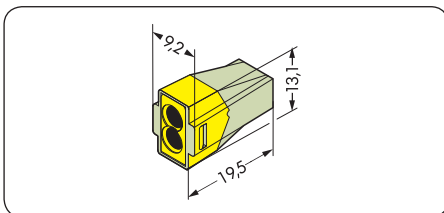

6 x 0.75 – 2.5 mm ² "s" 6 x 1.5 – 2.5 mm ² "st" 400 V/4 kV/2* I _N 24 A	6 x AWG 18 – 12 "sol." 6 x AWG 16 – 12 "str." 600 V, 20 A	8 x 0.75 – 2.5 mm ² "s" 8 x 1.5 – 2.5 mm ² "st" 400 V/4 kV/2* I _N 24 A	8 x AWG 18 – 12 "sol." 8 x AWG 16 – 12 "str." 600 V, 20 A	3 x 2.5 – 6 mm ² "s+st" 400 V/4 kV/2** 41 A	3 x AWG 14 – 10 "sol.+str." 600 V, 30 A
1 Approvals		1 Approvals		1 Approvals	



Color	Item No.	PU	Color	Item No.	PU	Color	Item No.	PU
PUSH WIRE® connector for junction boxes ②,			PUSH WIRE® connector for junction boxes ②,			PUSH WIRE® connector for junction boxes,		
6-conductor connector, color of housing transparent,			8-conductor connector, color of housing transparent,			3-conductor connector, color of housing transparent,		
color of cover violet	773-106	500 (10 x 50)	color of cover dark gray	773-108	500 (10 x 50)	color of cover red	773-173	500 (10 x 50)

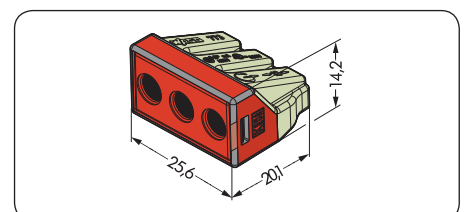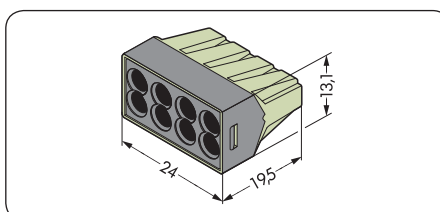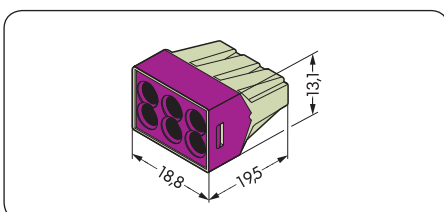

1 Approvals are available online at: www.wago.com.

2 Also available for increased continuous service temperature of 120 °C.

* In grounded (earthed) supply systems

For technical explanations and abbreviations, see technical section.