



Low Voltage Lighting Power Supplies with 24-Hour Timer & Photocell

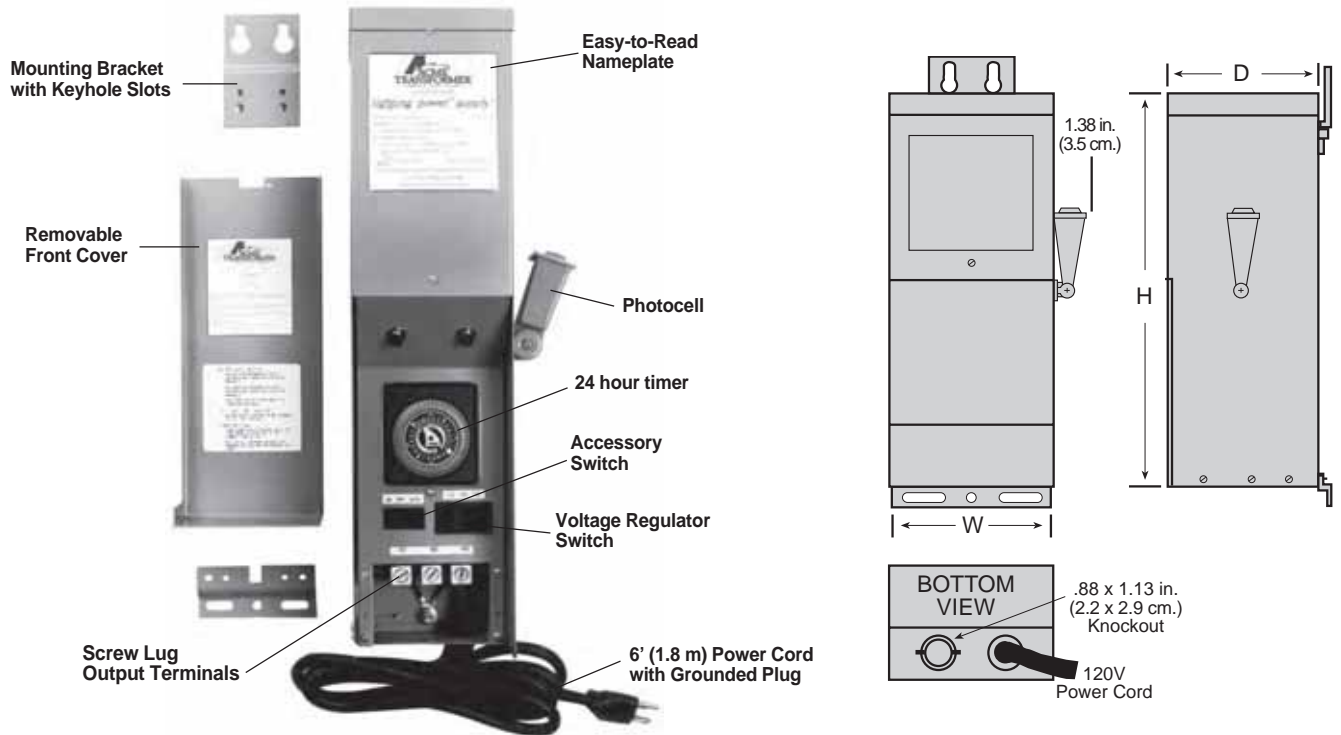


FEATURES

- 100, 150, 300, 600 Watt Models.
- 120V Primary, 12V or 12/24 V Secondary, 60 Hz.
- Fully encapsulated core and coil.
- 24-hour timer and photocell.
- Wall mounting brackets included.
- UL Listed.
- Screw lug terminals for ease of wiring.
- Deadfront terminal cover for added safety.
- 3-Position on-off-auto switch for versatility.
- Removable front cover, generous wiring space.
- 6' power cord with grounded plug.
- Voltage regulation switch for 11, 12 or 13 volts.
- Overload protection on primary and secondary sides.
- 10-year limited product warranty (3-years on timer/photocell).
- Faraday shielded for greater safety.

WIRING DIAGRAMS

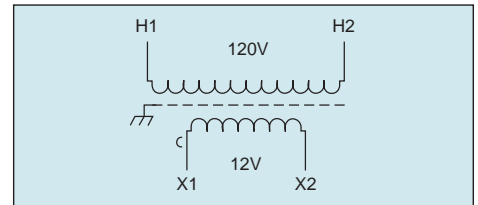

12V Units

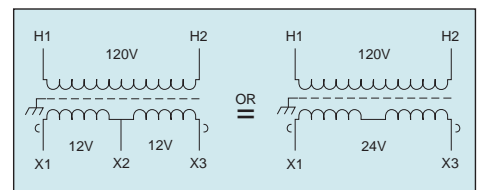

12/24 V Units

SELECTION GUIDE

GROUP I



WATTS	120V INPUT 12V OUTPUT	120V INPUT 12/24V OUTPUT ①	APPROX. DIMENSIONS ② INCHES (CM.)			APPROX. SHIP WEIGHT LBS. (KG.)
	CATALOG NO.	CATALOG NO.	HEIGHT	WIDTH	DEPTH	
300	TLVA30012SC	TLVA30024SC	19.00 (48.3)	4.62 (11.7)	4.25 (10.8)	14 (6.4)
600	TLVA60012SC	TLVA60024SC	19.00 (48.3)	4.62 (11.7)	4.25 (10.8)	18 (8.2)

① 12/24V denotes a three wire circuit, one 24V output or two 12V outputs. Each 12V is rated at one half the nameplate wattage.

② Dimensions not suitable for construction purposes. Contact factory for certified drawings.