

**Motor connection terminals**

In hazardous area applications, the installation instructions and the rated data specifications for accessories given in the technical appendix must be followed.

Width/Length/Height of lowest version	mm
max. current / max. cond. cross-section	A/mm <sup>2</sup>
Max. clamping range	mm <sup>2</sup>

**Technical data**

Rated data	
Rated voltage	V
Rated current	A
Rated cross-section	mm <sup>2</sup>
Rated impulse withstand voltage / Pollution severity	
Gauge to IEC 60947-1 / Flammability class UL94	
Approvals	
Clamped conductors (H05V/H07V)	
Solid / stranded	mm <sup>2</sup>
Flexible / Flexible with ferrule	mm <sup>2</sup>
Tightening torque range (terminal screw)	
Stripping length / Blade size	mm/-
Note	

**Ordering data**

Version	Dark beige Wemid With PE foot
Note	


**Accessories**

End plate / Partition plate	Dark beige PA
End bracket	Dark beige Wemid
Screwdriver	Standard
Cross-connection	black blue red

Identification systems	(see assortment in catalogue 7) Marking tags
Note	

**MAK 2.5**

**2.5 mm<sup>2</sup>**

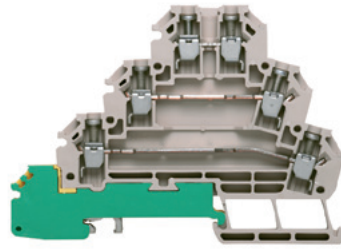

6.2 x 88 x 64	
<b>31 / 4</b>	
<b>0.13...4</b>	

IEC	UL	CSA
500	300 (D)	300 (C)
24	10 (D)	10 (C)
2.5	AWG 22...12	AWG 26...12
6 kV / 3		
A3 / V-0		
® 94		
Rated connection		
0.5...4 / 0.5...4		
0.5...4 / 0.5...2.5		
0.4...0.6 Nm (M 2.5)		
8 / 0.6 x 3.5 mm		
Note		


Type	Qty.	Order No.
MAK 2.5 DB	50	<b>7917030000</b>
Note		

Type	Width	Qty.	Order No.
AP MAK2.5 DB	1.5 mm	20	<b>7917000000</b>
WEW 35/1	12 mm	50	<b>1059000000</b>
SDIS 0.6X3.5X100		1	<b>9008390000</b>
current			
VQB 1.5/50 SW	17.5 A	5	<b>1635120000</b>
VQB 1.5/50 BL	17.5 A	5	<b>1633280000</b>
VQB 1.5/50 RT	17.5 A	5	<b>1633290000</b>

Identification systems	(see assortment in catalogue 7) Marking tags
Note	

**VLI 1.5**

**1.5 mm<sup>2</sup>**

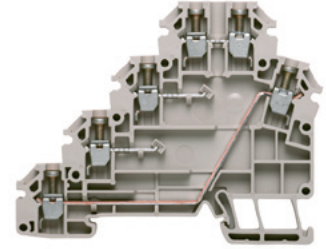

6.15 x 69 x 64	
<b>24 / 4</b>	
<b>0.13...4</b>	

IEC 60947-7-1 (-7-2)		
IEC	UL	CSA
250	300 (D)	
17.5	10 (D)	
1.5	AWG 26...12	
4 kV / 3		
A3 / V-0		
94		
Rated connection		
0.5...4 / 0.5...2.5		
0.5...4 / 0.5...2.5		
0.4...0.6 Nm (M 2.5)		
8 / 0.6 x 3.5 mm		
Note		

Type	Qty.	Order No.
VLI 1.5 DB	50	<b>1784120000</b>
VLI 1.5/PE DB	50	<b>1784130000</b>
Note		

Type	Width	Qty.	Order No.
AP VLI1.5 DB	1.5 mm	20	<b>1784150000</b>
WEW 35/1	12 mm	50	<b>1059000000</b>
SDIS 0.6X3.5X100		1	<b>9008390000</b>
current			
VQB 1.5/50 SW	17.5 A	5	<b>1635120000</b>
VQB 1.5/50 BL	17.5 A	5	<b>1633280000</b>
VQB 1.5/50 RT	17.5 A	5	<b>1633290000</b>

Identification systems	(see assortment in catalogue 7) Marking tags
Note	