

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130110-0050](#)
Status: **Active**
Description: Pro-Yellow® 400W Metal Halide High Bay Light with Lamp Molded 18/3 SJTW 1.83m (6.0') Pulse Start

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

UL E174254

General

Product Family	Portable Lighting
Series	130110
NEMA Configuration	NEMA 5-15
NEMA Rating	Rain Tight
Outlet	None
Product Literature Order No	987650-8054
Product Name	Pro-Yellow®
Type	Wide Area Lamps
UPC	78172505741
Woodhead	Yes

Physical

Cord Length - Primary	0.91m (3.0')
Cord Length - Secondary	N/A
Depth	N/A
Duty	General
Guard Included	No
Guard Type	N/A
Height	463.55mm (18.250")
Length	N/A
Material - Guard	#10 Gauge Zinc-plated Steel
Mounting Style	Hook
Packaging Type	Carton
Socket Construction	N/A

Electrical

Bulb Type	Metal Halide - Pulse Start
Cord Type - Primary	16/3 SOOW
Lamp Type	BT37/ED-37 Type O
Lamp Wattage - Maximum	400W
Lumens	26000
On/Off Switch	No
Voltage (Fixture) - Maximum	120VAC 60 HZ

Material Info

Old Part Number 8575-MH-PS

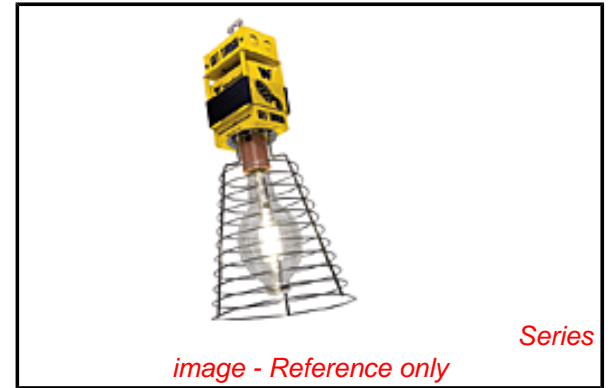


image - Reference only

EU RoHS

China RoHS

RoHS Compliance
Not Required
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[130110Series](#)