




CALL YOUR WOODHEAD REPRESENTATIVE TODAY!

SEE PAGES 2-7




SAFEWAY® NYLON DEVICES

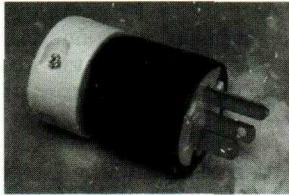

SAFEWAY® PLUG



SAFEWAY® 50A PLUG

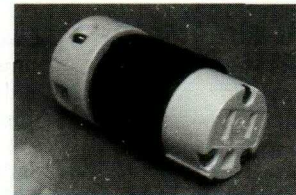

SAFEWAY® CONNECTOR

| Face View | NEMA Configuration | Amps/Volts | Cord Range | Plug ¹ |
|---|--------------------|-------------------|------------|--------------------------|
| 2-POLE/2-WIRE | | | | |
| | 1-15 | 15A/125V | .335-.640 | 5166 / 5176 ⁶ |
| | L1-15 | 15A/125V | .335-.640 | 24T04 |
| | L2-20 | 20A/250V | .325-.840 | 26T07 |
| 2-POLE/3-WIRE | | | | |
| | 5-15 | 15A/125V | .335-.640 | 5266 |
| | L5-15 | 15A/125V | .335-.640 | 4720 |
| | 6-15 | 15A/250V | .335-.640 | 5666 |
| | L6-15 | 15A/250V | .335-.640 | 24T49 |
| | 7-15 | 15A/277V | .335-.640 | 5766 |
| | L7-15 | 15A/277V | .335-.640 | 4770 |
| | 5-20 | 20A/125V | .335-.640 | 5366 |
| | L5-20 | 20A/125V | .335-.640 | 26T47 |
| | 6-20 | 20A/250V | .325-.840 | 5466 |
| | L6-20 | 20A/250V | .335-.640 | 26T48 |
| | L7-20 | 20A/277V | .325-.840 | 26T49 |
| | L5-30 | 30A/125V | .325-.840 | 28T47 |
| | L6-30 | 30A/250V | .425-1.150 | 28T48 |
| | L7-30 | 30A/277V | .425-1.150 | 28T49 |
| 2-POLE/3-WIRE GROUNDING, LOCKING, NON-NEMA, CALIFORNIA STYLE | | | | |
| | Non-NEMA Locking | 50A/125V | | CS6361N |
| | Non-NEMA Locking | 50A/250V | | CS8265N |
| | Non-NEMA Locking | 50A/480V | | CS8465N |
| 2-POLE/3-WIRE, GROUNDING, LOCKING, NON-NEMA, STANDARD DUTY | | | | |
| | Non-NEMA Locking | 50A/125V | | 6361CRN |
| | Non-NEMA Locking | 50A/250VDC/600VAC | | 3763N |

¹ To order Safeway® devices in yellow, add "YL" suffix to Woodhead number.

For dimensional information, see pages 147-149.

² Standard color is brown.

³ Standard color is black.

⁴ For corrosion-resistant receptacle, add "CR" suffix to part number (e.g., 4949CR).

⁵ For complete listing of receptacles, see pages 150-151.

⁶ Polarized